






Ordering Information

Part#: LI-TX2B-IMX390-GMSL2-xxxH-X

Note:

xxxH - 060H: FOV H 60 °
 120H: FOV H 120 °
 200H: FOV H 200 °

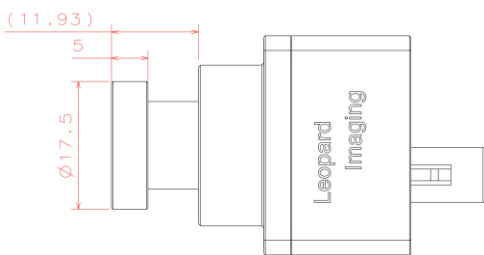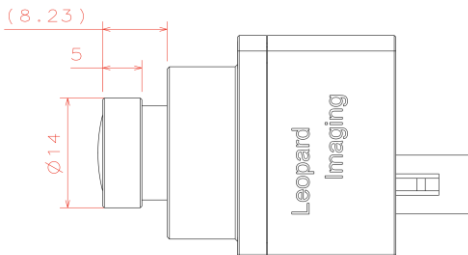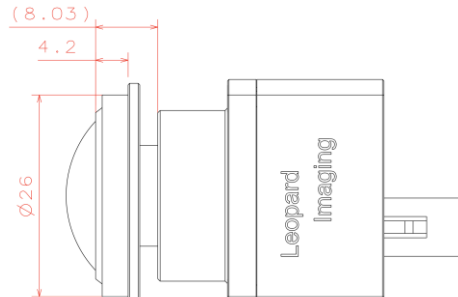LI-TX2B-IMX390-GMSL2-060H-X	LI-TX2B-IMX390-GMSL2-120H-X	LI-TX2B-IMX390-GMSL2-200H-X
		
Lens: M127B0618W Lens EFL: 6.0 mm FOV(D): 74.5° FOV(H): 60.6° FOV(V): 36.1°	Lens: M128B02820WM12R1 Lens EFL: 2.8 mm FOV(D): 148° FOV(H): 122° FOV(V): 74°	Lens: F132B0108WM12 Lens EFL: 1.08 mm FOV(D): 200° FOV(H): 200° FOV(V): 200°
		



Leopard Imaging Inc.

48820 Kato Rd, Suite 100B, Fremont, CA 94538, USA
 Phone: +1-408-263-0988
 Fax: +1-408-217-1960
 Email: sales@leopardimaging.com
 Website: www.leopardimaging.com

LI-TX2-BOX1-GMSL2

Technical details







- Nvidia Jetson TX2 SOM included
- 6 GMSL2 interfaces
- 1 Micro SD card interface
- 1 Micro HDMI connector
- 1 Power socket (DC 12V)
- 1 RJ45 Ethernet connector
- 1 USB 2.0 micro B interface
- REC, RST and PWR buttons included
- Heat sink and fan included
- WIFI Antenna included
- Connector: FAKRA Z TYPE
- Includes 4 mounting holes
- Weight: 500g
- Size: 100mm x 100mm x 69mm
- Part#: **LI-TX2-BOX1-GMSL2**



Leopard Imaging Inc.

48820 Kato Rd, Suite 100B, Fremont, CA 95035, USA
Phone: +1-408-263-0988
Fax: +1-408-217-1960
Email: sales@leopardimaging.com
Website: www.leopardimaging.com


Dimensions (with box)

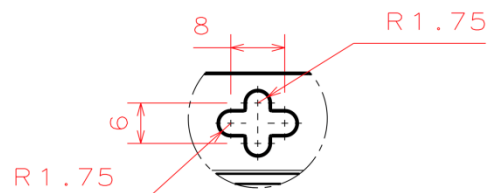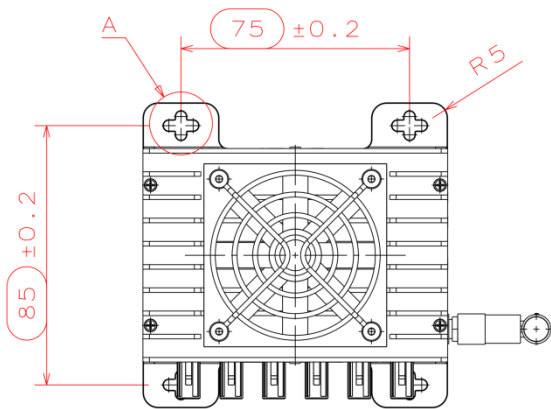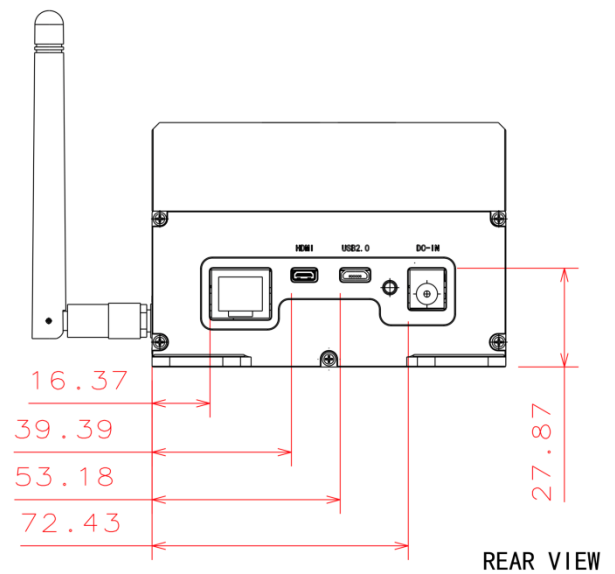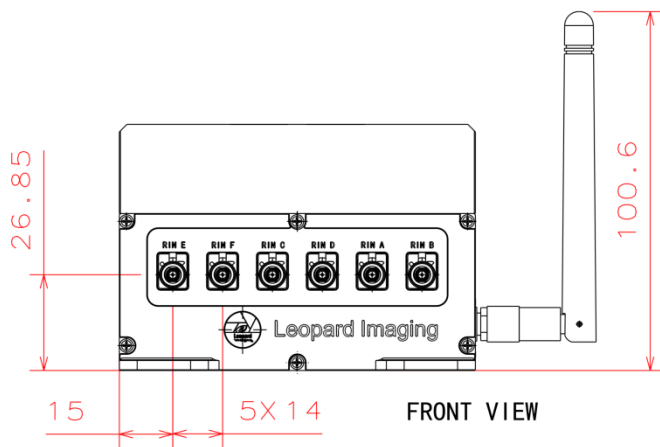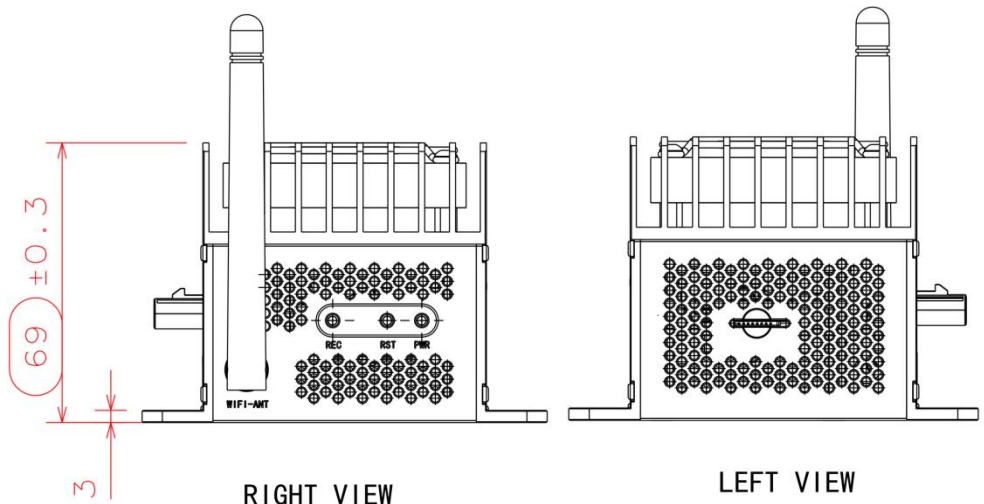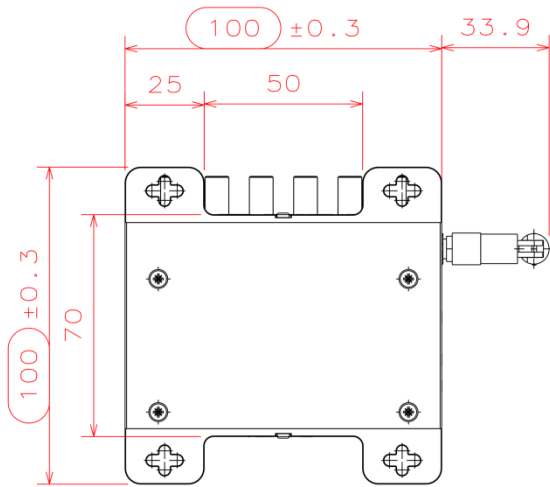

Leopard Imaging Inc.

48820 Kato Rd, Suite 100B, Fremont, CA 95035, USA
 Phone: +1-408-263-0988
 Fax: +1-408-217-1960
 Email: sales@leopardimaging.com
 Website: www.leopardimaging.com

Dimensions (without box)

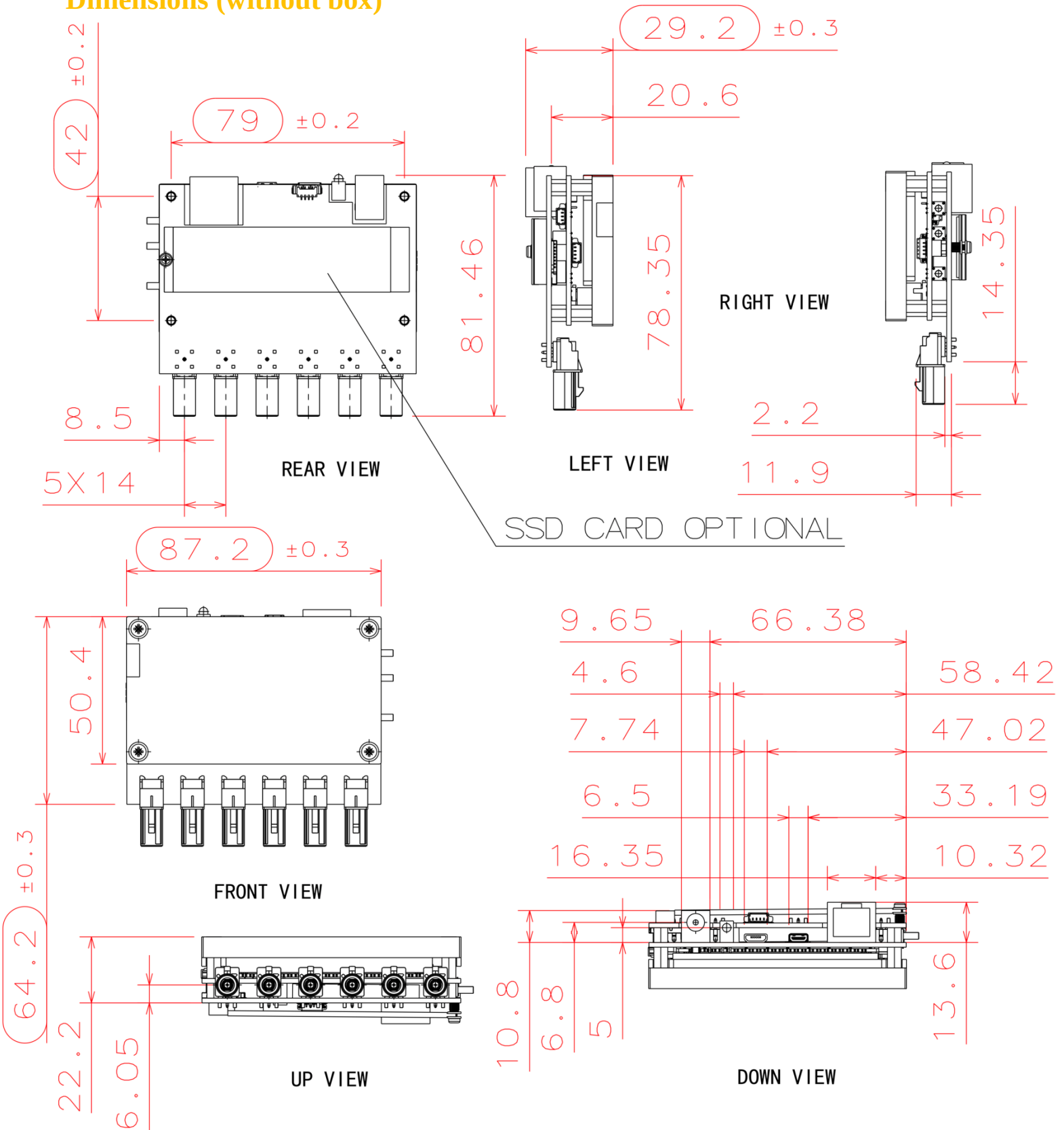


Leopard Imaging Inc.

48820 Kato Rd, Suite 100B, Fremont, CA 95035, USA
 Phone: +1-408-263-0988
 Fax: +1-408-217-1960
 Email: sales@leopardimaging.com
 Website: www.leopardimaging.com

LI-IMX390-GMSL2

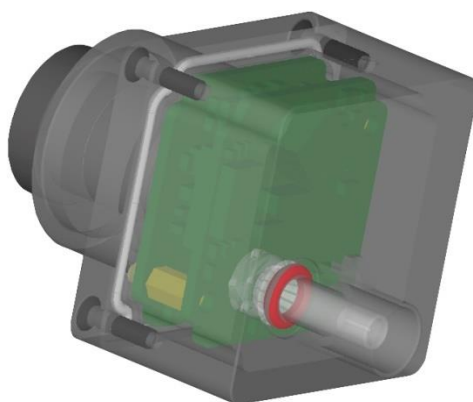

Camera Spec	
Image Sensor	Sony Diagonal 6.67mm (Type 1/2.7) CMOS RGGB Image Sensor IMX390
Optical format	1/2.7"
Number of active pixels	1937 (H) x 1217 (V)
Pixel size	3.0um (H) x 3.0um (V)
Color or Mono	Color
FOV	60 / 120 / 200 (H)
Format	RAW data output without compression
Interface	GMSL2 Serial interface
Lens mount	M12
Weight	45 g
Operation Temp	-40 ~ 105 °C
Storage Temp	-40 ~ 125 °C
Water proof : IP67 (Up to IP69K) Lens must be glued	
▪ Metal Housing ▪ Water-proof M12 lens ▪ Sealed Gasket (White) ▪ Sealed O-ring (Red)	



Leopard Imaging Inc.





48820 Kato Rd, Suite 100B, Fremont, CA 95035, USA
Phone: +1-408-263-0988
Fax: +1-408-217-1960
Email: sales@leopardimaging.com
Website: www.leopardimaging.com

Cable Connector

- Housing Connector-FAKRA Z Type
- Cable length: 3 meters
Support single Coax Cable transmit up to 12 meters
- Cable Part#: FAK-SMZSMZ-0008
FAKRA type connectors



Camera board dimensions

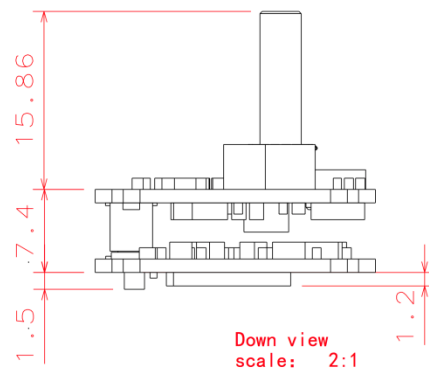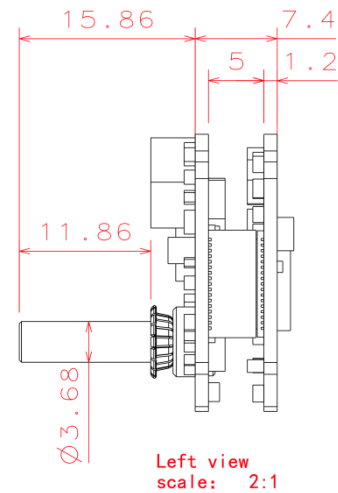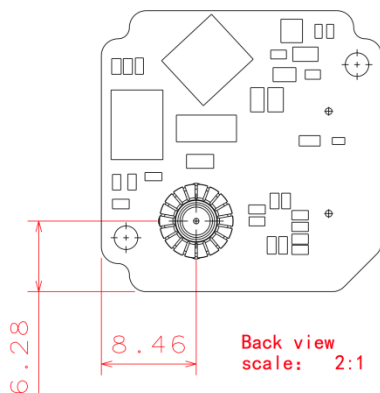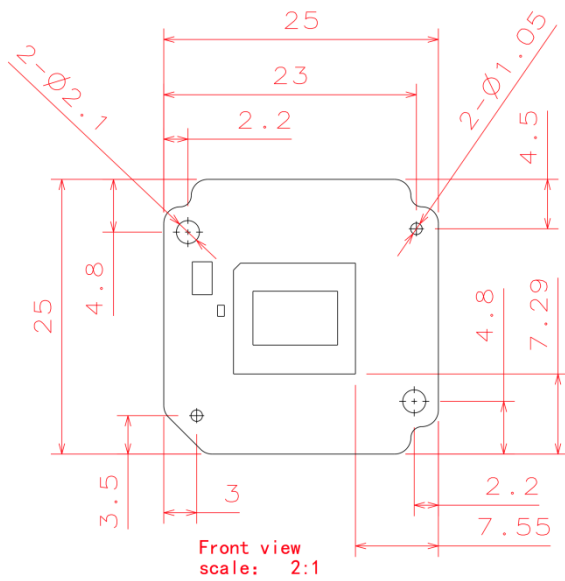

Leopard Imaging Inc.

48820 Kato Rd, Suite 100B, Fremont, CA 95035, USA
Phone: +1-408-263-0988
Fax: +1-408-217-1960
Email: sales@leopardimaging.com
Website: www.leopardimaging.com

Revision History

Revision	Description	Release Date
1.0	First Release	23. Dec. 2018



Leopard Imaging Inc.

48820 Kato Rd, Suite 100B, Fremont, CA 95035, USA
Phone: +1-408-263-0988
Fax: +1-408-217-1960
Email: sales@leopardimaging.com
Website: www.leopardimaging.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Leopard Imaging:

[LI-TX2B-IMX390-GMSL2-200H-D](#) [LI-TX2B-IMX390-GMSL2-200H-Q](#) [LI-TX2B-IMX390-GMSL2-200H-H](#) [LI-TX2B-IMX390-GMSL2-060H-Q](#) [LI-TX2B-IMX390-GMSL2-060H-H](#) [LI-TX2B-IMX390-GMSL2-060H-D](#) [LI-TX2B-IMX390-GMSL2-120H-D](#)