



LEOPARD IMAGING INC


Rev. 1.1

LI-USB30-OV10640-490

Data Sheet

Key Features

- USB 3.0 Super Speed support
- YUV output without compression
- UVC compliance
- Support M12 lens
- Provide customization services
- USB +5VDC powered device
- Support WDR
- On-board OV490 ISP
- Compact Size: 26mmx26mm
- 2 Boards are stacked

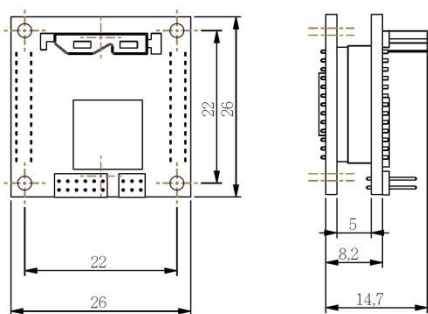

Default Lens Specification

- Model: YC-155N
- Focal length: 2.8 mm
- Aperture, F/#: 2.0
- Built in 650nm IR cut filter
- FOV (D/H/V): 125.5 ° / 104.5 ° / 88 °
- TV Distortion: < 12%
- Mount: M12 x P0.5

Applications

- Machine Vision
- Medical Camera
- Video Conference
- Scientific Camera

SDK Supported

- Camera Tool Source Code in C#
- Capture & Display



Leopard Imaging Inc.

1130 Cadillac Ct., Milpitas, CA 95035, USA
Phone: +1-408-263-0988
Fax: +1-408-217-1960
Email: sales@leopardimaging.com
Website: www.leopardimaging.com
www.leopard-security.com

Specification

General Behavior	
Video Resolution @ Frame rate	1280 x 1080 @ 30 fps 1280 x 720 @ 30 fps
Sensitivity	TBD
Dynamic range	TBD
Interface (Optical)	
IR cut filter (on lens)	Yes, 650nm IR cut filter
Sensor specification	OmniVision CMOS 1.3MP HDR Sensor OV10640
Shutter	Rolling
Format	1/2.56"
Resolution	H:1280, V:1080
Pixel size	H:4.2 um, V: 4.2 um
WDR	Support WDR (Wide Dynamic Range)
Lens mount	M12 lens mount support
ISP	OV490
Interface (Electrical)	
Interface	USB 3.0
Supply voltage	USB 3.0 +5 VDC power source
Current consumption	Approx. 312 mA at 5 VDC
Interface (Mechanical)	
Dimensions	L: 26 mm, W: 26 mm, H: 38 mm
Mass	22 g
Adjustment (Manual)	
Shutter	TBD
Gain	TBD
Adjustment (Auto)	
Shutter	TBD
Gain	TBD
Environmental	
Max. temperature (operation)	0 °C ~ 50 °C (32 °F~ 122 °F)
Max. temperature (storage)	-20 °C ~ 80 °C (-4 °F~176 °F)
Max. humidity (operation)	20 % ~ 80 %, relative, non-condensing
Max. humidity (storage)	20 % ~ 80 %, relative, non-condensing



Leopard Imaging Inc.

1130 Cadillac Ct., Milpitas, CA 95035, USA
Phone: +1-408-263-0988
Fax: +1-408-217-1960
Email: sales@leopardimaging.com
Website: www.leopardimaging.com
www.leopard-security.com

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Leopard Imaging:](#)

[LI-USB30-OV10640-490](#)