

Specification Sheet

USB2.0 Flash Drive Handy Steno AH322



Table of Contents

1. Product Introduction.....	3
2. Product Features.....	3
3. Specifications.....	4
4. Physical Dimension.....	4
5. Revision History.....	5

1. Product Introduction

Apacer's AH322 is for users that prefer personal accessories with an upscale look. With its black, baked enamel finish and transparent cap, the AH322 projects quality and a sophisticated sense of style. At the back of the drive is a hole for attaching a keychain or lanyard for easy carrying. No matter what digital files you are storing or sharing, the AH322 is a handy, yet elegant companion.

The AH322 USB drives are designed for user convenience. Insert the drive into a computer's USB port and transfer files with ease and speed. The plug-and-play USB 2.0 and USB 1.1 compliant interface is compatible with operating systems such as Windows XP/7/8, Mac OS 10.4.x or later, and Linux 2.6.x or later. Apacer AH322 USB flash drives let you bring your digital lifestyle with you wherever you go.


2. Product Features

- Plug and play
- A sophisticated sense of style
- The strap hole makes it easy to be attached
- Capacity support up to 32GB
- RoHS Compliant

3. Specifications

Specifications	
Interface	High-speed USB 2.0 certified, backwards compatible with USB 1.1
Power supply	USB bus powered No external power required
Operating Systems Supported	Windows XP/7/8, Mac OS 10.4.x and Linux 2.6.x or above
Capacity	2GB~ 32GB
Operating Temperature	0° C to +70° C (32° F to 158° F)
Storage Temperature	-20° C to +70° C (-4° F to +158° F)
Dimensions	(L) 55.4 x (W) 18 x (H) 8.5 mm
Weight	8g approx.

4. Physical Dimension

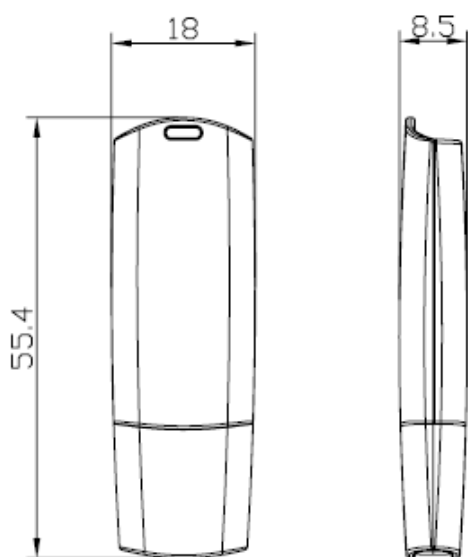

Tolerance ± 0.2 mm

5. Revision History

Revision	Date	History	Remark
1.0	2008/10/31	Release	
1.1	2010/9/29	Add Windows 7 support	
1.2	2012/10/04	Add 32GB density and physical dimension	
1.3	2015/07/02	Revise temperature	

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Apacer:

[AP2GAH322B-1](#) [AP4GAH322B-1](#) [AP8GAH322B-1](#) [AP16GAH322B-1](#) [AP2GAH322B](#) [AP32GAH322B](#)
[AP8GAH322B](#) [AP4GAH322B](#) [AP16GAH322B](#) [AP32GAH322B-1](#)