

40 & 50 VA Transformer

HCT Series



Specifications

Wire Size

All leads are 18 AWG stranded
2/64" insulation thickness

Quick Connect Size

Standard male quick connect terminals
are .250" x .032"

Frequency

50/60 Hz

Insulation System

130°C Class B

Unit Weight

| | |
|-------|----------|
| 40 VA | 24.32 oz |
| 50 VA | 33.60 oz |

Transformers change one AC voltage to another by magnetic induction. Hartland Controls produces transformers with primary and secondary voltage up to 250 VA. Our heavy-duty transformers are used in a variety of applications, including HVAC, water pumps, pool and spa, food service and electronics. We carry extensive inventory to meet delivery schedules.

Features

- UL/CUL recognized 5085—File No. E223730, Class 2 UL 1585
- Inherently limited
- No secondary fusing required
- Multiple mounting and termination options available, contact us for more information.

We can custom engineer a solution
to meet any need. Just ask.

815.626.5170 | [HartlandControls.com](https://www.HartlandControls.com)

40 & 50 VA Transformer


HCT Series

| Color | Black | White | Red | Orange | Brown | Black/Red | Grey |
|--------------|-------|-------|------|--------|-------|-----------|------|
| Lead Length | 12" | 12" | 12" | 12" | 12" | 12" | 12" |
| Strip Length | 1/2" | 1/2" | 1/2" | 1/2" | 1/2" | 1/2" | 1/2" |

| Color | Blue | Yellow |
|--------------|------|--------|
| Lead Length | 12" | 12" |
| Strip Length | 1/2" | 1/2" |

Dimensions (inches [mm])
Quick Connect Models

| | | |
|--------------|------|------|
| A DIM | 2.60 | 2.97 |
| B DIM | .875 | 1.25 |

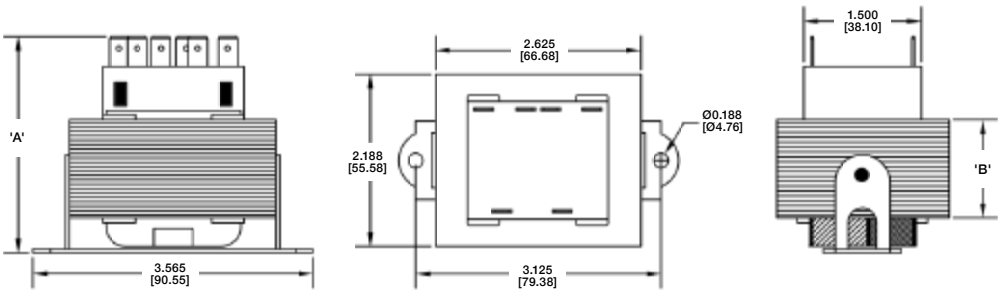

Multiple mounting and termination options available, contact us for more information.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Littelfuse:](#)

[TRAN-40VA](#) [TRAN-50VA](#)