


# C-Series

Single Pole Toggle Switches

**PRODUCT WEBPAGE**

*request sample, configure part*

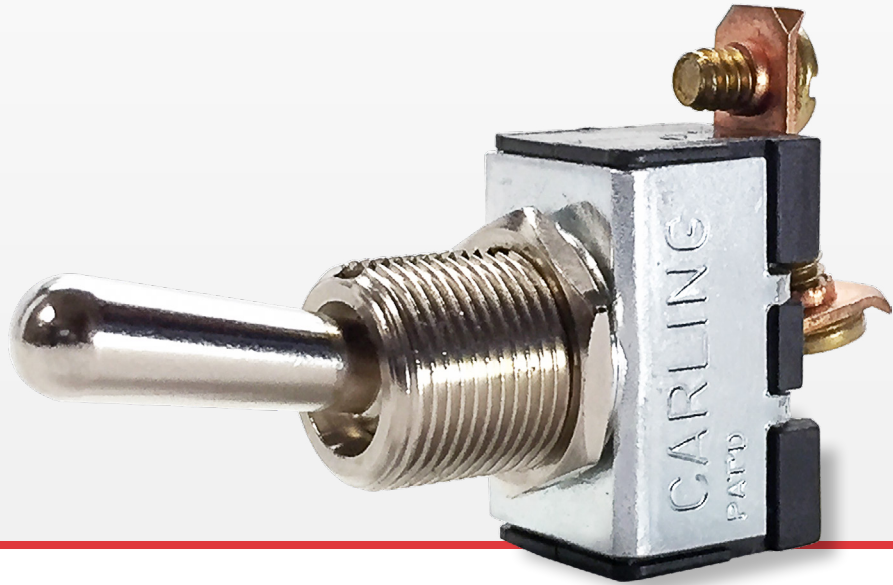

The C-Series single pole compact high current toggle switches are ideal for applications with back panel size constraints. These switches feature self-cleaning contacts and ratings up to 20A 125VAC, 10A 250VAC, 11/2 HP 125-250VAC. With a rugged metal construction, these switches figure prominently in markets with stringent current carrying requirements.

|          |              |                 |
|----------|--------------|-----------------|
| <b>1</b> | <b>10-20</b> | <b>125, 250</b> |
| Pole     | Amps         | VAC             |

## Typical Applications

• Environmental Controls • Marine • Food Service • Vacuum Cleaners

# Tech Specs

## Dielectric Strength

1000V - live to dead metal parts and opposite polarity.

## Electrical Life

25,000 cycles

## Operating Temperature

32°F to 185°F (0°C to 85°C)

# Ordering Scheme

Sample  
Part Number

CA201 73

Selection

1

2

### 1. SERIES

10A 250VAC, 20A 125VAC, 11/2 HP 125-250VAC

Single Pole

Solder Lug

.250 Tab

Screw Term.

Wire Leads

On-None-Off

CA200

CA201

CA204

CA205

On-None-On

CB200

CB201

CB204

CB205

Additional toggle styles available. Consult factory.

### 2. KNOB COLOR




|     |                |              |                        |                         |
|-----|----------------|--------------|------------------------|-------------------------|
| BAT | unsealed<br>73 | sealed<br>78 | toggle length<br>0.687 | bushing length<br>0.465 |
|-----|----------------|--------------|------------------------|-------------------------|

[Configure Complete Part Number >](#)

[Browse Standard Parts >](#)

# Dimensional Specs

inches [millimeters]

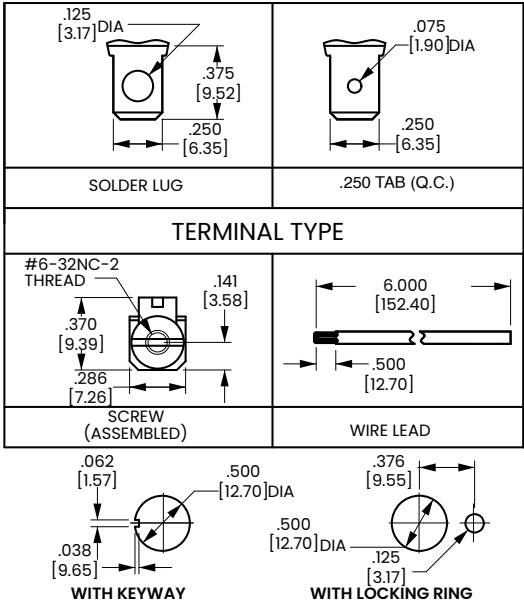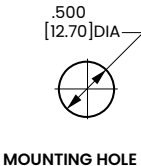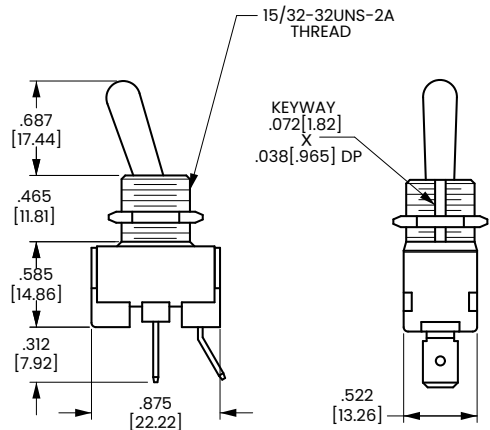

## Authorized Sales Representatives and Distributors

Click on a region of the map below to find your local representatives and distributors or visit [www.carlingtech.com/findarep](http://www.carlingtech.com/findarep).



## About Carling

Founded in 1920, Carling Technologies is a leading manufacturer of electrical and electronic switches and assemblies, circuit breakers, electronic controls, power distribution units, and multiplexed power distribution systems. With six ISO9001 and IATF16949 registered manufacturing facilities and technical sales offices worldwide, Carling Technologies Sales, Service and Engineering teams do much more than manufacture electrical components, they engineer powerful solutions! To learn more about Carling please visit [www.carlingtech.com/company-profile](http://www.carlingtech.com/company-profile).

To view all of Carling's environmental, quality, health & safety certifications please visit [www.carlingtech.com/environmental-certifications](http://www.carlingtech.com/environmental-certifications).

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Carling Technologies:](#)

[CB204-73](#) [CA201-73](#) [CA204-73](#) [CA205-73](#) [CB201-73](#) [CA200-78](#) [CB200-73](#) [CA200-73](#) [CA201-78](#) [CA204-78](#)  
[CA205-78](#) [CA101-78](#) [CA201-73/272-06747](#) [CB100-73](#) [CB101-73](#) [CA105-73/272-06747](#) [CB205-73](#) [CA105-78](#)  
[CA100-73](#) [CA201-73/2 HEX](#) [CB201-73/2 HEX](#) [CA205-52/2 HEX](#) [CA201-73/728-15907](#) [CA201-57](#) [CA101-73](#)  
[CA101-73/HDW ASSM](#) [CB100-78](#) [CA201-73/POLY](#) [CA200-52/2 HEX](#) [CA104-73](#) [CA101-52](#) [CA201-52](#) [CB101-78](#)  
[CA100-52](#) [CB201-52](#) [CB101-52](#) [CA105-52](#) [CA200-52](#) [CB201-78](#) [CA105-73](#) [CA204-52](#) [CA204-57](#) [CA205-57](#)  
[CAB-23970028](#) [CB200-78](#) [CB204-78](#)