

# INLINE MAXI® BLADE STYLE FUSE HOLDER

## For MAXI® Style Blade Fuses



### Description

Supplied with two 5" leads - 6 gauge wire for up to 60A MAXI®/FK3 Fuse applications, this In-line Fuse Holder also provides a protective cover for harsh under-the-hood environments. Mounting hole also permits easy bulkhead installation.

### Features and Benefits

- Two 5" UL3288 wire leads for easy in-line installation
- Center body hole for bulkhead mounting
- Attached cover secures and protects installed fuse from splashes and debris
- 80°C max operating temperature

### Dimensions in mm

PART NUMBER	A	B	LEAD A COLOR	LEAD B COLOR
MAHC0001ZXJ	127.0 ± 5.0	127.0 ± 5.0	Black	Black
MAHC0001TXJ	127.0 ± 5.0	127.0 ± 5.0	Red	Red
MAHC0001ZXJB	150.0 ± 5.0	150.0 ± 5.0	Black	Black

### Specifications

<b>Housing:</b>	Thermoplastic (UL 94-V0, heat resistant)
<b>Color:</b>	Black
<b>Current Rating:</b>	60A
<b>Voltage Rating:</b>	32V DC

### Applications

- Air conditioners
- Heater blower motor
- Air compressors
- High amperage audio equipment


### Recommended Fuse

MAXI® Series  
Blade Fuses



### Ordering Information

BULK PART NUMBER	BLISTER PART NUMBER	DESCRIPTION	PACKAGE SIZE
MAHC0001ZXJ	MAHC-BP	6AWG black wire 60A	100
MAHC0001TXJ	—	6AWG black wire 60A	10

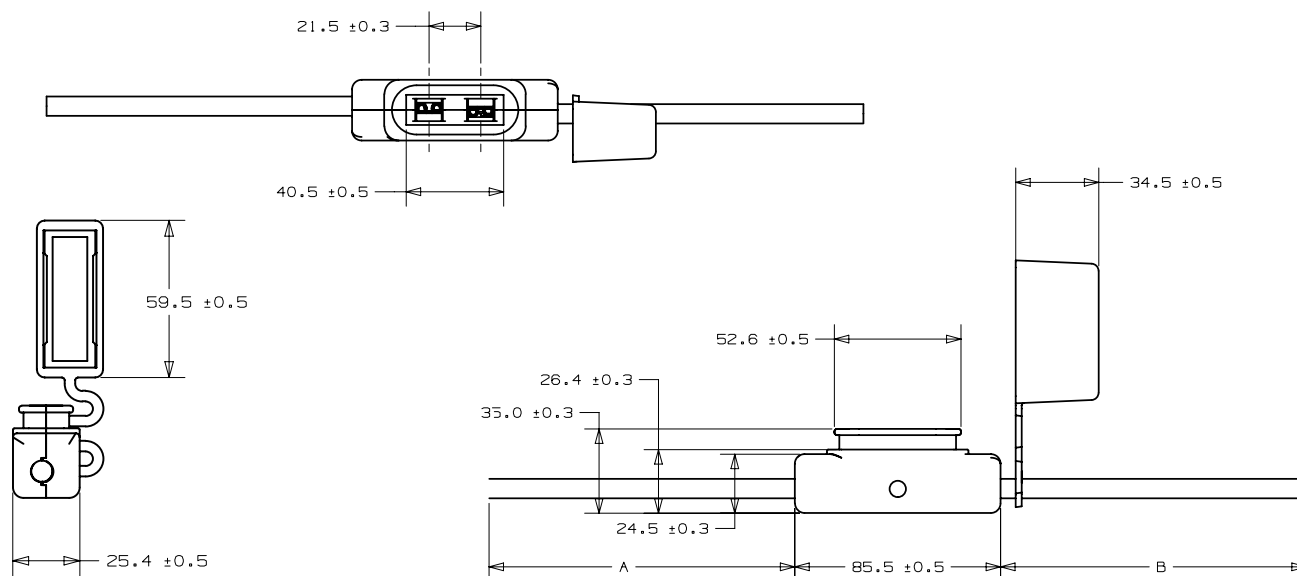

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Littelfuse:

[MAHC0001ZXJB](#)