

# MAXI STYLE SPLASH RESISTANT FUSE HOLDER

For MAXI® Blade Fuses



## Description

The Inline Splash Resistant Fuse Holder provides an efficient, simple installation method for MAXI® / FK3-style fuse applications in harsh under-the-hood environments. Protected to IP54 rating.

\* PA66-GF30: heat resistant

\*\* UL 94-V0: self extinguishing

## Recommended Fuse

MAXI® Blade Fuses  
 Voltage Rating: 60A-80A




## Ordering Information

| PART NUMBER    | DESCRIPTION                                                                       | CURRENT RATING | VOLTAGE RATING | PACKAGE SIZE |
|----------------|-----------------------------------------------------------------------------------|----------------|----------------|--------------|
| 01520003U      | Fuse Holder Body w/ Molded Holes                                                  | 80A            | 32VDC          | 500          |
| 01520003TXN941 | 01520003_ Fuse Holder Kit w/ cover & wire seals for 4-6mm <sup>2</sup> wire       | 80A            | 32VDC          | 10           |
| 01520003TXN942 | 01520003_ Fuse Holder Kit w/ cover & wire seals for 6-10mm <sup>2</sup> wire      | 80A            | 32VDC          | 10           |
| 01520004Z      | 60A Fuse Holder Body w/ Molded Mounting Tabs & 6mm Hole                           | 60A            | 32VDC          | 250          |
| 01520005Z      | 60A Fuse Holder Body                                                              | 60A            | 32VDC          | 250          |
| 01520006Z      | 60A Fuse Holder Body w/ Molded Mounting Tabs                                      | 60A            | 32VDC          | 250          |
| 01520007Z      | Cover & O-Ring Assembly                                                           | —              | —              | 750          |
| 279.6800.0002  | ** UL94-V0 Holder Housing                                                         | 80A            | —              | 100          |
| 279.6850.0402  | Assortment: Fuse Holder 279.6800.000 with seals and cover for 4mm <sup>2</sup>    | 80A            | —              | 10           |
| 279.6850.0602  | Assortment: Fuse Holder 279.6800.000 with seals and cover for 6-10mm <sup>2</sup> | 80A            | —              | 10           |
| 279.6850.1602  | Assortment: Fuse Holder 279.6800.000 with seals and cover for 16mm <sup>2</sup>   | 80A            | —              | 10           |

## Ordering Components

| PART NUMBER | DESCRIPTION                                          | PACKAGE SIZE |
|-------------|------------------------------------------------------|--------------|
| 01520903TXN | PA66-GF30* Inline Splash Resistant Fuse Holder Cover | 10           |
| 868-905     | Wire seals for wire Ø 2.5 - 6 mm <sup>2</sup>        | 1000         |
| 08680905TXN | Wire seals for wire Ø 2.5 - 6 mm <sup>2</sup>        | 10           |
| 868-906     | Wire seals for wire Ø 6 - 10 mm <sup>2</sup>         | 1000         |
| 08680906TXN | Wire seals for wire Ø 6 - 10 mm <sup>2</sup>         | 10           |

## Dimensions in mm

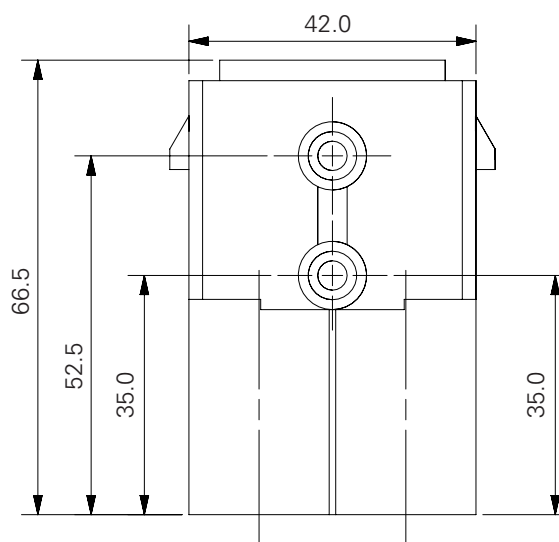

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Littelfuse:](#)

[08680906TXN](#) [08680905TXN](#)