



Carling Technologies®  
/// NOW PART OF



Littelfuse®

# VP-Series

Illuminated Indicators

**PRODUCT WEBPAGE**

*request sample, configure part*



The VP-Series illuminated plug offers an additional design option for the modular and flexible V-Series Contura® system. It is offered with removable and replaceable lamps, Contura styling, and LED illumination with your choice of one or two lenses.

**1-2**  
LED's

**125-250**  
VAC

**12-24**  
VDC

## Typical Applications

- On/Off-Highway

# Ordering Scheme

Flush Housing

Sample  
Part Number

VP 1 6 6 - B 1 1 6 6 - 00 0 00

Selection

1

2

3

4

5

6

7

8

9

10

11

12

## 1. SERIES

**VP** Illuminated plug for V and J Mounting Hole  
**H2** Housing only  
**H3** Lamp module only

## 2. TERMINATION

1 .250 TAB (QC)

## 3, 4. LAMP 4

|              |          |          |       |       |       |
|--------------|----------|----------|-------|-------|-------|
| No lamp      | 0        |          |       |       |       |
| Neon         | 1 125VAC | 2 250VAC |       |       |       |
| Incandescent | 4 3V     | 5 6V     | 6 12V | 7 18V | 8 24V |
| LED*         | Amber    | Green    | Red   |       |       |
| 2VDC         | L        | F        | R     |       |       |
| 6VDC         | M        | G        | S     |       |       |
| 12VDC        | N        | H        | T     |       |       |
| 24VDC        | P        | J        | V     |       |       |

\*Typical current draw for LED is 20ma.

## 5. FLUSH HOUSING COLOR / STYLE

**B** Black / Rectangular  
**W** White / Rectangular  
**R** Red / Rectangular  
**G** Gray / Rectangular  
**1** Black / Oval (Contura V)

## 6, 7. LENS STYLE 5

**Z** No Lens  
**1** Transparent Diamond Square  
**2** Translucent Square 9  
**3** Laser Etched 10  
**4** Transparent Oval  
**5** Translucent Oval  
**6** Laser Etched Oval 10

## 8, 9. LENS COLOR 6,11

|       |         |       |       |     |      |                                         |
|-------|---------|-------|-------|-----|------|-----------------------------------------|
| Z     | No Lens |       |       |     |      |                                         |
| Clear | White   | Amber | Green | Red | Blue | Lens Style                              |
| 4     | 9       | E     | K     | R   | W    | One piece lens                          |
| 5     | A       | F     | L     | S   | Y    | Two piece lens*                         |
|       |         |       |       |     |      | (with <b>clear top</b> protective lens) |
| 2     | 7       | C     | H     | N   | U    | Two piece lens*                         |
|       |         |       |       |     |      | (with <b>smoke top</b> protective lens) |
| 1     | 6       | B     | G     | M   | T    | Two piece lens*                         |
|       |         |       |       |     |      | (with <b>white top</b> protective lens) |

\*All bottom lenses are molded of opaque material.  
Consult factory for other lens colors.

## 10. LENS LEGEND OVER LAMP 1 7

**00** No legend  
For standard legends, see "Standard Legend Codes" page.  
For additional legends, please consult factory

## 11. LEGEND ORIENTATION

|   |               |                                                                                     |                                                                                     |                                                                                     |                                                                                     |
|---|---------------|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|-------------------------------------------------------------------------------------|
| 0 | No legend     |  |  |  |  |
| 1 | Orientation 1 |                                                                                     |                                                                                     |                                                                                     |                                                                                     |
| 2 | Orientation 2 |                                                                                     |                                                                                     |                                                                                     |                                                                                     |
| 3 | Orientation 3 |                                                                                     |                                                                                     |                                                                                     |                                                                                     |
| 4 | Orientation 4 |                                                                                     |                                                                                     |                                                                                     |                                                                                     |

## 12. LENS LEGEND OVER LAMP 2 7

**00** No legend  
For standard legends, see "Standard Legend Codes" page.  
For additional legends, please consult factory

### Notes:

- To order housing only, specify H2 followed by fields 5-11.
- To order lamp module only, specify H3 followed by fields 2-3.
- To order connector housing specify HPI-01 (black).
- Field 3 specifies lamp 1 is located over terminals 1A & 1B.  
Field 4 specifies lamp 2 is located over terminals 2A & 2B.
- Field 6 specifies lens 1 is located over terminals 1A & 1B.  
Field 7 specifies lens 2 is located over terminals 2A & 2B.
- Field 8 specifies lens 1 is located over terminals 1A & 1B.  
Field 9 specifies lens 2 is located over terminals 2A & 2B.
- Field 10 specifies legend is over lens 1.  
Field 12 specifies legend is over lens 2.
- If only one lens is chosen, it will be located over terminals 1A & 1B.
- Translucent lens is available with two piece lens option only.
- Laser etched option is available with one piece lens.
- Oval lens option is available as one piece lens.

[Configure Complete Part Number >](#)

[Browse Standard Parts >](#)

# Ordering Scheme

Raised Bracket

Sample Part Number **VP 1 6 6 - 6 1 1 6 6 - 00 0 00**

Selection 1 2 3 4 5 6 7 8 9 10 11 12

## 1. SERIES

**VP** Illuminated plug for V and J Mounting Hole

## 2. TERMINATION

- 1 .250 TAB (QC)  
2 Solder Lug

## 3, 4. LAMP 1

|              |          |          |       |       |       |
|--------------|----------|----------|-------|-------|-------|
| No lamp      | 0        |          |       |       |       |
| Neon         | 1 125VAC | 2 250VAC |       |       |       |
| Incandescent | 4 3V     | 5 6V     | 6 12V | 7 18V | 8 24V |
| LED*         | Amber    | Green    | Red   |       |       |
| 2VDC         | L        | F        | R     |       |       |
| 6VDC         | M        | G        | S     |       |       |
| 12VDC        | N        | H        | T     |       |       |
| 24VDC        | P        | J        | V     |       |       |

\*Typical current draw for LED is 20ma.

## 5. RAISED BRACKET / INSERT COLOR

- 5 White / White  
6 Black / Black  
7 White / Black  
8 Black / White

## 6, 7. LENS STYLE 2

- Z No Lens  
1 Transparent Diamond Square  
2 Translucent Square 6  
3 Laser Etched 7

## 8, 9. LENS COLOR 3

|       |         |       |       |     |      |                                                     |
|-------|---------|-------|-------|-----|------|-----------------------------------------------------|
| Z     | No Lens |       |       |     |      |                                                     |
| Clear | White   | Amber | Green | Red | Blue | Lens Style                                          |
| 4     | 9       | E     | K     | R   | W    | One piece lens                                      |
| 5     | A       | F     | L     | S   | Y    | Two piece lens*<br>(with clear top protective lens) |
| 2     | 7       | C     | H     | N   | U    | Two piece lens*<br>(with smoke top protective lens) |
| 1     | 6       | B     | G     | M   | T    | Two piece lens*<br>(with white top protective lens) |

 
\*All bottom lenses are molded of opaque material.  
Consult factory for other lens colors.

## 10 LENS LEGEND OVER LAMP 1 4

00 No legend  
For standard legends, see "Standard Legend Codes" page.  
For additional legends, please consult factory

## 11 LENS ORIENTATION

- 0 No legend  
1 Orientation 1  
2 Orientation 2  
3 Orientation 3  
4 Orientation 4



## 12 LENS LEGEND OVER LAMP 2 4

00 No legend  
For standard legends, see "Standard Legend Codes" page.  
For additional legends, please consult factory

### Notes:


- Field 3 specifies lamp 1 is located over terminals 8 (+) & 7 (-).  
Field 4 specifies lamp 2 is located over terminals 10 (+) & 9 (-).
- Field 6 specifies lens 1 is located over terminals 8 (+) & 7 (-).  
Field 7 specifies lens 2 is located over terminals 10 (+) & 9 (-).
- Field 8 specifies lens 1 is located over terminals 8 (+) & 7 (-).  
Field 9 specifies lens 2 is located over terminals 10 (+) & 9 (-).
- Field 10 specifies legend is over lens 1.  
Field 12 specifies legend is over lens 2.
- If only one lens is chosen, it will be located over terminals 8 (+) & 7 (-).
- Translucent lens is available with two piece lens option only.
- Laser etched option is available with one piece lens.

[Configure Complete Part Number >](#)

[Browse Standard Parts >](#)

# Dimensional Specs

inches [millimeters]

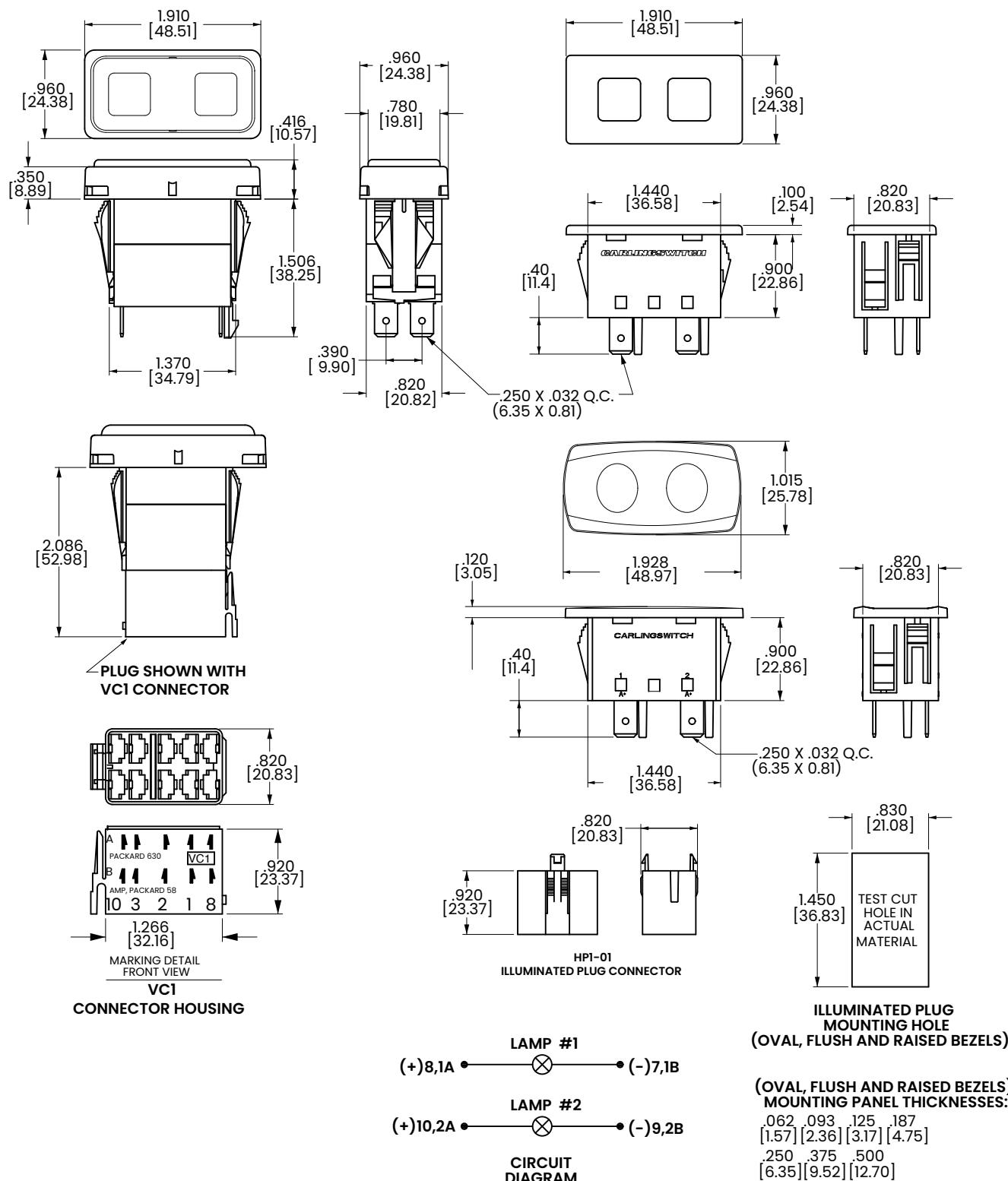

Notes:  
Oval and flush bezel styles use terminals 1A, 1B, 2A, 2B. Raised bezel style uses terminals 7, 8, 9, 10.

# Standard Legend Codes

|       |        |      |     |     |     |       |          |      |          |                 |           |      |
|-------|--------|------|-----|-----|-----|-------|----------|------|----------|-----------------|-----------|------|
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| YK    | UA     | UB   | US  | UV  | UW  | UX    | UY       | MP   | MR       | PX              | MS        | MT   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| VU    | MW     | NZ   | NX  | NY  | YM  | VW    | PS       | PW   | PZ       | WG              | WM        | RN   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| RP    | YG     | TX   | VD  | VE  | VF  | VG    | SH       | SM   | SN       | SP              | SR        | SY   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| DIM   | BRIGHT | UH   | UJ  | PD  | PE  | PF    | VC       | VJ   | UF       | UG              | MU        | TN   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| NS    | PB     | SE   | VZ  | YE  | NN  | RW    | PU       | WA   | YN       | UE              | NM        | RJ   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| NR    | YD     | TL   | VR  | SL  | VA  | UC    | VN       | PK   | VY       | UZ              | RH        | NU   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| NV    | RB     | RC   | RK  | RL  | MZ  | RG    | UP       | DOWN | UD       | UR              | WD        | TY   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| PA    | UK     | WR   | UU  | UT  | YR  | PM    | VV       | WB   | TB       | TC              | TD        | TE   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| MY    | PV     | TA   | TZ  | WC  | PT  | PN    | PH       | RA   | TU       | TT              | YL        | SK   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| VS    | UL     | UM   | WK  | TS  | VT  | WL    | VP       | YJ   | PJ       | RY              | UP        | NW   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| NP    | RE     | RF   | PP  | PR  | TV  | PC    | YT       | YU   | PL       | WJ              | MV        | RR   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| TK    | RT     | SZ   | VX  | WF  | WH  | PG    | SJ       | YA   | YB       | RM              | TM        | RD   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| RS    | UN     | TP   | TR  | NT  | MX  | YC    | TW       | TJ   | YF       | TH              | TF        | TG   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| YS    | YH     | SX   | RZ  | YP  | WN  | WP    | WW       | WX   | SA       | SB              | SC        | SD   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| RAISE | LOWER  | HIGH | LOW | FWD | REV | DEPTH | TRIM TAB | ACC  | NAV ANCH | WIND LASS UP/DN | LIVE WELL | REAR |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| ST    | SU     | WU   | WV  | SV  | SW  | VB    | VH       | VK   | VL       | VM              | WE        | SF   |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| PARK  | AUTO   | RU   | RV  | RX  |     |       |          |      |          |                 |           |      |
|       |        |      |     |     |     |       |          |      |          |                 |           |      |
| SG    | SS     |      |     |     |     |       |          |      |          |                 |           |      |

## Authorized Sales Representatives and Distributors

Click on a region of the map below to find your local representatives and distributors or visit [www.carlingtech.com/findarep](http://www.carlingtech.com/findarep).



## About Carling

Founded in 1920, Carling Technologies is a leading manufacturer of electrical and electronic switches and assemblies, circuit breakers, electronic controls, power distribution units, and multiplexed power distribution systems. With six ISO9001 and IATF16949 registered manufacturing facilities and technical sales offices worldwide, Carling Technologies Sales, Service and Engineering teams do much more than manufacture electrical components, they engineer powerful solutions! To learn more about Carling please visit [www.carlingtech.com/company-profile](http://www.carlingtech.com/company-profile).

To view all of Carling's environmental, quality, health & safety certifications please visit [www.carlingtech.com/environmental-certifications](http://www.carlingtech.com/environmental-certifications).

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## Carling Technologies:

[VP188-B1144-00000](#) [VP188-B11RX-00000-XGT1](#) [VP166-B11RE-00000](#) [VP160-B1ZKZ-00000](#) [VP160-62ZLZ-00000](#)  
[VP1PP-B1199-00000](#) [VP1VV-B1199-00000](#) [HP1-01-XLT1](#) [VP100-B11XX-00000-XASS1](#) [VP166-BXXXX-00000-](#)  
[XWB1](#) [VP160-B1ZKZ-00000-XJC1](#) [VP1NT-611ER-00000](#) [VP1TT-15599-00000](#) [VP188-B11E9-00000](#) [VP166-155KK-](#)  
[00000](#) [VP1H0-B1Z4Z-00000](#) [VP1X0-61ZRZ-00000-XGR1](#) [VP1HH-611KK-00000](#) [VP161-B11R4-00000](#) [VP188-](#)  
[B11KR-00000](#) [VP1NN-B1199-3M100](#) [HP1-02 CONNECTOR WHITE](#) [VP1PP-622FF-00000](#) [VP1VP-B1199-00000](#)  
[VP1NT-144ER-00000](#) [VP1TH-61199-00000](#) [VP1TO-61ZRZ-00000](#) [VP1JV-B11KR-00000](#) [VP1TT-B1199-MJ1ML](#)  
[VP1HT-15599-00000](#) [VP1X0-61ZRZ-00000-XRD1](#) [VP1HH-B11KK-BG1BE](#) [VP1JV-622AA-00000](#) [VP1TN-B11RE-](#)  
[00000](#) [VP1NN-62215-00000](#) [VP188-B11EX-00000-XGT1](#) [VP1XX-B11WW-00000-XBLU1](#) [VP1TT-B1199-83180](#)  
[VP1VV-W11RR-00000](#) [VP1P0-62ZFZ-B3100](#) [VP1JV-611KR-00000](#) [VP122-B11EE-00000](#) [VP188-B11RE-00000](#)  
[VP1HT-B1199-00000](#) [VP1V0-B1Z9Z-DA100](#) [VP160-B1ZEZ-DV100](#) [VP111-B1144-00000](#) [VP1VJ-16699-00000-XLT1](#)  
[VP1VV-155RR-00000](#) [VP1JV-15599-00000](#) [VP1HH-61199-00000](#) [VP100-611XX-00000-XGH1](#) [VP1H0-61ZKZ-00000](#)  
[VP1VP-16699-ER1XX-XBM1](#) [VP1PV-611ER-00000](#) [VP1VV-61144-00000](#) [VP166-155RR-00000](#) [VP166-611EE-](#)  
[00000](#) [VP1TT-62267-00000](#) [VP1NN-61199-00000](#) [VP1VV-15599-DT12J](#) [VP1JJ-61199-00000](#) [VP1NT-B1199-00000](#)  
[VP166-B11RR-N912J](#) [VP170-B1ZEZ-00000](#) [VP188-1559W-00000](#) [VP1XX-622AA-00000-XRD1](#) [VP1VJ-B11RX-](#)  
[00000-XGN1](#) [VP1JV-B1144-00000](#) [VP1V0-B1Z9Z-2J100](#) [VP1HH-B1199-00000](#) [VP1MN-B11EE-00000](#) [VP1V0-](#)  
[14ZRZ-00000](#) [VP1TH-B1199-00000](#) [VP1HH-15599-00000](#) [VP1JJ-611KK-00000](#) [VP1NN-144EE-00000](#) [VP166-](#)  
[B11WR-451Y3](#) [VP1TH-611RK-00000](#) [VP166-155WK-00000](#) [VP1HH-155KK-00000](#) [VP180-B1ZKZ-00000](#) [VP1VV-](#)  
[15599-00000](#) [VP1XX-60000-00000-XRED1](#) [VP1NT-15599-M81AW](#) [VP1P0-14ZEZ-00000](#) [VP188-B11X9-00000-XCG1](#)  
[VP1XP-B1199-00000-XTM1](#) [VP1XT-15599-00000-XHBG1](#) [VP166-B11K9-00000](#) [VP1PV-622FS-00000](#) [VP188-](#)  
[B11KK-00000](#) [VP180-61ZEZ-00000](#) [VP1TT-B1199-DV1DX](#) [VP1VV-B11RR-DX1DV](#) [VP166-B11RK-00000](#) [VP1XV-](#)  
[B1199-8612J-XBV2](#) [VP166-B11ER-3V100](#) [VP1N0-B1ZEZ-00000-XTR1](#) [VP1V0-15Z9Z-00000](#)