

# F Series Pushbutton Switches




## Features/Benefits

- Up to 10 poles per module
- Various contact terminals
- Various mounting & switch ganging configurations
- Mechanical indicator buttons
- RoHS compliant

## Typical Applications

- Audio selection
- Digital equipment interface
- Medical equipment interface

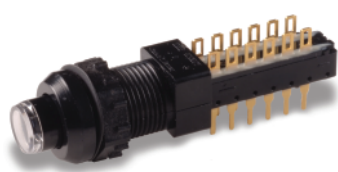

## Specifications

SWITCHING POWER: F module max. AC/DC: Silver: 50 VA/15W, Gold: 1 VA/300 mW.

SWITCHING VOLTAGE: F module max. AC/DC: Silver: 125/30V, Gold: 50/30 V.

SWITCHING CURRENT: F module max. AC/DC: Silver: 0.5A/0.5A, Gold: 0.04A/0.01A.

CARRYING CURRENT: Max at du = 20C: Silver: < 2A, Gold: <0.5A.

DIELECTRIC STRENGTH (50 Hz, 1 min.): Chassis/contact: ^1500V Between contacts: ^1500V.

OPERATING LIFE "OA/EE" (24V/200mA): >10<sup>5</sup> operations "GR": >3.5 x 10<sup>4</sup> operations.

CONTACT RESISTANCE: Initial: Typical %10 mΩ, max. 20 mΩ After operating life: %100 mΩ

INSULATION RESISTANCE: ^10<sup>9</sup> Ω between open contacts, ^10<sup>9</sup> Ω between chassis and contacts.

CAPACITANCE (at f = 10 kHz): %0.7 pF between 2 contacts.

TOTAL TRAVEL/LATCHING TRAVEL: 4.7mm/3.3mm (.185 inch/.130 inch).

All models and options are RoHS compliant and compatible.

**NOTE:** All models and options are RoHS compliant and compatible.

**NOTE:** Specifications and materials listed above are for switches with standard options. For information on specific and custom switches, consult Customer Service Center.

TYPICAL F OPERATING FORCE: 2U: 6.5N (650 grams); 4U: 6.5N (650 grams); 6U: 7.5N (750 grams); 8U: 9.0N (900 grams); 10U: 9.0N (900 grams).

EUROPEAN TYPICAL SF OPERATING FORCE:  
2U: 3.5N±0.5N (350 grams±100 grams); 4U: 5N±1N (500 grams±100 grams); 6U: 6.5N±1N (650 grams±100 grams); 8U: 9.0N±1N (900 grams±100 grams).

OPERATING TEMPERATURE RANGE: -40°C to 70°C.

## Materials

HOUSING: Polycarbonate UL 94V-0 or polyester UL 94V-0.

ACTUATOR: Polyester UL 94V-0.

MOVABLE CONTACTS: Bimetal brass, silver plated, gold plate over nickel.

STATIONARY CONTACTS & TERMINALS: Brass, silver plated, gold plated.

TERMINAL BOARD: Polyester UL 94V-0.

RETURN SPRING: Music wire.

TERMINAL SEAL: RTV adhesive sealant.

CHASSIS: Steel.

LOCKOUT PIN: Steel.


BLOCKERS: Steel.

## Build-A-Switch

To order, simply select desired option from each category and place in the appropriate box. Available options are shown and described on pages A-88 thru A-95. For additional options not shown in catalog, consult Customer Service Center.

If requesting only a switch, select either a North American or European switch as noted below. Chassis and buttons are sold separately. If multiple stations are selected, we will assume all switches are the same unless noted otherwise.

## North American Order Code - Switch Only

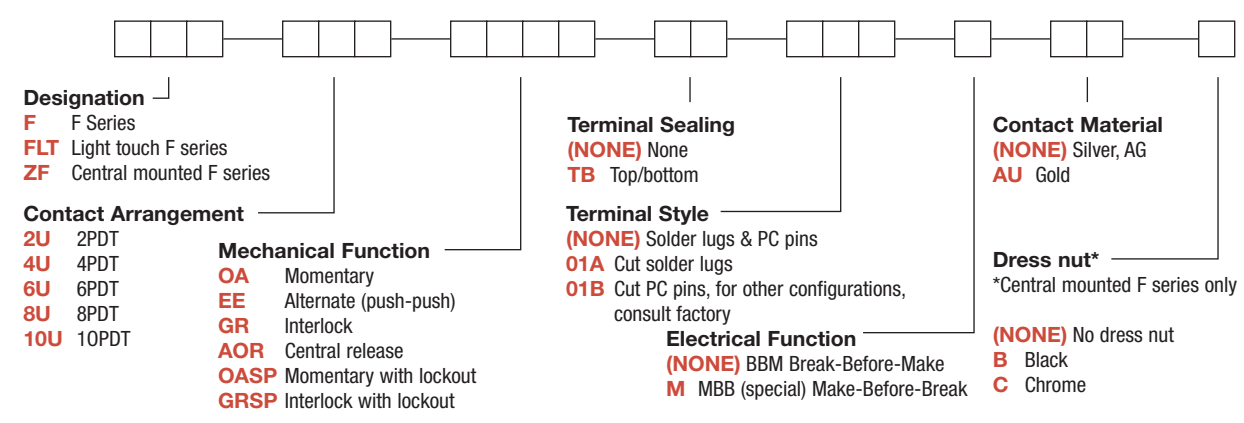

Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change




A

Pushbutton

## F Series Pushbutton Switches


### European Order Code - Switch Only

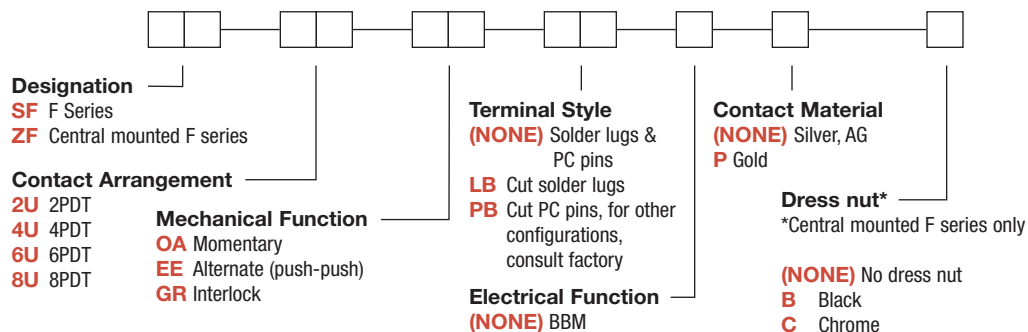


\*Minimum order quantities apply.

### Order Code - Buttons

#### Solid Buttons

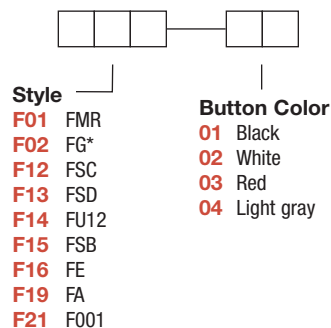

#### Mechanical Indicator Buttons

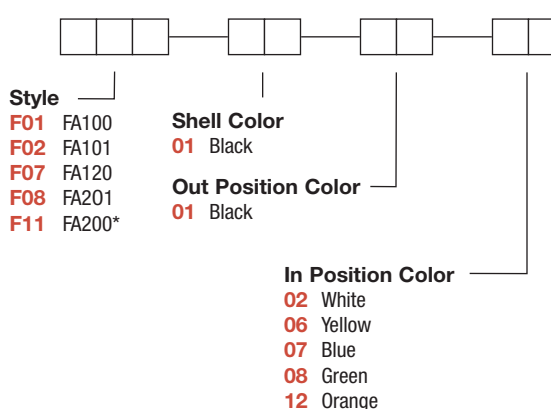

\*Button options for central mounting configurations, use 'FG' for central mount with chrome dress nut, use 'FA200' for central mount with black dress nut.


### BUTTON REMOVAL

A button of a push-push switch should only be removed in the "OFF" non-latching position.

### Order Code - Chassis

To order a switch with chassis, create the switch part number listed above and add the Chassis part number configurator information at the end of the part number.

Note: We do not guarantee or recommend interlocking beyond 10 stations.

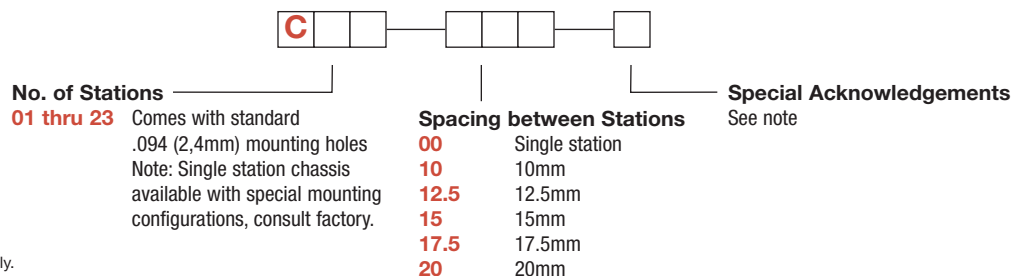

\*Minimum order quantities apply.



Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change

# F Series Pushbutton Switches




A

Pushbutton

## SWITCHES WITH STANDARD OPTIONS


### F2UEE

| CONTACT<br>ARRANGEMENT | LENGTH<br>DIM 'L' |
|------------------------|-------------------|
| 2U                     | 0.827 (21,00)     |
| 4U                     | 1.300 (33,00)     |
| 6U                     | 1.770 (45,00)     |
| 8U                     | 2.240 (57,00)     |
| 10U                    | 2.720 (69,00)     |

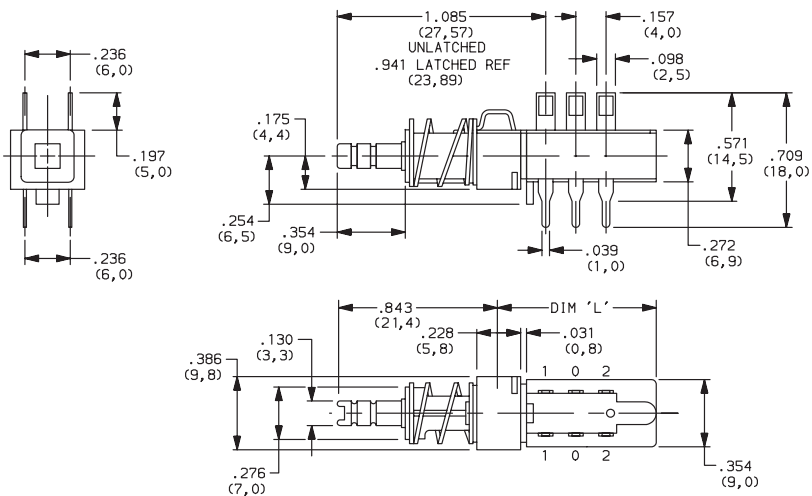

### ZF2UEEBF11010108

| CONTACT<br>ARRANGEMENT | LENGTH<br>DIM 'L' |
|------------------------|-------------------|
| 2U                     | 0.827 (21,00)     |
| 4U                     | 1.300 (33,00)     |
| 6U                     | 1.770 (45,00)     |
| 8U                     | 2.240 (57,00)     |
| 10U                    | 2.720 (69,00)     |

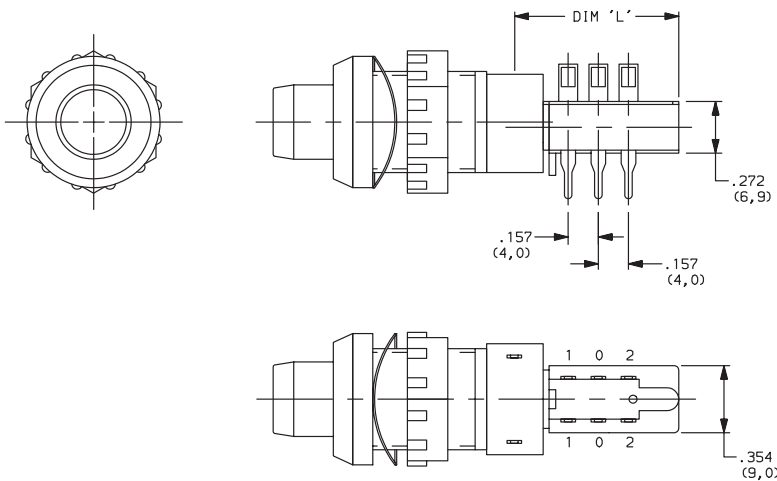

## DESIGNATION

 


### Designation, North America

- F** F Series
- FLT** Light touch F series
- ZF** Central mounted F series

### Designation, Europe

- SF** F Series
- ZF** Central mounted F series



Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change



# F Series Pushbutton Switches

A


Pushbutton

## CONTACT ARRANGEMENT



| OPTION CODE | NO. OF POLES | SCHEMATIC |
|-------------|--------------|-----------|
| <b>2U</b>   | 2PDT         |           |
| <b>4U</b>   | 4PDT         | 2X        |
| <b>6U</b>   | 6PDT         | 3X        |
| <b>8U</b>   | 8PDT         | 4X        |
| <b>10U</b>  | 10PDT        | 5X        |

### PC MOUNTING

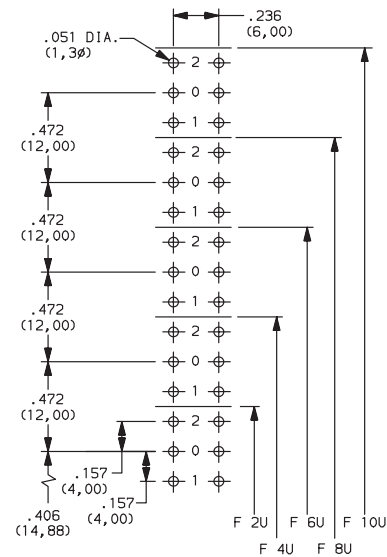

## MECHANICAL FUNCTION



### North America

| OPTION CODE | FUNCTION               |
|-------------|------------------------|
| <b>OA</b>   | Momentary              |
| <b>EE</b>   | Alternate (push-push)  |
| <b>GR</b>   | Interlock              |
| <b>AOR</b>  | Central release        |
| <b>OASP</b> | Momentary with lockout |
| <b>GRSP</b> | Interlock with lockout |


### Europe

| OPTION CODE | FUNCTION              |
|-------------|-----------------------|
| <b>OA</b>   | Momentary             |
| <b>EE</b>   | Alternate (push-push) |
| <b>GR</b>   | Interlock             |

## TERMINAL SEALING




**(NONE)** NO SEAL

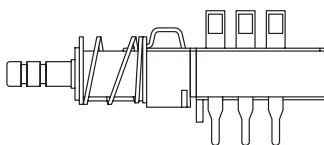

F2UEE shown in example above.

**TB** TOP & BOTTOM

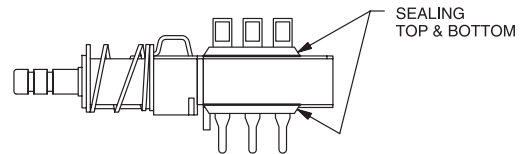

**NOTE:** Available for North America only

**C&K**



Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change

[www.ckswitches.com](http://www.ckswitches.com)

# F Series Pushbutton Switches




A

Pushbutton


## TERMINAL STYLE




**(NONE)** SOLDER LUGS & PC PINS

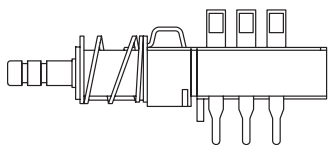

**01A** CUT SOLDER LUGS (North America)  
**LB** CUT SOLDER LUGS (Europe)

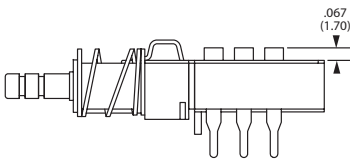

**01B** CUT PC PINS (North America)  
**PB** CUT PC PINS (Europe)

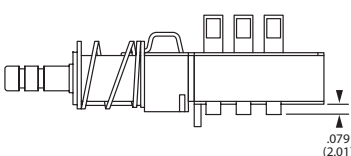

## ELECTRICAL FUNCTION



| OPTION CODE   | FUNCTION                          |
|---------------|-----------------------------------|
| <b>(NONE)</b> | BBM Non-shorting                  |
| <b>M</b>      | MBB Shorting (North America only) |

## CONTACT MATERIAL



| NORTH AMERICA<br>OPTION CODE | EUROPE<br>OPTION CODE | RoHS<br>COMPLIANT * | RoHS<br>COMPATIBLE * | MATERIAL   | RATING                             |
|------------------------------|-----------------------|---------------------|----------------------|------------|------------------------------------|
| <b>(NONE)</b>                | <b>(NONE)</b>         | YES                 | YES                  | SILVER, AG | 50 VA/15 W; 125/30 V; 0.5/0.5 A    |
| <b>AU</b>                    | <b>P</b>              | YES                 | YES                  | GOLD       | 1 VA/300mW; 50/30 V; 0.04 A/0.01 A |


\* Note: See Technical Data section of this catalog for RoHS compliant and compatible definitions and specifications.

## DRESS NUT




**(NONE)** NO DRESS NUT FOR F & F/LT  
DESIGNATIONS

**B** BLACK

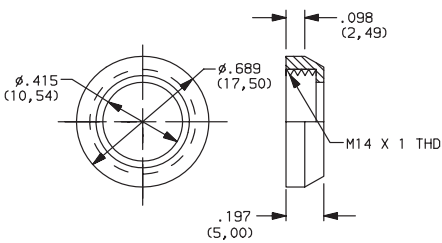


### PANEL CUTOUT

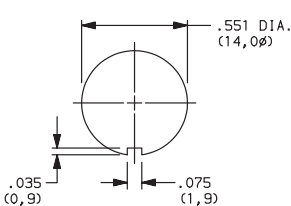


NOTE: Available with ZF designation and FA200 buttons.


**C** CHROME

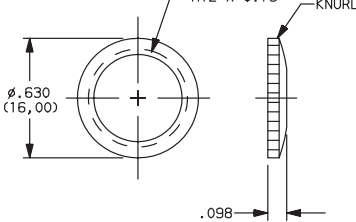

### PANEL CUTOUT

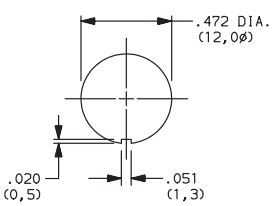

 NOTE: Available with ZF designation and  
FG button.



Third Angle  
Projection

**C&K**

Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change



# F Series Pushbutton Switches

A


Pushbutton

SOLID BUTTON





## STYLE



**F01** FMR

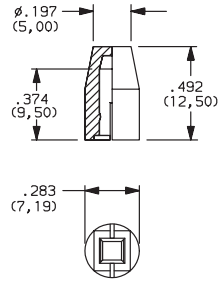



**F02** FG

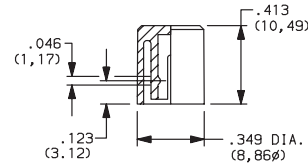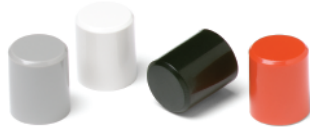



**F12** FSC

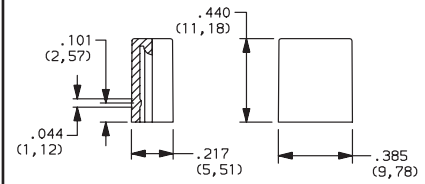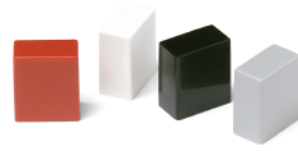


**F13** FSD

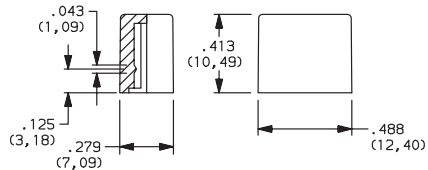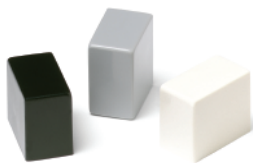


**F14** FU12

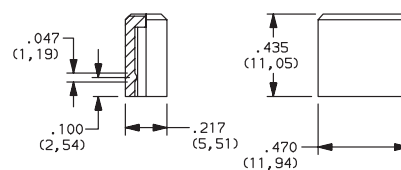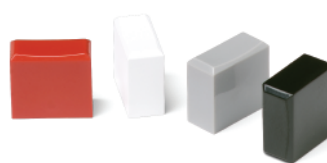


**F15** FSB

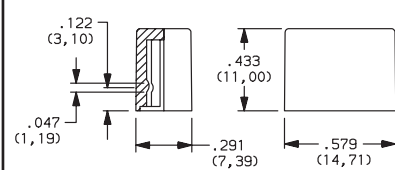


**F16** FE

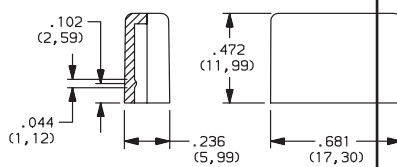

**F19** FA

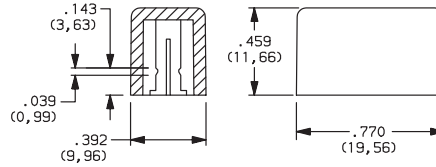

**F21** F001

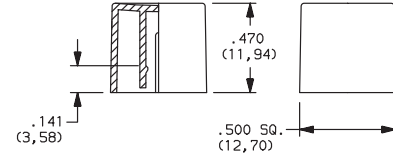

| OPTION CODE | COLOR    |
|-------------|----------|
| 01          | BLACK    |
| 02          | WHITE    |
| 03          | RED      |
| 04          | LT. GRAY |


**C&K**

 Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change

# F Series Pushbutton Switches




## MECHANICAL BUTTON




### STYLE


**F01** FA100

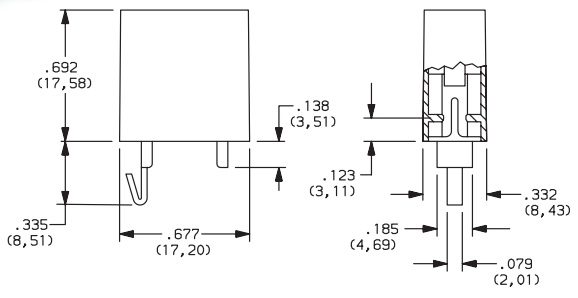


**F02** FA101

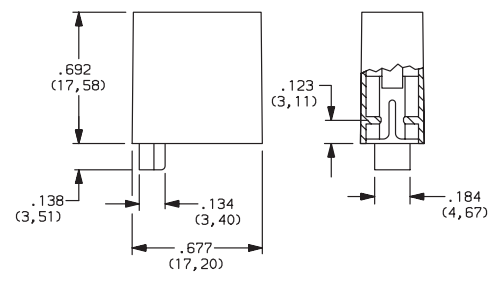


**F07** FA120

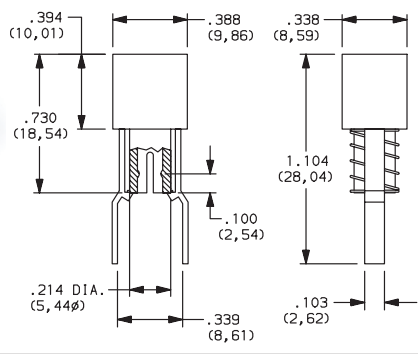

**F08** FA201

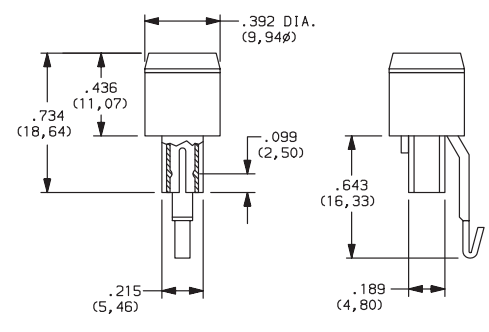

**F11** FA200

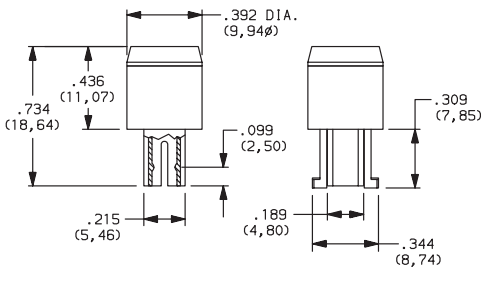

### SHELL COLOR

**01** BLACK

### OUT POSITION COLOR

**01** BLACK

### IN POSITION COLOR

| OPTION CODE | COLOR  |
|-------------|--------|
| <b>02</b>   | WHITE  |
| <b>06</b>   | YELLOW |
| <b>07</b>   | BLUE   |
| <b>08</b>   | GREEN  |
| <b>12</b>   | ORANGE |



Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change

 


# F Series Pushbutton Switches

A

Pushbutton

CHASSIS




## NUMBER OF STATIONS

**C00 Thru C10** Comes with standard 0.094 (2,44mm) mounting holes


**NOTE:** Single station chassis available with mounting configurations, consult factory.

## SPACING

**00** SINGLE STATION

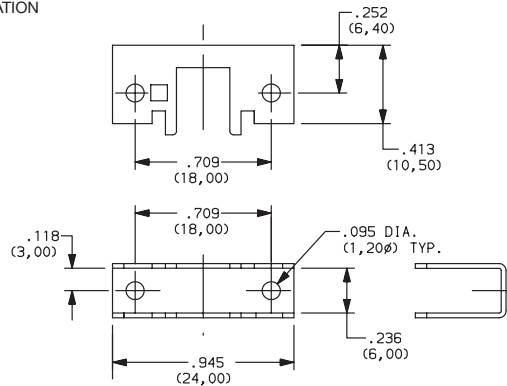


**10** 10mm

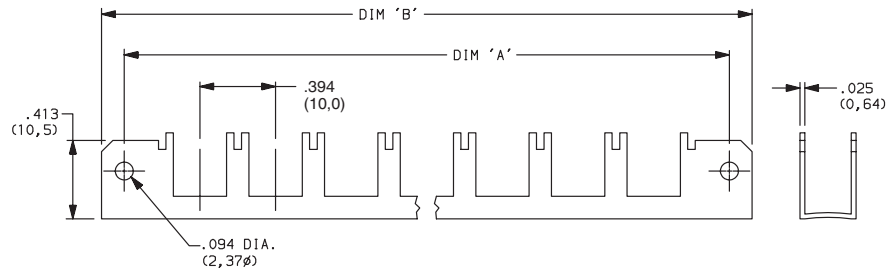

| No. of Stations | Dim. 'A'          | Dim. 'B'          | Tolerance |
|-----------------|-------------------|-------------------|-----------|
| 2               | 1.182<br>(30,02)  | 1.418<br>(36,02)  | 0.005     |
| 3               | 1.575<br>(40,01)  | 1.811<br>(46,00)  | 0.010     |
| 4               | 1.969<br>(50,01)  | 2.205<br>(56,01)  | 0.010     |
| 5               | 2.363<br>(60,02)  | 2.599<br>(66,01)  | 0.010     |
| 6               | 2.757<br>(70,03)  | 2.993<br>(76,02)  | 0.015     |
| 7               | 3.150<br>(80,01)  | 3.386<br>(86,00)  | 0.015     |
| 8               | 3.544<br>(90,02)  | 3.780<br>(96,01)  | 0.015     |
| 9               | 3.938<br>(100,03) | 4.174<br>(106,02) | 0.015     |
| 10              | 4.331<br>(110,01) | 4.567<br>(116,00) | 0.015     |

**12.5** 12.5mm

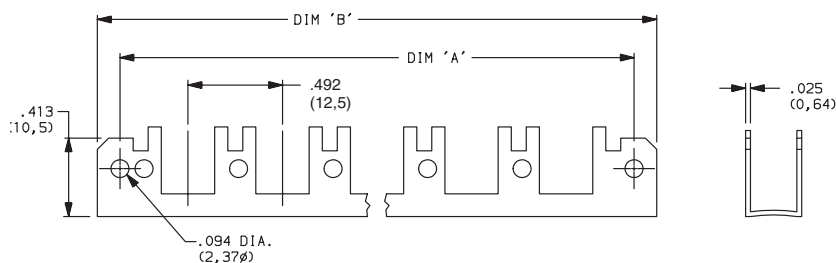

| No. of Stations | Dim. 'A'          | Dim. 'B'          | Tolerance |
|-----------------|-------------------|-------------------|-----------|
| 2               | 1.200<br>(30,48)  | 1.436<br>(36,47)  | 0.005     |
| 3               | 1.692<br>(42,98)  | 1.928<br>(48,97)  | 0.010     |
| 4               | 2.184<br>(55,47)  | 2.420<br>(61,47)  | 0.010     |
| 5               | 2.676<br>(67,97)  | 2.912<br>(73,96)  | 0.010     |
| 6               | 3.169<br>(80,49)  | 3.405<br>(86,49)  | 0.015     |
| 7               | 3.661<br>(92,99)  | 3.897<br>(98,98)  | 0.015     |
| 8               | 4.153<br>(105,49) | 4.389<br>(111,48) | 0.015     |
| 9               | 4.645<br>(117,98) | 4.881<br>(123,98) | 0.015     |
| 10              | 5.137<br>(130,48) | 5.373<br>(136,47) | 0.015     |



Third Angle  
Projection

**C&K**

Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change

 
# F Series Pushbutton Switches



A

Pushbutton


CHASSIS



## SPACING


**15** 15mm

| No. of Stations | Dim. 'A'          | Dim. 'B'          | Tolerance |
|-----------------|-------------------|-------------------|-----------|
| 2               | 1.374<br>(34,90)  | 1.615<br>(41,02)  | 0.005     |
| 3               | 1.969<br>(50,01)  | 2.205<br>(56,01)  | 0.010     |
| 4               | 2.560<br>(65,02)  | 2.796<br>(71,02)  | 0.010     |
| 5               | 3.150<br>(80,01)  | 3.386<br>(86,00)  | 0.010     |
| 6               | 3.741<br>(95,02)  | 3.977<br>(101,02) | 0.015     |
| 7               | 4.332<br>(110,03) | 4.568<br>(116,03) | 0.015     |
| 8               | 4.922<br>(125,02) | 5.158<br>(131,01) | 0.015     |
| 9               | 5.513<br>(140,03) | 5.749<br>(146,02) | 0.015     |
| 10              | 6.103<br>(155,02) | 6.339<br>(161,01) | 0.015     |

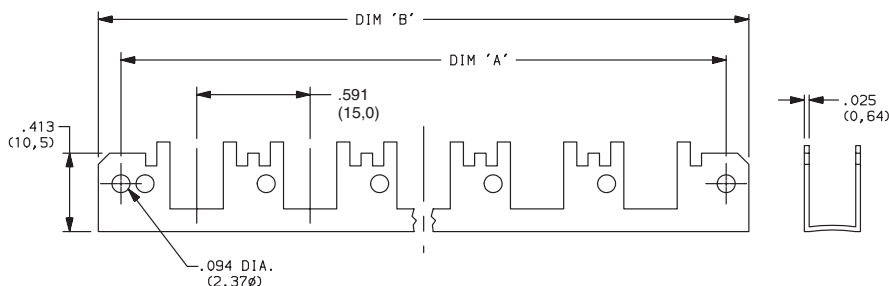


**17.5** 17.5mm

| No. of Stations | Dim. 'A'          | Dim. 'B'          | Tolerance |
|-----------------|-------------------|-------------------|-----------|
| 2               | 1.477<br>(37,52)  | 1.713<br>(43,51)  | 0.005     |
| 3               | 2.166<br>(55,02)  | 2.402<br>(61,01)  | 0.010     |
| 4               | 2.855<br>(75,52)  | 3.091<br>(78,51)  | 0.010     |
| 5               | 3.544<br>(90,02)  | 3.780<br>(96,01)  | 0.010     |
| 6               | 4.233<br>(107,52) | 4.469<br>(113,51) | 0.015     |
| 7               | 4.922<br>(125,02) | 5.158<br>(131,01) | 0.015     |
| 8               | 5.611<br>(142,52) | 5.847<br>(148,51) | 0.015     |
| 9               | 6.300<br>(160,02) | 6.536<br>(166,01) | 0.015     |
| 10              | 6.989<br>(177,52) | 7.225<br>(183,52) | 0.015     |

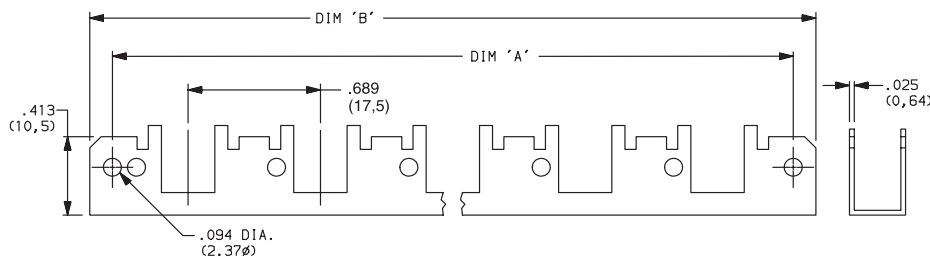

**20** 20mm

| No. of Stations | Dim. 'A'          | Dim. 'B'          | Tolerance |
|-----------------|-------------------|-------------------|-----------|
| 2               | 1.575<br>(40,01)  | 1.811<br>(46,00)  | 0.005     |
| 3               | 2.363<br>(60,02)  | 2.599<br>(66,01)  | 0.010     |
| 4               | 3.150<br>(80,01)  | 3.386<br>(86,00)  | 0.010     |
| 5               | 3.938<br>(100,03) | 4.174<br>(106,02) | 0.010     |
| 6               | 4.725<br>(120,02) | 4.961<br>(126,01) | 0.015     |
| 7               | 5.512<br>(140,00) | 5.748<br>(146,00) | 0.015     |
| 8               | 6.300<br>(160,02) | 6.536<br>(166,01) | 0.015     |
| 9               | 7.087<br>(180,01) | 7.323<br>(186,00) | 0.015     |
| 10              | 7.875<br>(200,03) | 8.111<br>(206,02) | 0.015     |

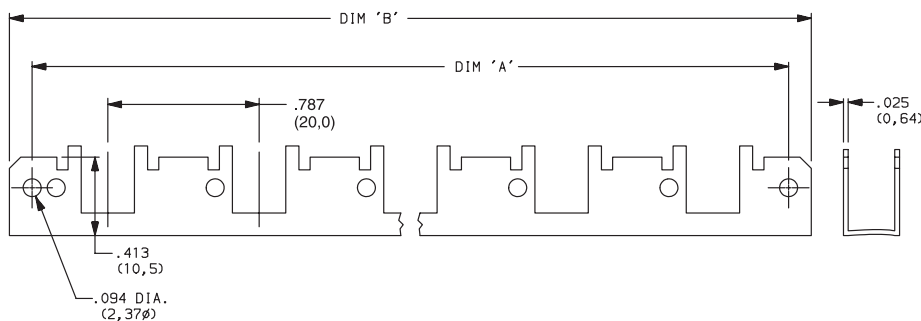

Third Angle  
Projection

**C&K**

Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## C&K Components:

[F4UEE](#) [FLT2UEETB](#) [F6UEETB](#) [F6UEEAU](#) [F8UOA](#) [F8UEETB](#) [F6UEE](#) [F2UEETB01A](#) [F10UEE](#) [F2UOATBAU](#)  
[F2UOATB01AAU](#) [F2UOASP](#) [F2UOASPTB](#)

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## C&K Switches:

[1XSFFMRBK2UPEE](#) [CH 6XF15](#) [CH 7XF10](#) [CH4XF10](#) [1XSF2UEE](#) [CH5XF15](#) [CH4XF15](#) [1XSF4UEE](#) [1XSF 6U EE](#)  
[CH 5XF20](#) [CHAS F5X10 W.126 FRT&BTM](#) [1XSFFSCRD2UEE](#) [CH 6XF20](#) [CH8XF15](#) [1XSF6UEE](#) [CHAS F5X10](#)  
[W/.126 FRT&BTM](#) [109-9300-009](#) [1XSFFGBK4UPOA](#)