


# CA Series Power Rocker Switches

## Features/Benefits

- 15 AMPS @ 125 V AC
- Cosmetic slimline detail
- Positive detent

## Typical Applications

- Hair dryers and other small appliances
- HVAC and other large appliances
- RoHS compliant

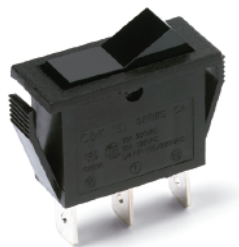

## Specifications

CONTACT RATING: 15 AMPS @ 125 V AC;  
10 AMPS @ 250 V AC;  
1/4 HP @ 125 V AC or 250 V AC

ELECTRICAL LIFE: 10,000 make-and-break cycles at full load.

INSULATION RESISTANCE:  $10^9 \Omega$  min.

DIELECTRIC STRENGTH: 1,000 Vrms min. @ sea level.

OPERATING TEMPERATURE: -30°C to +65°C

## Materials

HOUSING: 6/6 nylon (UL 94V-2), black.

ACTUATOR: Polycarbonate (UL 94V-2), black.

CONTACTS: Coin silver, silver plated.

TERMINALS: Copper, silver plated.

CONTACT SPRING: Music wire.

**NOTE:** Specifications and material listed above are for switches with standard options. For information on specific and custom switches, consult Customer Service Center.

## Build-A-Switch

To order, simply select desired option from each category and place in the appropriate box. Available options are shown and described on pages G-106 through G-108. For additional options not shown in catalog, consult Customer Service Center.

<b>Switch Function</b> CA01 SPDT, On-On CA02 SPST, On-Off CA21 DPDT, On-On CA22 DPST, On-Off	<b>Actuator</b> J1 Rocker with gloss finish J7 Curved rocker with matte finish	<b>Actuator Color</b> 2 Black 1 White 3 Red 6 Green	<b>Housing Color</b> 2 Black	<b>Terminations</b> 07 Quick connect	<b>Actuator Markings</b> NONE No marking D ON-OFF H 0 I P 0 -	<b>Contact Material</b> Q Silver
--	--	---	---------------------------------	---	---	-------------------------------------

Rocker



G

C&K



Dimensions are shown: Inches (mm)

Specifications and dimensions subject to change

[www.ck-components.com](http://www.ck-components.com)

 


CA Series  
Power Rocker Switches

SWITCH FUNCTION

NO. POLES	MODEL NO.	SWITCH FUNCTION		CONNECTED TERMINALS		SCHEMATIC
		POS. 1	POS. 2	POS. 1	POS. 2	
SP	CA01	ON	ON	1-1A	1-1B	SPDT
	CA02	ON	OFF	1-1A	OPEN	SPST
<div><div><p><b>SPST</b></p></div><div><p>ACTUATOR SHOWN IN POS. 1</p></div><div><p>TERMINAL NOS. MARKED ON HOUSING</p></div></div> <p>Part number shown: CA02J12207Q</p>						
DP	CA21	ON	ON	1-1A, 2-2A	1-1B, 2-2B	DPDT
	CA22	ON	OFF	1-1A, 2-2A	OPEN	DPST
<div><div><p><b>DPDT</b></p></div><div><p>ACTUATOR SHOWN IN POS. 1</p></div><div><p>TERMINAL NOS. MARKED ON HOUSING</p></div></div> <p>Part number shown: CA21J12207Q</p>						

For complete contact ratings and agency approvals, see CONTACT MATERIAL section, page G-108.  
Contacts make on side opposite actuator thrown.  
All models with all options.



Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change

www.ck-components.com

Rocker




G




# CA Series Power Rocker Switches

## ACTUATOR

### J1 ROCKER WITH GLOSS FINISH

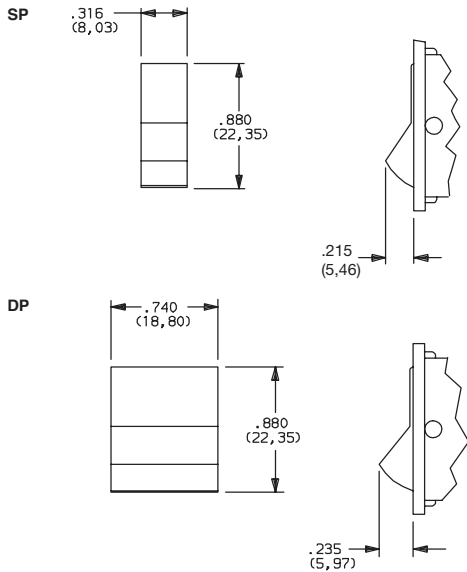

### J7 CURVED ROCKER WITH MATTE FINISH

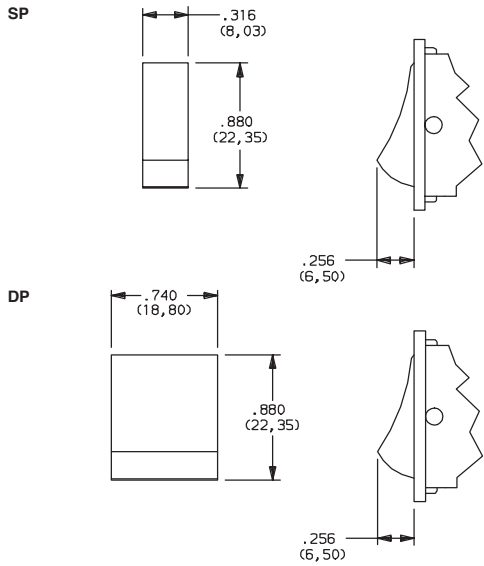

## ACTUATOR COLOR

OPTION CODE	OPAQUE ACTUATOR COLOR
1	WHITE
2	BLACK
3	RED
6	GREEN

**NOTE:** Actuator finish: matte. Special colors available, consult Customer Service Center.

## HOUSING COLOR

OPTION CODE	HOUSING COLOR
2	BLACK

**NOTE:** Housing frame finish: matte.

Rocker



G

**C&K**



Third Angle  
Projection

Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change


[www.ck-components.com](http://www.ck-components.com)



# CA Series Power Rocker Switches


## TERMINATIONS

### 07 QUICK CONNECT

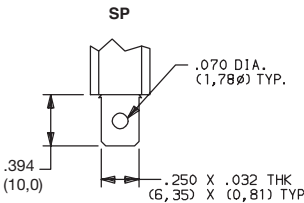

### PANEL MOUNTING

J1, & J7 only

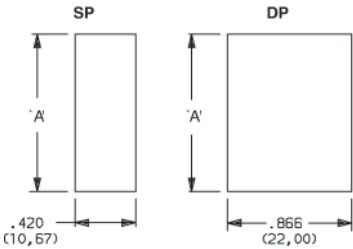


PANEL THICKNESS	DIM 'A'
.059-.078 (1,50) (2,00)	1.102 (28,00)
.078-.118 (2,00) (3,00)	1.110 (28,20)
.118-.177 (3,00) (4,50)	1.126 (28,60)

## ACTUATOR MARKINGS

 
### NONE NO MARKING





### D ON-OFF



### H O |

 

### P O -

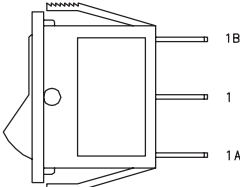 

Marking color white, standard for all actuator colors except white and yellow. Marking color black, standard for white and yellow actuators. Consult Customer Service Center for other available markings and colors.

**NOTE:** Orientation of actuator markings and terminals

## CONTACT MATERIAL

 
OPTION CODE	CONTACT AND TERMINAL MATERIAL	RATINGS	
Q	SILVER <sup>1</sup>	POWER	10 AMPS @ 250 VAC 15 AMPS @ 125 VAC 1/4 HP 125/250 VAC



\* Note: See Technical Data section of this catalog for RoHS compliant and compatible definitions and specifications.

<sup>1</sup> CONTACTS: Coin silver, silver plated.  
TERMINALS: Copper, silver plated.

All models with all options.



Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change

[www.ck-components.com](http://www.ck-components.com)

Rocker



G



# CA Series Illuminated Power Rocker Switches

### Features/Benefits

- 15 AMPS @ 125 V AC
- Illuminated actuator
- Various actuator styles

### Typical Applications

- Power outlet strips
- Appliances
- Handling and packaging machines
- RoHS compliant



### Specifications

CONTACT RATING: 15 AMPS @ 125 V AC; 10 AMPS @ 250 V AC; 1/4 HP @ 125 V AC or 250 V AC.

ELECTRICAL LIFE: 10,000 make-and-break cycles at full load.

LAMP LIFE: 20,000 hours typ.

INSULATION RESISTANCE:  $10^9 \Omega$  min.

DIELECTRIC STRENGTH: 1,000 Vrms min. @ sea level.

### Materials

HOUSING: 6/6 nylon (UL 94V-2), black.

ACTUATOR: Polycarbonate (UL 94V-2), red.

CONTACTS: Coin silver, silver plated.

OPERATING TEMPERATURE: -30°C to +65°C

**NOTE:** Specifications and materials listed above are for switches with standard options. For information on specific and custom switches, consult Customer Service Center.

### Build-A-Switch

To order, simply select desired option from each category and place in the appropriate box. Available options are shown and described on pages G-103 through G-105. For additional options not shown in catalog, consult Customer Service Center.

<div>Switch Function</div> <div>CA04 SPST, On-Off</div> <div>CA24 DPST, On-Off</div>	<div>Actuator</div> <div>J1 Rocker</div> <div>J7 Curved rocker</div>	<div>Actuator Color</div> <div>3 Red translucent</div> <div>5 Yellow translucent</div> <div>6 Green translucent</div>	<div>Lamp Voltage</div> <div>7 125 V neon</div> <div>8 250 V neon</div>	<div>Housing Color</div> <div>2 Black</div> <div>1 White</div>	<div>Terminations</div> <div>07 Quick connect</div>	<div>Actuator Markings</div> <div>NONE No markings</div> <div>D ON-OFF</div> <div>H 0 I</div> <div>P 0 -</div>	<div>Contact Material</div> <div>Q Silver</div>
--	--	---	---	--	---	--	---

Rocker



G

C&K



Third Angle  
Projection

Dimensions are shown: Inches (mm)

Specifications and dimensions subject to change

[www.ck-components.com](http://www.ck-components.com)



# CA Series Illuminated Power Rocker Switches

## SWITCH FUNCTION



NO. POLES	MODEL NO.	SWITCH FUNCTION		CONNECTED TERMINALS		SCHEMATIC
		POS. 1	POS. 2	POS. 1	POS. 2	
SP	<b>CA04</b>	ON	OFF	1-1A	OPEN	<p>SPST</p>
<p><b>SPST</b></p> <p>ACTUATOR SHOWN IN POS. 1 - 'ON' POSITION</p> <p>TERMINAL NOS. MARKED ON HOUSING</p> <p>Part number shown: CA04J137207Q</p>						
DP	<b>CA24</b>	ON	OFF	1-1A, 2-2A	OPEN	<p>DPST</p>
<p><b>DPST</b></p> <p>ACTUATOR SHOWN IN POS. 1 - 'ON' POSITION</p> <p>TERMINAL NOS. MARKED ON HOUSING</p> <p>Part number shown: CA24J137207Q</p>						

See CONTACT MATERIAL section, page G-105, for complete contact ratings and agency approvals.  
Contacts make on side opposite actuator thrown.


All models with all options.




# CA Series Illuminated Power Rocker Switches

## ACTUATOR

**J1**   ROCKER

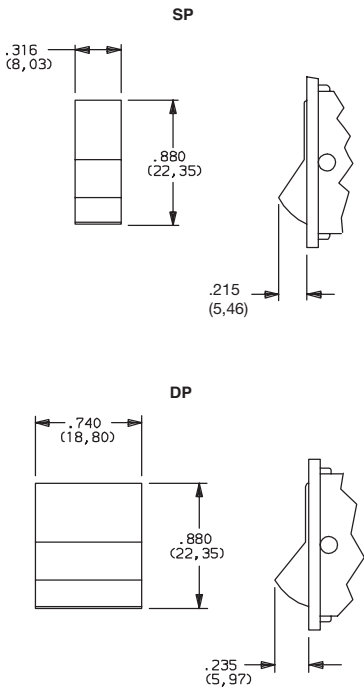

**J7**   CURVED ROCKER

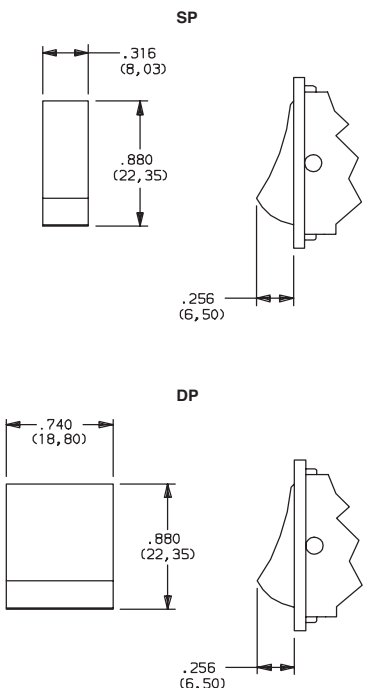

## ACTUATOR COLOR

OPTION CODE	ACTUATOR COLOR
3	RED TRANSLUCENT
5	YELLOW
6	GREEN

**NOTE:** Special colors available, consult Customer Service Center.

## NEON LAMP VOLTAGE

- 7 125 V NEON
- 8 250 V NEON

## HOUSING COLOR

OPTION CODE	HOUSING COLOR
2	BLACK
1	WHITE

**NOTE:** Housing frame finish: matte. Special colors available, consult Customer Service Center.



Dimensions are shown: Inches (mm)  
Specifications and dimensions subject to change

[www.ck-components.com](http://www.ck-components.com)

Rocker



G



**C&K**




# CA Series Illuminated Power Rocker Switches

## TERMINATIONS

### 07 QUICK CONNECT

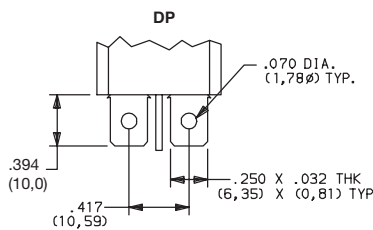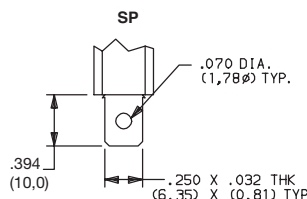

### PANEL MOUNTING

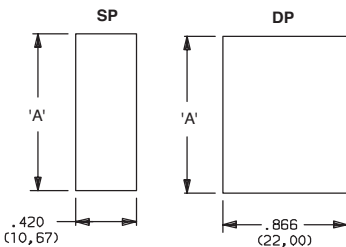


PANEL THICKNESS	DIM 'A'
.059-.078 (1,50) (2,00)	1.102 (28,00)
.078-.118 (2,00) (3,00)	1.110 (28,20)
.118-.177 (3,00) (4,50)	1.126 (28,60)

## ACTUATOR MARKINGS
 
### NONE NO MARKING




### D ON-OFF



### H O I



### P O -

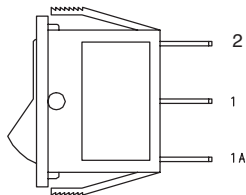

Marking color white, standard for all actuator colors except yellow. Marking color black, standard for yellow actuators. Consult Customer Service Center for other available markings and colors.

**NOTE:** Orientation of actuator markings and terminals

## CONTACT MATERIAL

OPTION CODE	CONTACT AND TERMINAL MATERIAL	RATINGS	
		POWER	
<b>Q</b>	SILVER <sup>1</sup>	10 AMPS @ 250 VAC 15 AMPS @ 125 VAC 1/4 HP 125/250 VAC	<b>C&amp;K</b> US

\* Note: See Technical Data section of this catalog for RoHS compliant and compatible definitions and specifications.

<sup>1</sup> CONTACTS: Coin silver, silver plated.  
TERMINALS: Copper, silver plated.

All models **C&K** US with all options.



# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

## C&K Switches:

[CA02J72207PQ](#) [CA24J137207Q](#) [CA22J76207PQ](#) [CA04J157207PQ](#) [CA22J72207HQ](#) [CA22J72207Q](#)  
[CA22J73207HQ](#) [CA02J72207DQ](#) [CA21J11207Q](#) [CA22J73207PQ](#) [CA24J737207Q](#) [CA04J138207Q](#) [CA01J11207Q](#)  
[CA01J12207HQ](#) [CA01J12207PQ](#) [CA01J12207Q](#) [CA01J13207Q](#) [CA01J16207Q](#) [CA02J11207Q](#) [CA02J12207DQ](#)  
[CA02J12207HQ](#) [CA02J12207PQ](#) [CA02J12207Q](#) [CA02J13207Q](#) [CA02J76207DQ](#) [CA04J137107DQ](#)  
[CA04J137207PQ](#) [CA04J137207Q](#) [CA04J138207PQ](#) [CA04J157207Q](#) [CA04J167207PQ](#) [CA04J167207Q](#)  
[CA04J168207PQ](#) [CA04J168207Q](#) [CA04J737207PQ](#) [CA21J12207PQ](#) [CA21J12207Q](#) [CA21J72207PQ](#)  
[CA21J73207PQ](#) [CA22J12207DQ](#) [CA22J12207HQ](#) [CA22J12207PQ](#) [CA22J12207Q](#) [CA22J72207PQ](#)  
[CA22J73207DQ](#) [CA24J137207DQ](#) [CA24J137207HQ](#) [CA24J137207PQ](#) [CA24J138207PQ](#) [CA24J138207Q](#)  
[CA24J167207DQ](#) [CA24J167207Q](#) [CA24J168207PQ](#) [CA24J168207Q](#) [CA24J767107Q](#) [CA24J768207PQ](#)  
[CA04J738207PQ](#) [CA24J167207PQ](#) [CA24J737207PQ](#) [CA24J767207DQ](#) [CA04J138207DQ](#)