 
 



Contents

Package style 		V_{RRM}	I_{dAVM}	Type	Page
		V	A		
1  2 	1	1400	1.0	VGB 0124 AY7	F7 - 2
	2	2800	1.5	VGF 0136 AB	
	3	1400	1.1	VGF 0136 AH	

Braking Rectifier Assemblies


Typ	Typical			Max.			
	V_{VRMS} V	V_{dAV} V	I_{dAVM} A	I_{dAVM} A	V_{RRM} V	I_{FSM} A	I^2t A ² s
VGB 0124 AY7	380	340	1.0	1.0	1400	60	28

VGB0124 AY7

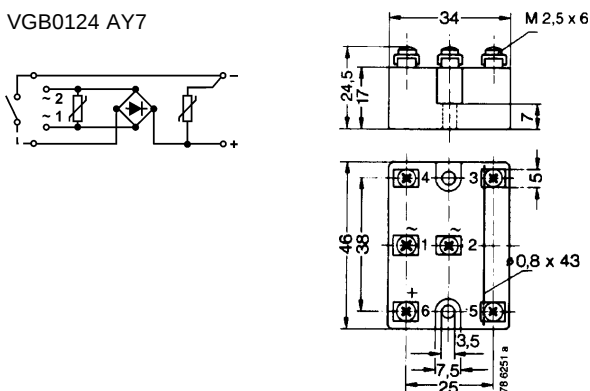


Typ	Typical			Max.			
	V_{VRMS} V	V_{dAV} V	I_{dAVM} A	I_{dAVM} A	V_{RRM} V	I_{FSM} A	I^2t A ² s
VGF 0136 AB	1000	440	1.2	1.5	2800	80	40
VGF 0136 AH	1000	440	0.6	1.1	1400	60	28

VGF 0136 AB

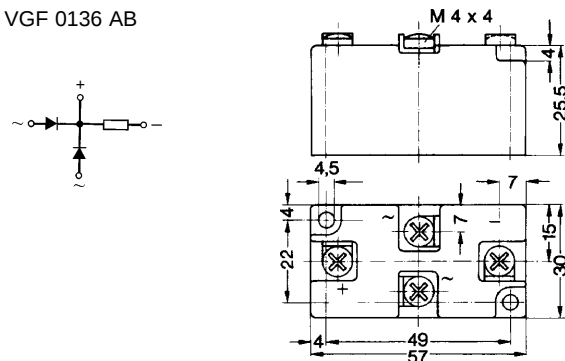

VGF 0136 AH

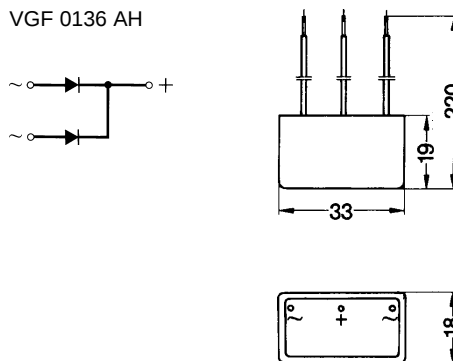

Data according to IEC 60747
IXYS reserves the right to change limits, test conditions and dimensions

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[IXYS:](#)

[VGF0136AB](#)