



Features/Benefits

- ***RoHS compliant and meets all requirements of RoHS directive 2002/95EC, Halogen Free***
- ***Positive detent***
- ***Low profile***
- ***IR reflow to 260° solder profile***
- ***Surface and thru hole mounting***
- ***Maintained and momentary functions***
- ***SP3T model***

Typical Applications

- **Telecommunication products**
- **Computer peripherals**
- **Thermostat select switch**
- **Instrumentations**



Specifications

CONTACT RATING: 4 VDC @ 0.3A
ELECTRICAL LIFE: 10,000 make-and-break cycles at full load.
CONTACT RESISTANCE: 70 m Ω max.
INSULATION RESISTANCE: 100 M Ω min. @ 500V.
DIELECTRIC STRENGTH: 100 VAC min. @ sea level.
OPERATING TEMPERATURE: -10°C to +60°C
STORAGE TEMPERATURE: -30°C to +85°C


NOTE: Specifications and materials listed above are for switches with standard options. For information on specific and custom switches, consult Customer Service Center.

Materials


HOUSING: LCP, Glass filled (Halogen free)
ACTUATOR: 4/6 nylon (UL94V-2), black.
CONTACTS: Beryllium copper, silver plated.
TERMINALS: Brass, silver plated.
COVER: Stainless steel
RETURN SPRING: Stainless steel




Slide

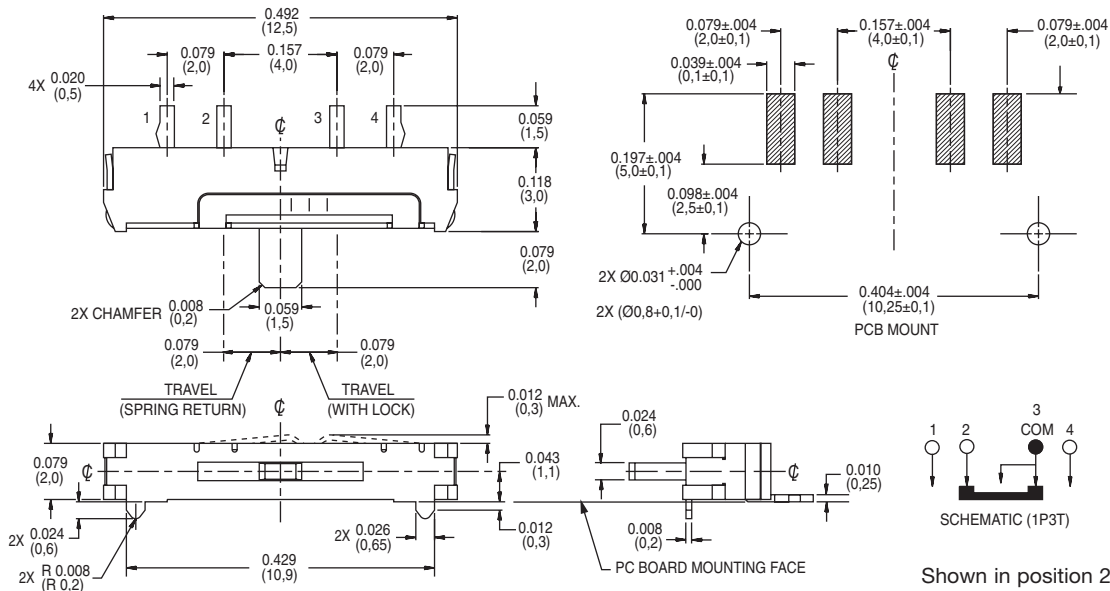

JSM07011SAQNR
SP3T Surface Mount
Momentary one side
& Maintained the other

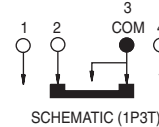



Shown in position 2

 




Dimensions are shown: Inches (mm)
Specifications and dimensions subject to change

JSM Series




Sub-Miniature Slide Switches

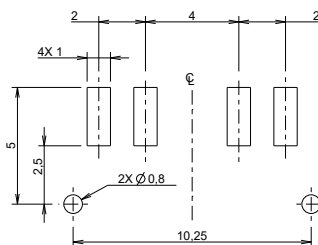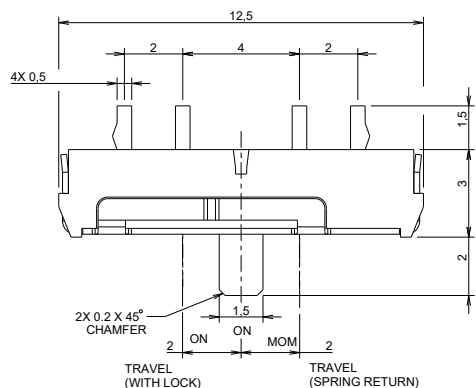

JSM07011SAQNL
SP3T Surface Mount
Momentary one side
& Maintained the other

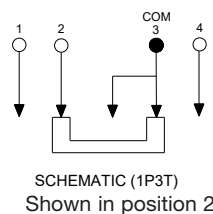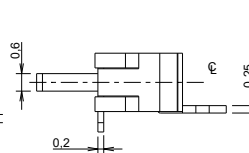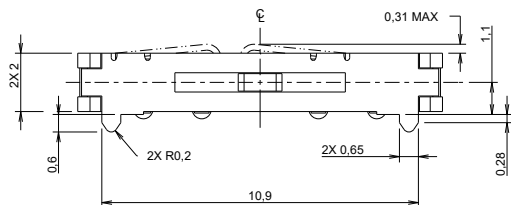

Packaging for JSM07011SAQNR and JSM07011SAQNL

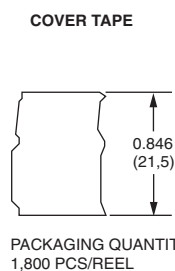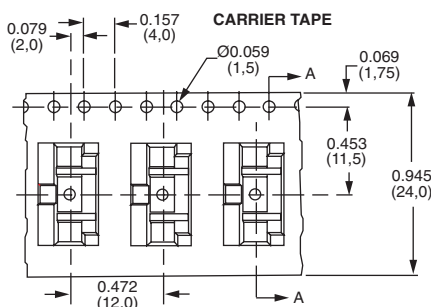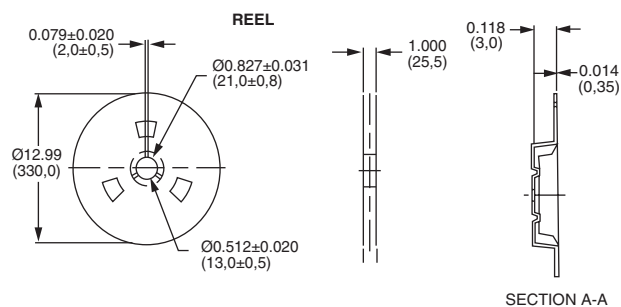

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[C&K Switches:](#)

[JSM07011SAQNL](#) [JSM05000SAQN](#) [JSM07011SAQNR](#) [JSM08011SAQNL](#) [JSM08011SAQNR](#) [JSM08022SAQNL](#)
[JSM08022SAQNR](#)