


KSC2 Series

Sealed Tact Switch for SMT

KSC2 soft actuator 3,5 mm high



Type	Operating force FA (Newtons)	Operating life (operations)	Travel (mm)
KSC201	1.6 ± 0.6	5,000,000	0.3 ± 0.2
KSC221	2 ± 0.5	500,000	0.35 + 0.25/- 0.15
KSC222	2 ± 0.5	1,000,000	0.35 + 0.25/- 0.15
KSC241	3.5 ± 0.9	300,000	0.5 ± 0.2
KSC251	5.55 ± 1.45	300,000	0.5 ± 0.2
KSC241 SP DELTA	3.55 ± 0.9	300,000	0.5 ± 0.2
KSC251 SP DELTA	6.2 ± 1.55	100,000	0.6 ± 0.2

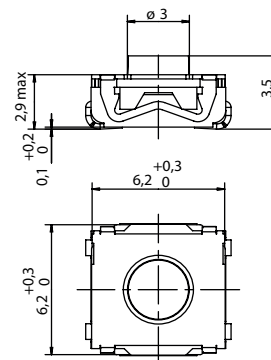


Packaging

Switches delivered on continuous tape & reels of 2,000 pieces
 Dimensions according to EIA RS-481/ IEC 60286-3 standard
 External diameter 330 ± 2 mm

How To Order

Our easy build-a-switch concept allows you to mix and match options to create the switch you need. To order, select desired option from each category and place it in the appropriate box.

However, please note that all the combinations of these options are not feasible.
 For any part number different from those listed above, please consult your local representative.

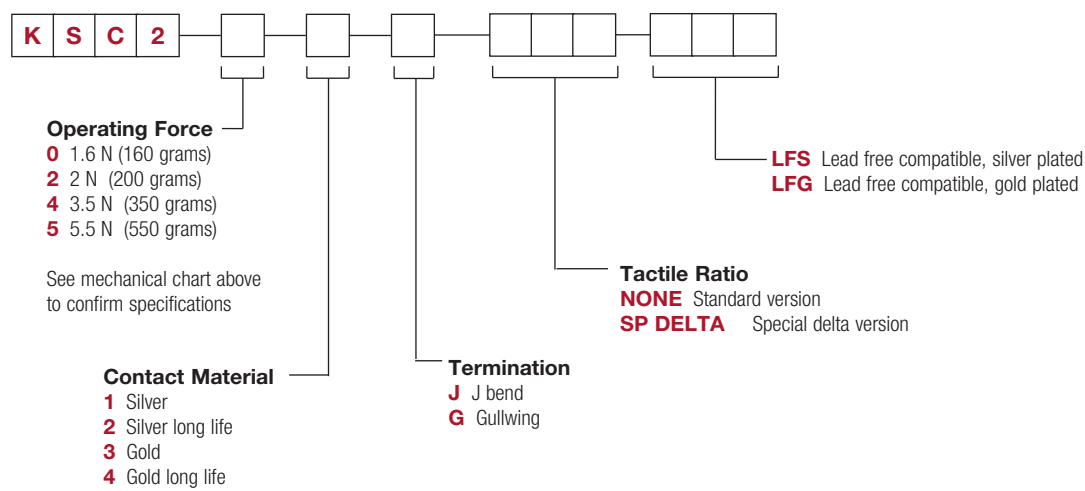

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

C&K Switches:

[KSC221G LFS](#) [KSC221J LFS](#) [KSC241G LFS](#) [KSC222G LFS](#) [KSC201GLFS](#) [KSC201JLFS](#) [KSC223GLFG](#)
[KSC223JLFG](#) [KSC243GLFG](#) [KSC243JLFG](#) [KSC233JSPDLFG](#) [KSC221JLFS](#) [KSC222JLFS](#) [KSC222GLFS](#)
[KSC221GLFS](#) [KSC241GLFS](#) [KSC241JLFS](#) [KSC252JLFS](#) [KSC251JLFS](#) [KSC241JSPDELTALFS](#) [KSC253JLFG](#)
[KSC243J LFG](#) [KSC201J LFS](#) [KSC223J LFG](#) [KSC243G LFG](#) [KSC201G LFS](#)