

08098900 BATTERY DISCONNECT SWITCHES

350A • SPST • IP65 • M12 Studs • Removable or Fixed Handle



Description

Manual Battery Disconnect Switch features a removable or fixed handle depending on part number selected.

08098900 - base unit with removable handle

08098980 - switch with removable handle with black boot and chain

08098981 - switch with fixed handle and black boot

Features/Benefits

- 350A continuous current rating
- Waterproof and dustproof to IP65

Specifications

Max Operating Voltage:	24V DC
Max Continuous Current:	350A
Intermittent Current:	2500A at 3 sec
Operating Temp:	-40°C to +80°C
Ingress Protection:	IP65 IP69K (08098981)
Contacts:	Silver-Plated Copper
Terminals:	M12 (zinc-plated steel)


Applications

- Heavy Truck
- Off-Road
- Emergency Vehicles
- Material Handling
- Mining
- Agricultural
- Marine
- Construction

Web Resources

Download 2D prints and additional technical resources at:
littelfuse.com/ManualBatterySwitches

Electrical Diagram

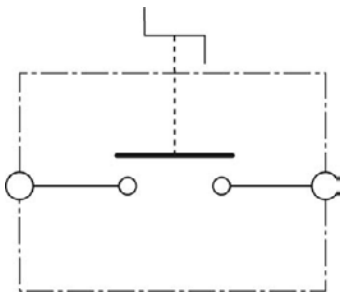

Ordering Information

PART NUMBERS		VOLTAGE	AMPERAGE	CIRCUITRY	MOUNTING	INGRESS	NOTES
BULK	BOXED						
08098900	08098900-BX	12-24V DC	350A	SPST	Flange Mount	IP65	Removable Handle
08098980	08098980-BX	12-24V DC	350A	SPST	Flange Mount	IP65	Removable Handle w/ Chain Cap to Cover when Key is Removed
08098981	08098981-BX	12-24V DC	350A	SPST	Flange Mount	IP65/IP69K	Fixed Handle w/ Black Boot

Dimensions in millimeters



Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Littelfuse:

[08098980](#) [08098900](#) [08098981](#)