


PUSH-BUTTON SWITCHES

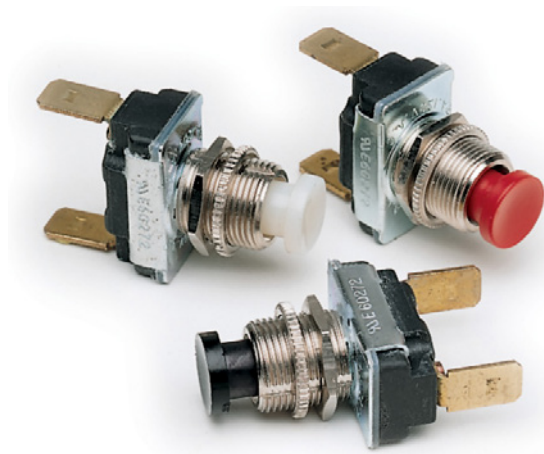

Description

- Off - Momentary On, spring return to Off, SPST.
- Body size: 0.890" L x 0.560" W x 0.773" H (to top of terminal) (22.61 x 14.22 x 19.64mm).
- Stem: 0.470" long (11.93mm).
- Push button diameter: 0.410" (10.41mm), nylon.
- Nickel-plated brass hexnut 15/32" - 32.
- Nickel-plated brass facenut

Specifications Overview

Voltage Rating:	12-24V DC
Amperage Rating:	5A
Circuitry:	SPST (Off Momentary On) Spring Return to Off
Terminals:	Blade - 0.250" wide (6.35mm)
Dimensions:	L 0.890" x W 0.560" x H 0.773"

Web Resources

Download technical resources at:
littelfuse.com/9187

Ordering Information

PART NUMBER			
BULK	BOXED	RETAIL	DESCRIPTION
9187	9187-BX	9187-BP	Black Push Button Switch
9187-01	—	—	Natural/White Push Button Switch
9187-02	9187-02-BX	9187-02-BP	Red Push Button Switch

Other SPST Momentary Switches

PART NUMBER	DESCRIPTION
9095	Push-Button Switch
90030	Push-Button Switch with Cap
M-612	Push-Button Switch with Recessed Plunger Button
M-608	Plasticized Push-Button Switch with Cap
58027-02	Weather-Resistant Rocker Switch
55020	Toggle Switch
9100	Push-Button Switch



9095



90030



M-612



M-608



58027-02



55020



9100



Visit Littelfuse.com for the most up-to-date product information. Littelfuse products are designed for specific applications and should not be used for any purpose (including, without limitation, automotive applications) not expressly set forth in applicable Littelfuse product documentation. Warranties granted by Littelfuse shall be deemed void for products used for any purpose not expressly set forth in applicable Littelfuse product documentation. Littelfuse shall not be liable for any claims or damages arising out of products used in applications not expressly intended by Littelfuse as set forth in applicable Littelfuse product documentation.

Datasheet Replaces Hotfeed Number D-602

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Littelfuse:

[96101](#) [9187-02](#) [92118-06](#)