 



PART NUMBER	GT-NR6H1525T	REV.	C
DATE	E.C.N. NUMBER AND REVISION COMMENTS		REV.
12.11.96	E.C.N. #10284.		A
12.15.06	E.C.N. #11148.		B
01.10.12	E.C.N. #10BRDR. & REDRAWN.		C

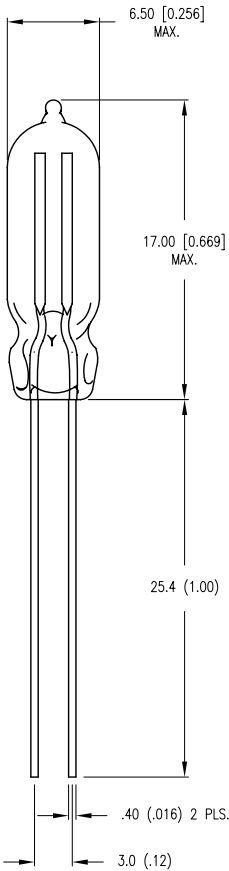

ELECTRICAL SPECIFICATIONS

D.C. FIRING VOLTAGE (dv/dt<100us):	145 ±10%
IMPULSE FIRING VOLTAGE (dv/dt=5kv/us):	800VDC
PEAK IMPULSE CURRENT (8/20us FORM):	1.5KA
IMPULSE SURGE LIFE (8/20us 500A):	1000 TIMES MIN.
D.C. HOLDOVER VOLTAGE:	50VDC
A.C. DISCHARGE CURRENT (1s X 5):	1 AMP
A.C. FOLLOW-ON CURRENT:	1 AMP
INSULATION RESISTANCE (50VDC MIN.):	10 10Ω
INTER-ELECTRODE CAPACITANCE:	.5PF MAX.

ENVIRONMENTAL TESTING

THERMAL SHOCK:	MIL-STD-202 METHOD 107 TEST COND B
HUMIDITY:	MIL-STD-202 METHOD 103B TEST COND B
TEMP CYCLING:	MIL-STD-202 METHOD 102A TEST COND C
OPERATING TEMP.:	-40°C TO +100°C

*UNLESS OTHERWISE SPECIFIED TOLERANCES PER DECIMAL PRECISION ARE: X=±1 (±0.039), X.X=±0.5 (±0.020), X.XX=±0.25 (±0.010), X.XXX=±0.127 (±0.005). LEAD SIZE=±0.05 (±0.002), LEAD LENGTH=±0.75 (±0.030). MIN= ^{+DECIMAL PRECISION}_{-0.00} MAX.= ^{+0.00}_{-DECIMAL PRECISION}



290 E. HELEN ROAD
PALATINE, IL 60067-6976
PHONE: +1.847.359.2790
FAX: +1.847.359.6538
WEB: WWW.LUMEX.COM

GAS COLOR INDICATOR TUBE, RED.

THE SPECIFICATIONS MAY CHANGE AT ANY TIME WITHOUT NOTICE DUE TO NEW MATERIALS OR PRODUCT IMPROVEMENT.

CONFIDENTIAL INFORMATION

THE INFORMATION CONTAINED IN THIS DOCUMENT IS THE PROPERTY OF LUMEX INC. EXCEPT AS SPECIFICALLY AUTHORIZED IN WRITING BY LUMEX INC., THE HOLDER OF THIS DOCUMENT SHALL KEEP ALL INFORMATION CONTAINED HEREIN CONFIDENTIAL AND SHALL PROTECT SAME IN WHOLE OR IN PART FROM DISCLOSURE AND DISSEMINATION TO ALL THIRD PARTIES.

DATE:	01.10.12	DRAWN BY:	AB
PAGE:	1 OF 1	CHKD BY:	KF
SCALE:	NTS	APRVD BY:	SS
UNIT:	mm [INCH]		Ⓟ

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumex:

[GT-NR6H1525T](#)