
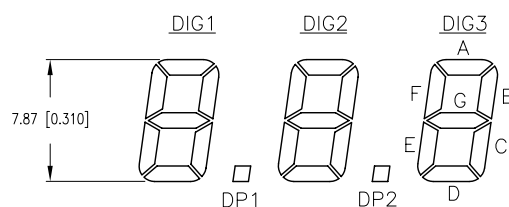


PART NUMBER	LCD-H301C31TR	REV.	A
DATE	E.C.N. NUMBER AND REVISION COMMENTS		REV.
03.05.12	E.C.N. #10BRDR. & REDRAWN.		A

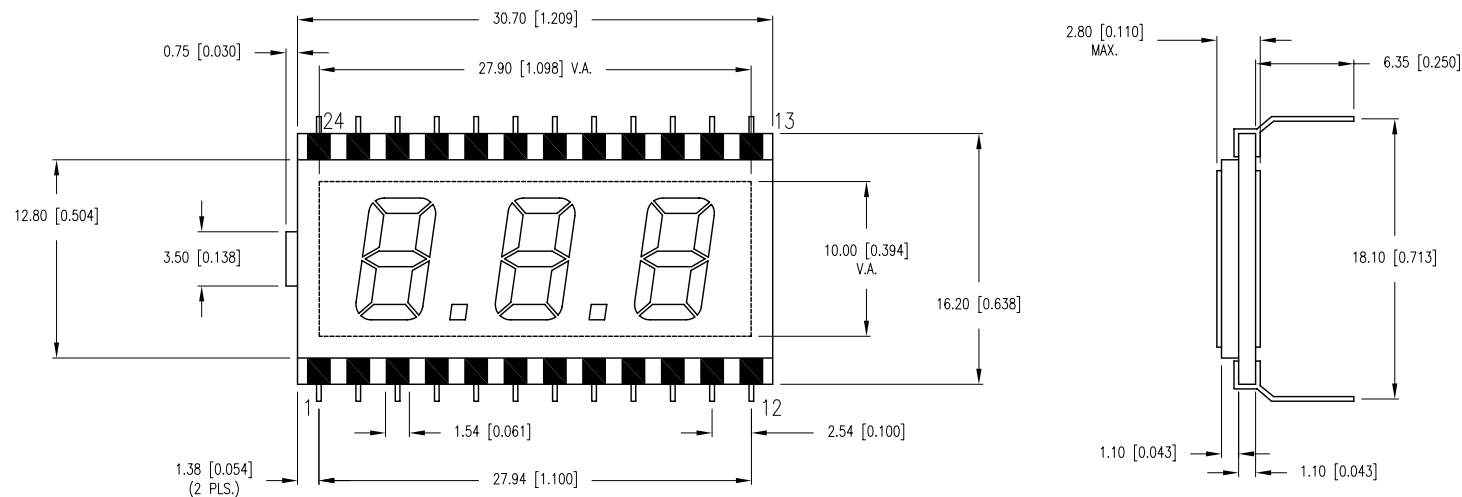

PIN NO.	1	2	3	4	5	6	7	8
SEGMENT	COM	E1	D1	C1	DP1	E2	D2	C2
PIN NO.	9	10	11	12	13	14	15	16
SEGMENT	DP2	E3	D3	C3	B3	A3	F3	G3
PIN NO.	17	18	19	20	21	22	23	24
SEGMENT	B2	A2	F2	G2	B1	A1	F1	G1

CHARACTERISTICS	
FLUID TYPE:	TN
BACKGROUND COLOR:	GRAY
VIEWING DIRECTION:	6:00
DISPLAY MODE:	REFLECTIVE
OPERATING VOLTAGE:	5.0V A.C.
OPERATING TEMP.	-30°C TO 80°C
STORAGE TEMP.	-40°C TO 85°C
DRIVING METHODE:	STATIC
CONNECTION TYPE:	24 PINS

REPLACES PART #: LCD-S31C301TR

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

Lumex:

[LCD-H301C31TR](#)