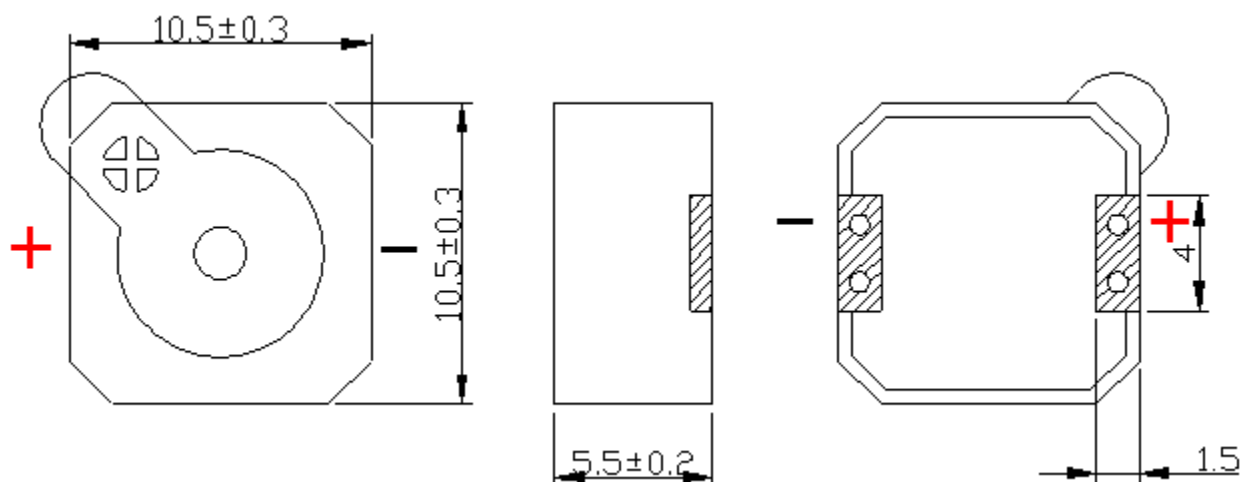


**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**

Oscillation Frequency (Hz)	4000 $\pm$ 300
Operating Voltage (VDC)	2.5 ~ 5.5
Rated Voltage (VDC)	5.0
Current Consumption Max. (mA)	2 at Rated Voltage
Sound Pressure Level Min. (dB)	80 at 10cm at Rated Voltage
Tone / Pulse Rate	Constant
Operating Temperature (°C)	-20 ~ +100
Storage Temperature (°C)	-30 ~ +110
Housing	LCP (Color: Black)
Type of Connection	SMD
Weight (Grams)	0.8
Condition by reflow soldering (°C)	250 $\pm$ 5 / 5 sec
Condition by hand soldering (°C)	350 $\pm$ 20 / within 5 sec
Options	For other options contact factory

Dimensions: (units: mm)

Attention: Must be installed with correct polarity.

Units come with wash label and are suitable for aqueous wash

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[ASI09N40MQ](#)