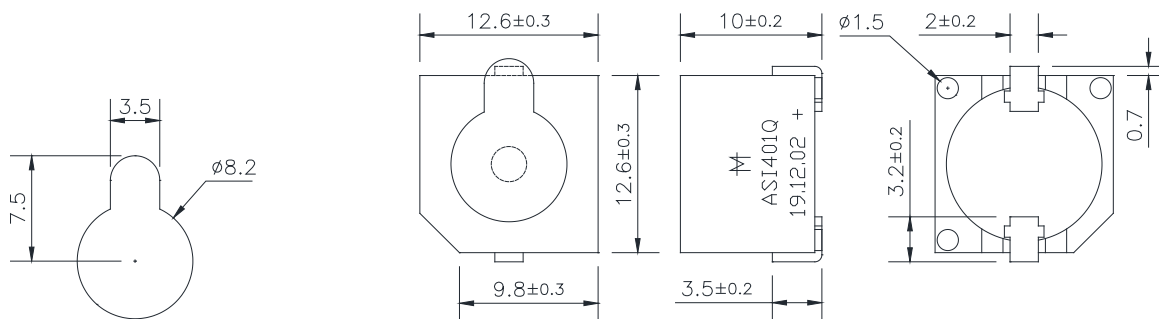
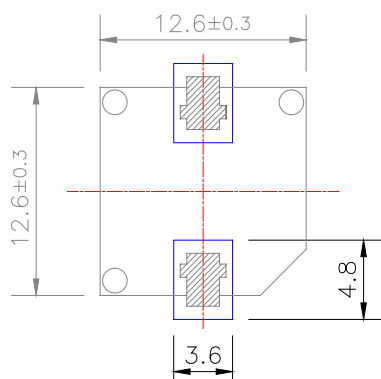


**May not be suitable for all Medical and Aerospace applications.  
Contact Mallory Sonalert to discuss your application.**

|                                    |                                   |
|------------------------------------|-----------------------------------|
| Oscillation Frequency (Hz)         | 2400 $\pm$ 300                    |
| Operating Voltage (Vdc)            | 9.0 ~ 15                          |
| Rated Voltage (Vdc)                | 12                                |
| Current Consumption Max. (mA)      | 50 at Rated Voltage               |
| Sound Pressure Level Min. (dB)     | 90 at 10cm at Rated Voltage       |
| Tone/Pulse Rate                    | Constant                          |
| Operating Temperature (°C)         | -40 ~ +80                         |
| Storage Temperature (°C)           | -40 ~ +80                         |
| Housing                            | PPS plastic resin (Color: Gray)   |
| Type of Connection                 | SMD                               |
| Weight (Grams)                     | 3.0                               |
| Condition by reflow soldering (°C) | 250 $\pm$ 5 / within 5 sec        |
| Condition by hand soldering (°C)   | 350 $\pm$ 20 / within 5 sec       |
| Options                            | For other options contact factory |

**Dimensions:** (units: mm)**ROHS Compliant****Recommended PCB Layout****Packaging:**

Parts are supplied in tubes of 35 pieces.

Units come with wash label and are appropriate for aqueous wash.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[ASI401Q](#)