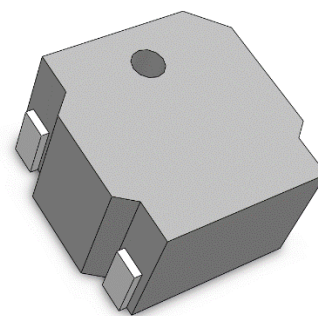
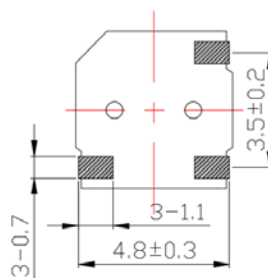
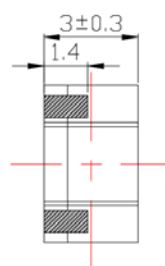
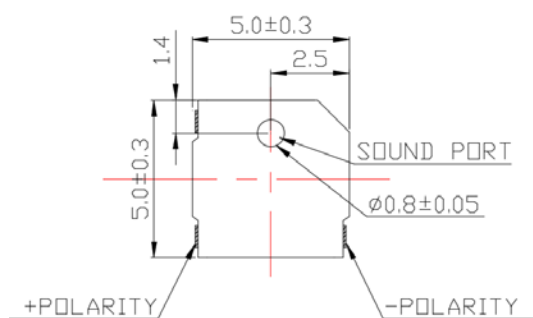


**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**


NO CIRCUITRY

| | |
|--|-----------------------------------|
| Oscillation Frequency (Hz) | 4000 |
| Operating Voltage (Vpp) | 2 ~ 4 |
| Rated Voltage (Vpp) | 3.6 |
| Current Consumption Max. (mA) | 110 at Rated Voltage |
| Sound Pressure Level Min. (dB) | 80 at 10cm at Rated Voltage |
| Coil Resistance (Ω) | 12 ± 3 |
| Operating Temperature ($^{\circ}\text{C}$) | $-20 \sim +60$ |
| Storage Temperature ($^{\circ}\text{C}$) | $-30 \sim +80$ |
| Housing | LCP Plastic Resin (Color: Black) |
| Type of Connection | SMD |
| Condition by wave soldering ($^{\circ}\text{C}$) | 250 ± 5 / within 10 sec |
| Condition by hand soldering ($^{\circ}\text{C}$) | 350 ± 20 / within 5 sec |
| Weight (Grams) | 0.6 |
| Options | For other options contact factory |

Dimensions: (units: mm)**ROHS Compliant**

Packaging: Parts are supplied on tape-and-reel, 1000 pcs/reel.

Units do not come with wash label and are not appropriate for aqueous wash.

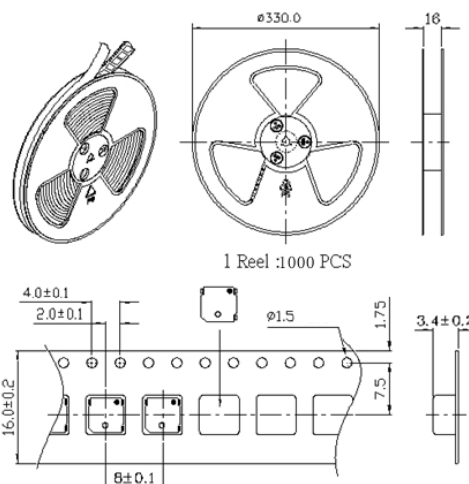

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[AST0540MW-3.6TRQ](#)