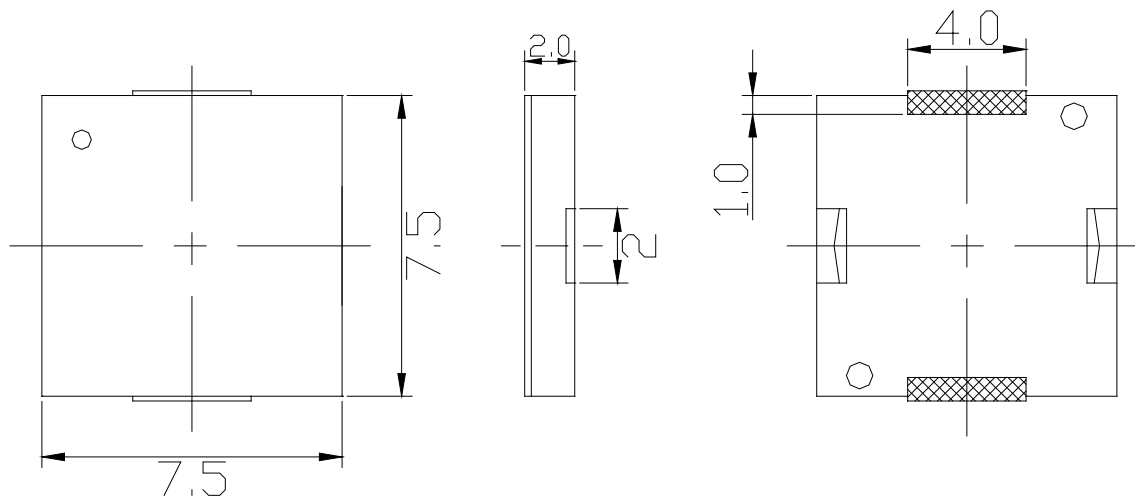


**May not be suitable for all Medical and Aerospace applications.  
Contact Mallory Sonalert to discuss your application.**

**NO CIRCUITRY**

Resonant Frequency (Hz)	6000
Operating Voltage (Vpp)	1 ~ 25
Rated Voltage (Vpp)	3.0
Current Consumption Max. (mA)	6 at 12 Vpp
Sound Pressure Level Min. (dB)	74 at 10cm at 12Vpp
Capacitance (pF)	6,000 $\pm$ 30%
Operating Temperature (°C)	-40 ~ +85
Storage Temperature (°C)	-40 ~ +85
Housing	LCP Plastic Resin (Color: Black)
Type of Connection	SMD
Condition by wave soldering (°C)	250 $\pm$ 5 / within 5 sec
Condition by hand soldering (°C)	350 $\pm$ 20 / within 5 sec
Weight (Grams)	0.2
Options	For other options contact factory

**Dimensions:** (units: mm)**ROHS Compliant**

Units do not come with wash label and are not appropriate for aqueous wash.

**Packaging:** Parts are supplied on cut tape.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[AST0760MCQ](#)