

May not be suitable for all medical and aerospace applications.


Specifications: Contact Mallory Sonalert to discuss your application.

Resonant Frequency (Hz)	6000
Operating Voltage (Vpp)	1 ~ 25
Rated Voltage (Vpp)	3.0
Current Consumption Max. (mA)	6 at 12 Vpp
Sound Pressure Level Min. (dB)	74 at 10cm at 12Vpp
Capacitance (pF)	6,000 \pm 30%
Operating Temperature (°C)	-40 ~ +85
Storage Temperature (°C)	-40 ~ +85
Housing	LCP Plastic Resin (Color: Black)
Type of Connection	SMD
Condition by wave soldering (°C)	250 \pm 5 / within 5 sec
Condition by hand soldering (°C)	350 \pm 20 / within 5 sec
Weight (Grams)	0.2
Options	For other options contact factory

Dimensions: (units: mm)


ROHS Compliant

NO CIRCUITRY

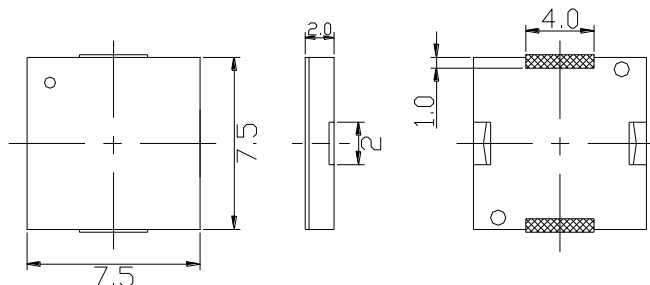


Units do not come with wash label and are not appropriate for aqueous wash.

Packaging: Parts are supplied on tape-and-reel, 1000 pcs/reel.

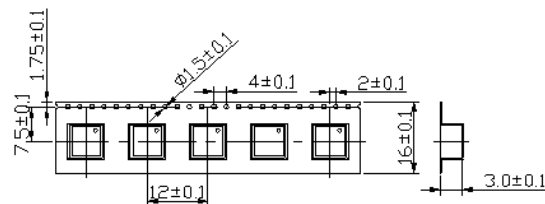

1000 PCS/SPool

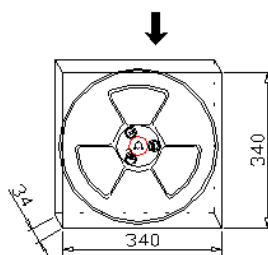

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[AST0760MCTRQ](#)