

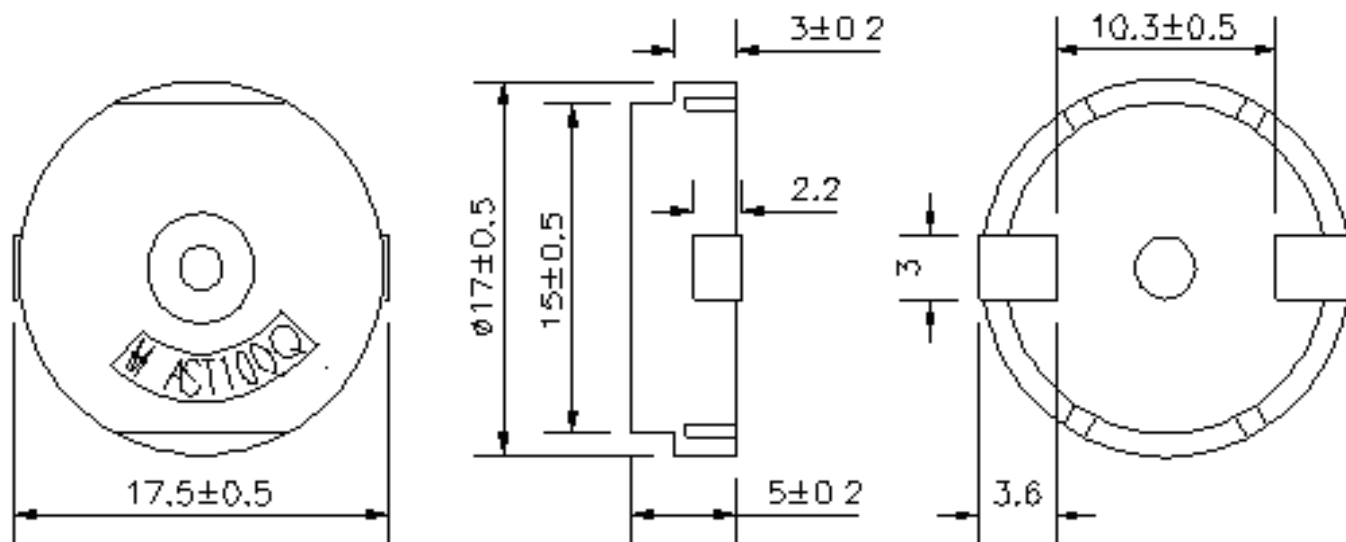
**May not be suitable for all medical and aerospace applications.
Specifications: Contact Mallory Sonalert to discuss your application.**

NO CIRCUITRY

Oscillation Frequency (Hz)	4000 $\pm$ 500
Operating Voltage (Vp-p/max)	15
Rated Voltage (Vp-p)	5.0
Current Consumption Max. (mA)	1.5 at Rated Voltage
Sound Pressure Level Min. (dB/min)	80 at 10cm at 5V Square Wave
Capacitance (pF)	10000 $\pm$ 30%
Soldering Condition	250 °C/15 sec (max)
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-40 ~ +85
Housing	PPS plastic resin (Color: Brown)
Type of Connection	SMD
Condition by reflow soldering (°C)	245 $\pm$ 5 / 1 min
Condition by hand soldering (°C)	350 $\pm$ 20 / within 5 sec
Weight (g)	1.4
Options	For other options contact factory

Dimensions: (units: mm)

Vp-p = 1/2duty, square wave

RoHS Compliant**Packaging:**

Parts are supplied on reels (500 pcs per tape and reel).

Units do not come with wash label and are not appropriate for aqueous wash.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[AST100TRQ](#)