

**Sales Outline Drawing**

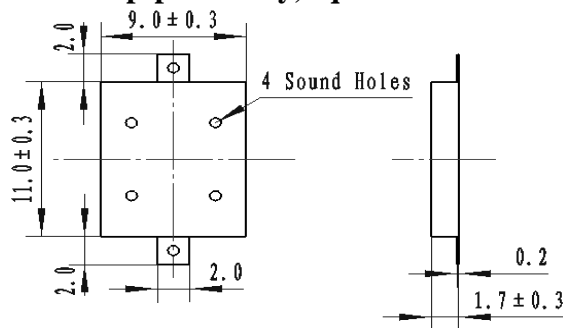
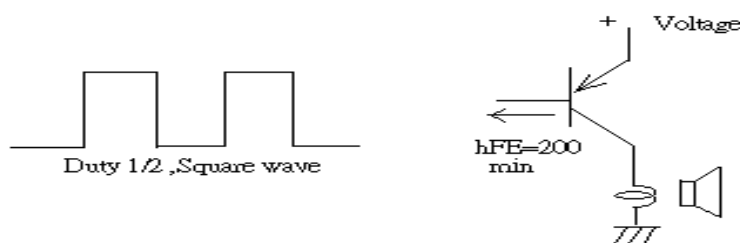
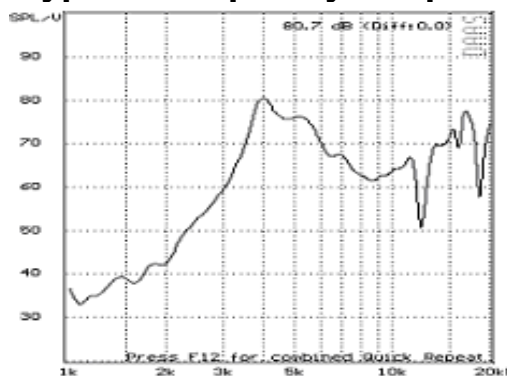
Revision

**D**

**May not be suitable for all Medical and Aerospace applications.  
Contact Mallory Sonalert to discuss your application.**

**NO CIRCUITRY**

Oscillation Frequency (Hz)	4100 $\pm$ 500
Operating Voltage (Vp-p)	1 ~ 20
Rated Voltage (Vp-p)	5.0
Current Consumption Max. (mA)	1.0 at Rated Voltage
Sound Pressure Level (dB/min)	73 at 10cm at Rated Voltage
Capacitance (pF)	12000 $\pm$ 30% at 100 Hz
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Type of Connection Terminal	SMD
Housing	LCP plastic resin (Color : Black)
Weight (Grams)	0.25
Condition by reflow soldering (°C)	245 $\pm$ 5 / 1 min
Condition by hand soldering (°C)	350 $\pm$ 20 / within 5 sec
Options	For other options contact factory

**Dimensions:** (units: mm)**PS: Vp-p=1/2duty, square wave****ROHS Compliant****Recommend Driving Circuit****Typical Frequency Response Curve****Packaging:** Parts are supplied on Cut-Tape.

Units do not come with wash label and are not appropriate for aqueous wash.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[AST1109MLQ](#)