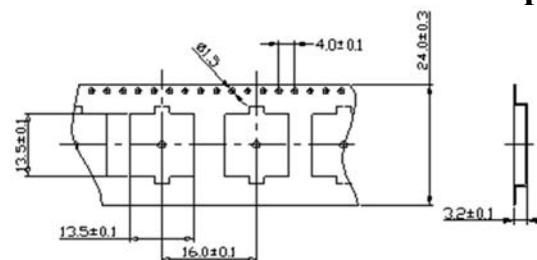
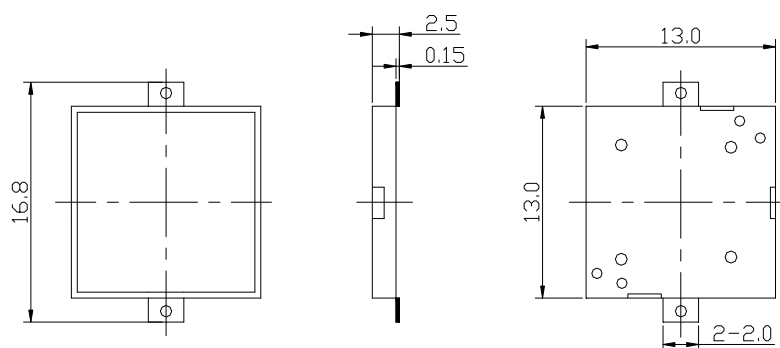



**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**

NO CIRCUITRY

Resonant Frequency (Hz)	4100
Operating Voltage (Vp-p)	1 ~ 25
Rated Voltage (Vp-p)	5.0
Current Consumption Max. (mA)	8 at 12 Vp-p
Sound Pressure Level Min. (dB)	90 at 10cm at 12Vp-p
Capacitance (pF)	16,000 \pm 30%
Operating Temperature (°C)	-40 ~ +85
Storage Temperature (°C)	-40 ~ +85
Housing	LCP Plastic Resin (Color: Black)
Type of Connection	SMD
Condition by wave soldering (°C)	260 \pm 5 / within 5 sec
Condition by hand soldering (°C)	350 \pm 20 / within 5 sec
Weight (Grams)	0.5
Options	For other options contact factory

Dimensions: (units: mm)**ROHS Compliant**

1000 PCS/SP00L

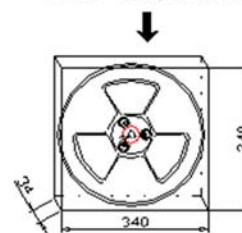

Packaging: Parts are supplied on tape-and-reel, 1000 pcs/reel.

Units do not come with wash label and are not appropriate for aqueous wash.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[AST1341MCTRQ](#)