

Sales Outline DrawingRevision **K**

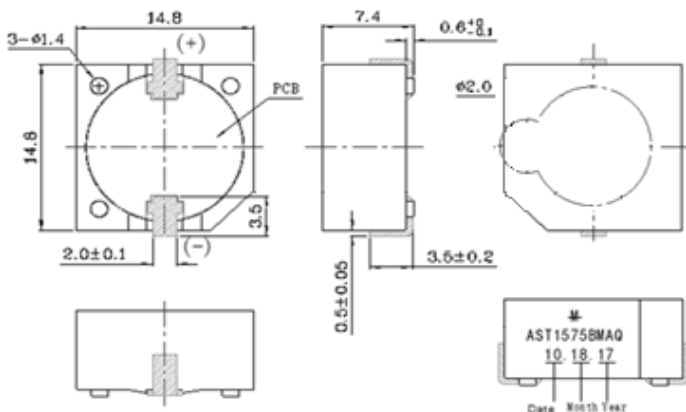
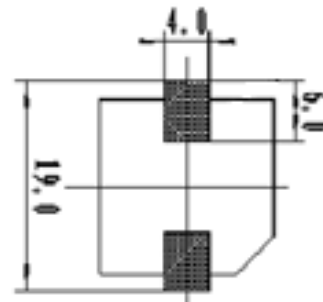
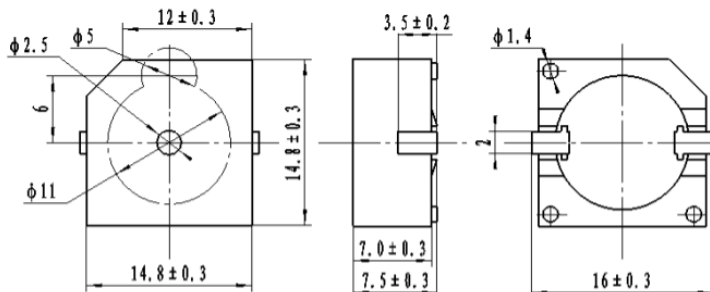
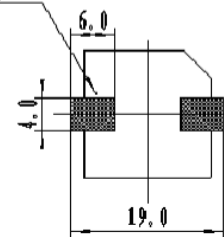
**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**

NO CIRCUITRY

Oscillation Frequency (Hz)	3650 ± 500
Operating Voltage (V _{p-p})	3 ~ 20
Rated Voltage (V _{p-p})	7.0
Current Consumption Max. (mA)	5 at Rated Voltage
Sound Pressure Level (dB/min)	85 at 10cm at Rated Voltage
Capacitance (pF)	15,000 ± 30% at 100 Hz 1V
Operating Temperature (°C)	-30 ~ +85
Storage Temperature (°C)	-40 ~ +85
Type of Connection Terminal	SMD
Housing	PPS plastic resin (Color : Black)
Weight (Grams)	2.0
Condition by reflow soldering (°C)	255 ± 5 / within 5 sec
Condition by hand soldering (°C)	350 ± 20 / within 5 sec
Options	For other options contact factory

Dimensions: (units: mm)PS: V_{p-p}=1/2duty, square wave

RoHS Compliant

After Code Date: 1803-3**Suggested Pad PCB-Layout****Before Code Date: 1803-2****Suggested Pad PCB-Layout****Packaging:** Parts are supplied on reels (300 pcs per tape and reel).

Units come with wash label and are acceptable for aqueous wash.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[AST1575BMATRQ](#)