

**Mallory Sonalert Products, Inc.**

Part #:

**JR16-RYG-4LDP3****Sales Outline Drawing**

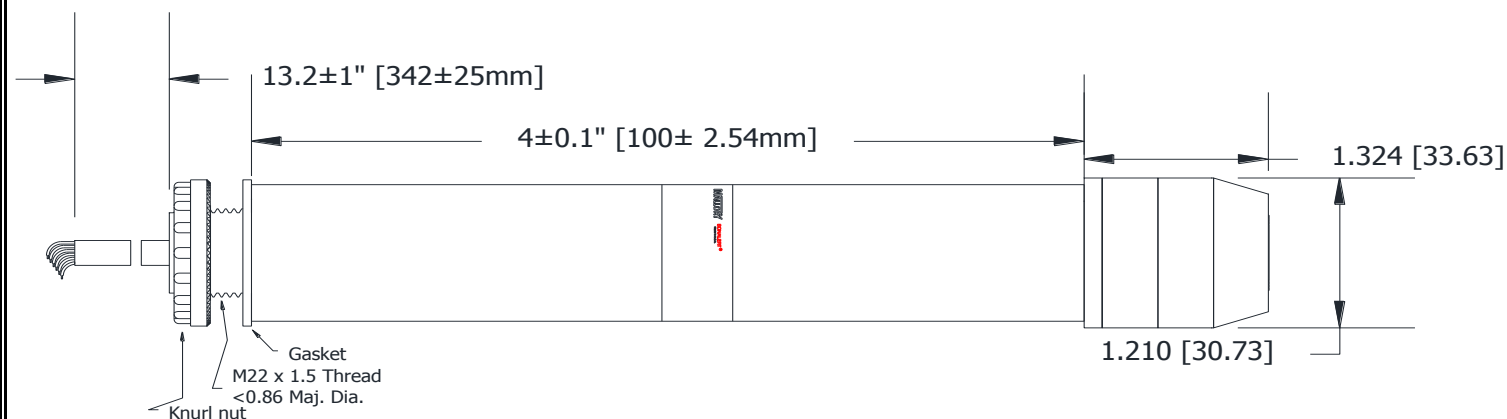
Revision:

**A****Specifications:**

|                         |  |          |          |
|-------------------------|--|----------|----------|
| Sound Level Category    | Loud   |          |          |
| Mode of Operation       | Slow Double Pulse @ 0.5 PPS                                    |          |          |
| Voltage Rating          | 9 to 16 VDC  |          |          |
| Frequency               | 3900 ± 500 Hz  |          |          |
| Loudness @ 1M           | 80 to 85 dB(A) Typ.  |          |          |
| Sound Current Draw      | 40mA MAX   |          |          |
| Stack Level             | BOTTOM   | MIDDLE   | TOP      |
| LED Color               | GREEN  | YELLOW   | RED      |
| LED Current Draw        | 25mA max   | 60mA MAX | 60mA MAX |
| Total Max Current Draw  | 185mA MAX  |          |          |
| Housing Material        | 6/6 Nylon, Color: Black  |          |          |
| Top Cap / Lens Material | 6/6 Nylon, Color: Opaque White                                 |          |          |
| Storage Temperature     | -40° to +70° C   |          |          |
| Operating Temperature   | -30° to +60° C   |          |          |
| Panel Mounting          | Recommended hole size is 22.5 mm.                              |          |          |
| Knurled Nut             | The max recommended torque is 10 in-lbs.                       |          |          |
| Cable                   | Gray, UL Style 21894, 300V, 105°C, 24AWG, Pb-Free Tinned Leads |          |          |
| Weight (Typical)        | 112 grams  |          |          |
| NEMA 3R, 4X, & 12       | Approved with use of included gasket.                          |          |          |
| Options                 | Please contact factory.  |          |          |

**Dimensions:**

Inches (mm)

**cUL Recognized****ROHS Compliant****Connections:**

**SOUND** BLACK wire to Ground and ORANGE wire to Positive  
**BOTTOM** BROWN wire to Ground and GREEN wire to Positive  
**MIDDLE** BROWN wire to Ground and YELLOW wire to Positive  
**TOP** BROWN wire to Ground and RED wire to Positive

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[JR16-RYG-4LDP3](#)