


<b>Mallory</b>	<b>Mallory Sonalert Products, Inc.</b>	Part #:	<b>JT028-RY-CS</b>
<b>Sales Outline Drawing</b>		Revision:	<b>C</b>

### Specifications:

Stack Number:	1	2			
LED Color:	RED	YELLOW			
Connection Wires:	Red and Brown	Yellow and Brown			
LED Current Draw:	<50 mA	<60 mA			
Rated Voltage:	24 VAC/DC				
Operating Voltage:	20-28 VAC/DC				
Total Max Current:	<110mA				
Operating Temperature:	-25° ~ +60°C				
Lens Color:	Opaque White				
Material:	ABS FR15U				
Mounting Method:	Stainless Steel Pole				
Weight Typical (g):	580				
NEMA 12:	Approved				
Options:	Please contact factory.				

**Dimensions:** Inches (mm) **cUL Recognized** **ROHS Compliant**  
 PATENT NUMBER 10309594

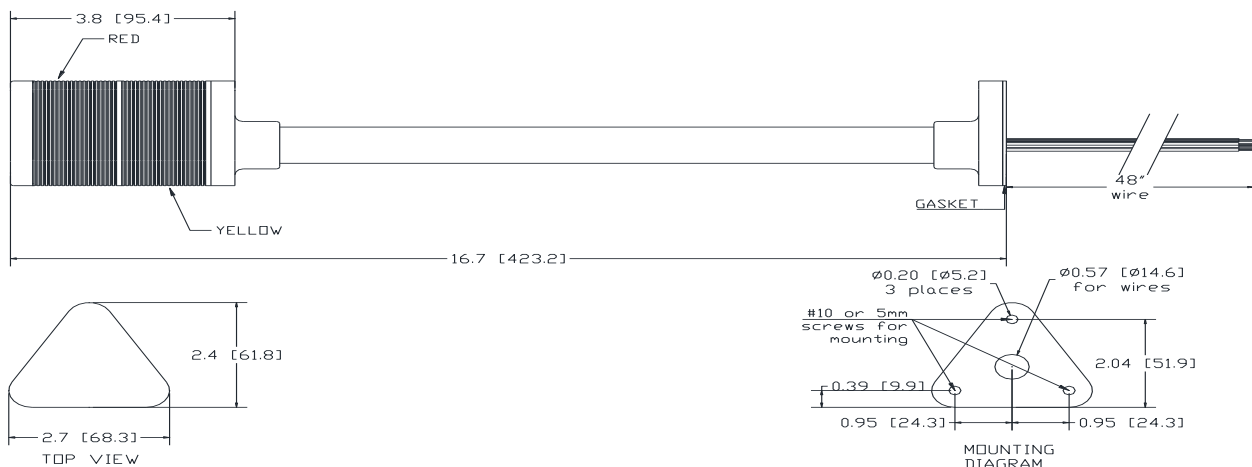

**LED OPERATION:** CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[JT028-RY-CS](#)