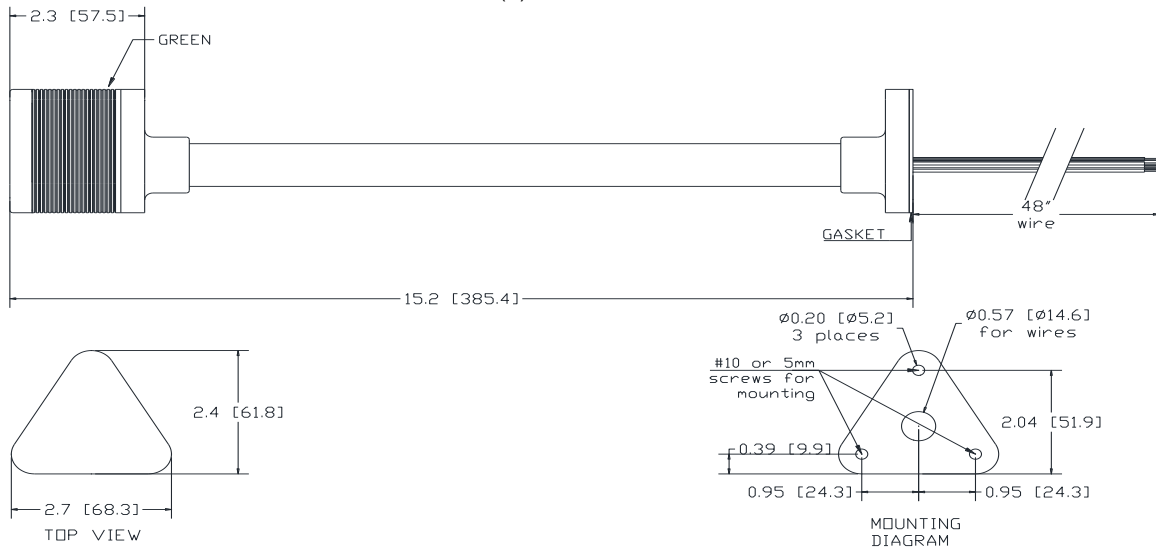


**Mallory Sonalert Products, Inc.**Part #: **JT028-G-CE****Sales Outline Drawing**Revision: **B****Specifications:**

Stack Number:	1				
LED Color:	GREEN				
Connection Wires:	Green and Brown				
LED Current Draw:	<50 mA				
Rated Voltage:	24 VAC/DC				
Operating Voltage:	20-28 VAC/DC				
Total Max Current:	<50mA				
Operating Temperature:	-25° ~ +60°C				
Lens Color:	Opaque White				
Material:	ABS FR15U				
Mounting Method:	Stainless Steel Pole - Black				
Weight Typical (g):	535				
NEMA 12:	Approved				
Options:	Please contact factory.				

Dimensions: Inches (mm)**cUL Recognized****ROHS Compliant**

PATENT NUMBER(S) D898600

**LED OPERATION:** CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[JT028-G-CE](#)