

# C

### Specifications:


Stack Number:	1				
LED Color:	GREEN				
Connection Wires:	Green and Brown				
LED Current Draw:	<50 mA				
Rated Voltage:			24 VAC/DC		
Operating Voltage:			20-28 VAC/DC		
Total Max Current:			<50mA		
Operating Temperature:			-25° ~ +60°C		
Lens Color:			Opaque White		
Material:			ABS FR15U		
Mounting Method:			Stainless Steel Pole		
Weight Typical (g):			535		
NEMA 12:			Approved		
Options:			Please contact factory.		

**Dimensions:**    Inches (mm)

## cUL Recognized

**ROHS Compliant**

PATENT NUMBER(S) D898600

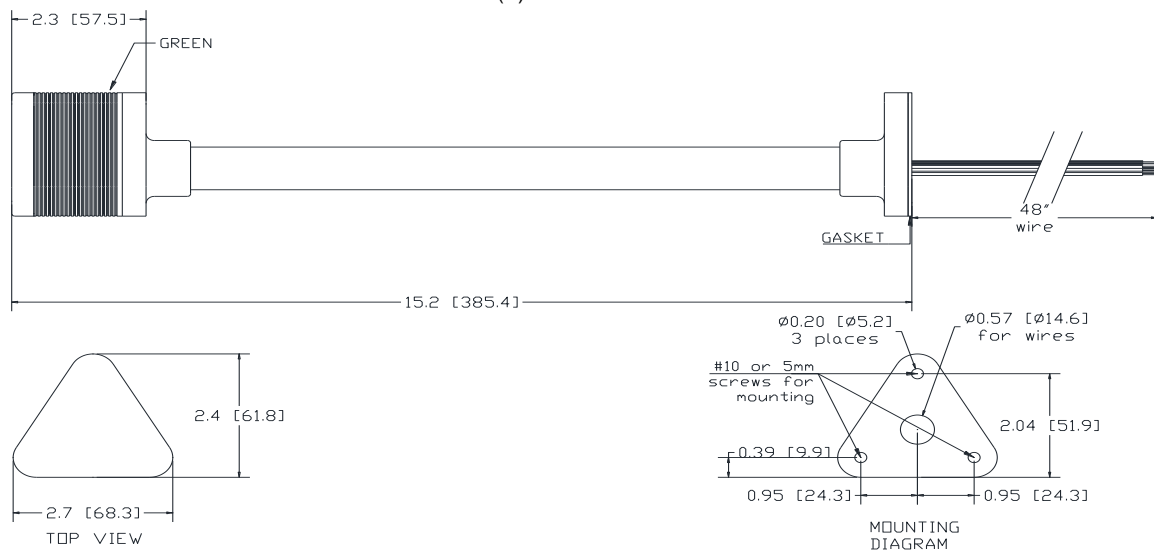

LED OPERATION:	CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.
----------------	--

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[JT028-G-CS](#)