

**MALLORY** **Mallory Sonalet Products, Inc.**  
**Sales Outline Drawing**

Part #: **JT028-RG-CD**  
 Revision: **D**

**Specifications:**


Stack Number:	1	2			
LED Color:	RED	GREEN			
Connection Wires:	Red and Brown	Green and Brown			
LED Current Draw:	<50 mA	<40 mA			
Rated Voltage:		24 VAC/DC			
Operating Voltage:		20-28 VAC/DC			
Total Max Current:		<90mA			
Operating Temperature:		-25° ~ +60°C			
Lens Color:		Opaque White			
Material:		ABS FR15U			
Mounting Method:		Direct Mount using 1/2" NPT Stainless Steel Pipe and Nut			
Weight Typical (g):		210			
NEMA 12:		Approved			
Options:		Please contact factory.			

**Dimensions:** Inches (mm)

**cUL Recognized**

**ROHS Compliant**

PATENT NUMBER(S) D898600 10309594

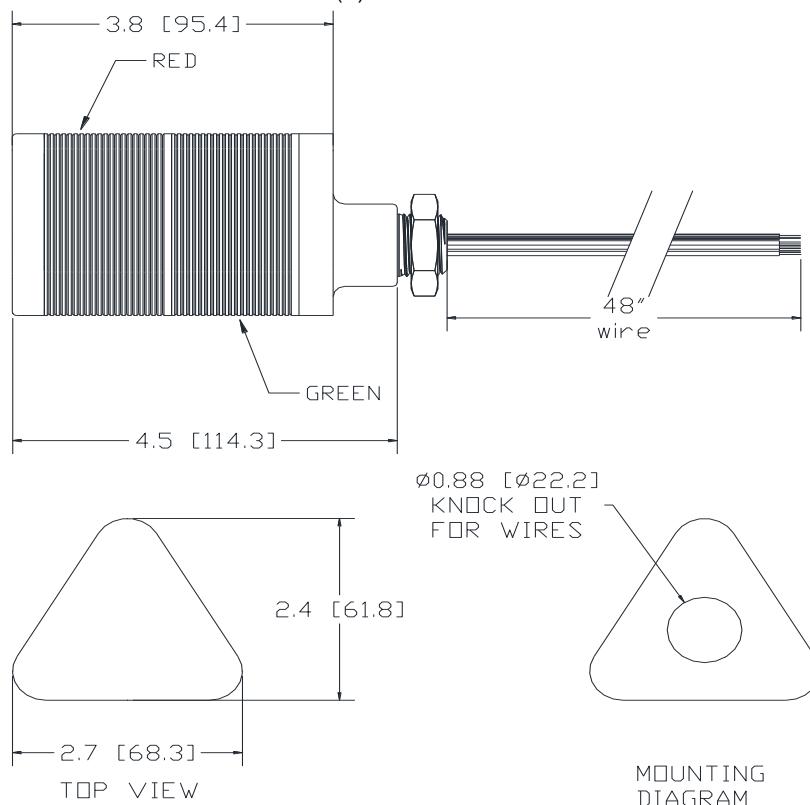

LED OPERATION: CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[JT028-RG-CD](#)