


|   |                           |
|---|---------------------------|
| <b>Mallory</b> <b>Mallory Sonalert Products, Inc.</b> | Part #: <b>JT028-R-CD</b> |
| <b>Sales Outline Drawing</b>                          | Revision: <b>C</b>        |

### Specifications:

|                        |  |  |  |  |  |
|------------------------|--|--|--|--|--|
| Stack Number:          | 1  |  |  |  |  |
| LED Color:             | RED  |  |  |  |  |
| Connection Wires:      | Red and Brown  |  |  |  |  |
| LED Current Draw:      | <50 mA   |  |  |  |  |
| Rated Voltage:         | 24 VAC/DC  |  |  |  |  |
| Operating Voltage:     | 20-28 VAC/DC   |  |  |  |  |
| Total Max Current:     | <50mA  |  |  |  |  |
| Operating Temperature: | -25° ~ +60°C   |  |  |  |  |
| Lens Color:            | Opaque White   |  |  |  |  |
| Material:              | ABS FR15U  |  |  |  |  |
| Mounting Method:       | Direct Mount using 1/2" NPT Stainless Steel Pipe and Nut |  |  |  |  |
| Weight Typical (g):    | 160  |  |  |  |  |
| NEMA 12:               | Approved   |  |  |  |  |
| Options:               | Please contact factory.                                  |  |  |  |  |

**Dimensions:**      Inches (mm)      **cUL Recognized**      **ROHS Compliant**

PATENT NUMBER(S) D898600

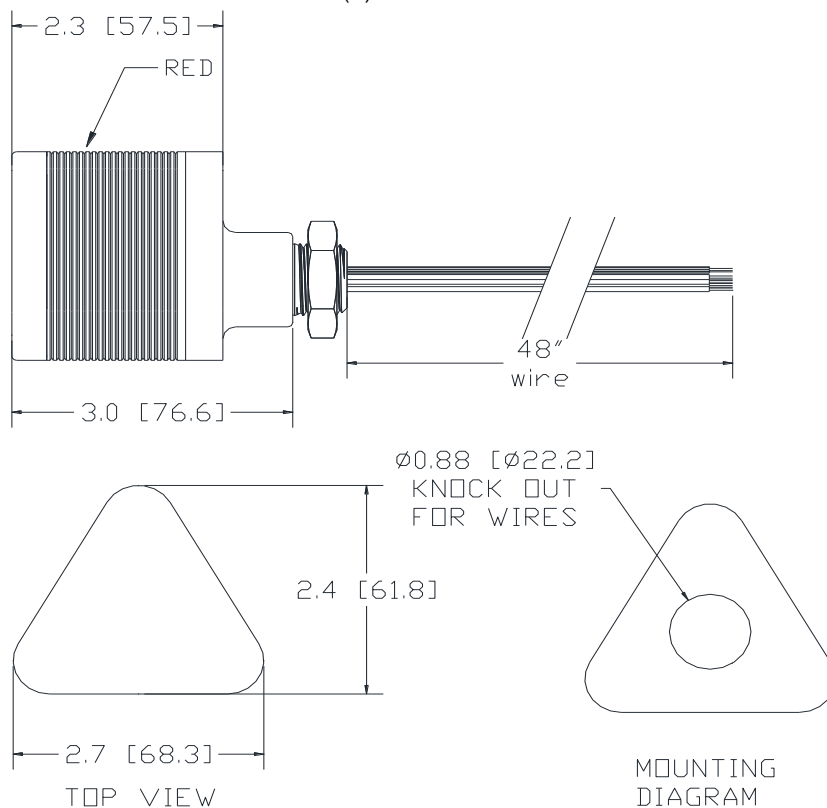

**LED OPERATION:**      CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[JT028-R-CD](#)