


| | |
|---|----------------------------|
| Mallory Mallory Sonalert Products, Inc. | Part #: JT120-YG-CD |
| Sales Outline Drawing | Revision: D |

Specifications:

| | | | | | |
|------------------------|--|-----------------|--|--|--|
| Stack Number: | 1 | 2 | | | |
| LED Color: | YELLOW | GREEN | | | |
| Connection Wires: | Yellow and Brown | Green and Brown | | | |
| LED Current Draw: | <230 mA | <190 mA | | | |
| Rated Voltage: | 120 VAC | | | | |
| Operating Voltage: | 90-120 VAC | | | | |
| Total Max Current: | <420mA | | | | |
| Operating Temperature: | -25° ~ +60°C | | | | |
| Lens Color: | Opaque White | | | | |
| Material: | ABS FR15U | | | | |
| Mounting Method: | Direct Mount using 1/2" NPT Stainless Steel Pipe and Nut | | | | |
| Weight Typical (g): | 215 | | | | |
| NEMA 12: | Approved | | | | |
| Options: | Please contact factory. | | | | |

Dimensions: Inches (mm) **cUL Recognized** **ROHS Compliant**

PATENT NUMBER(S) D898600 10309594

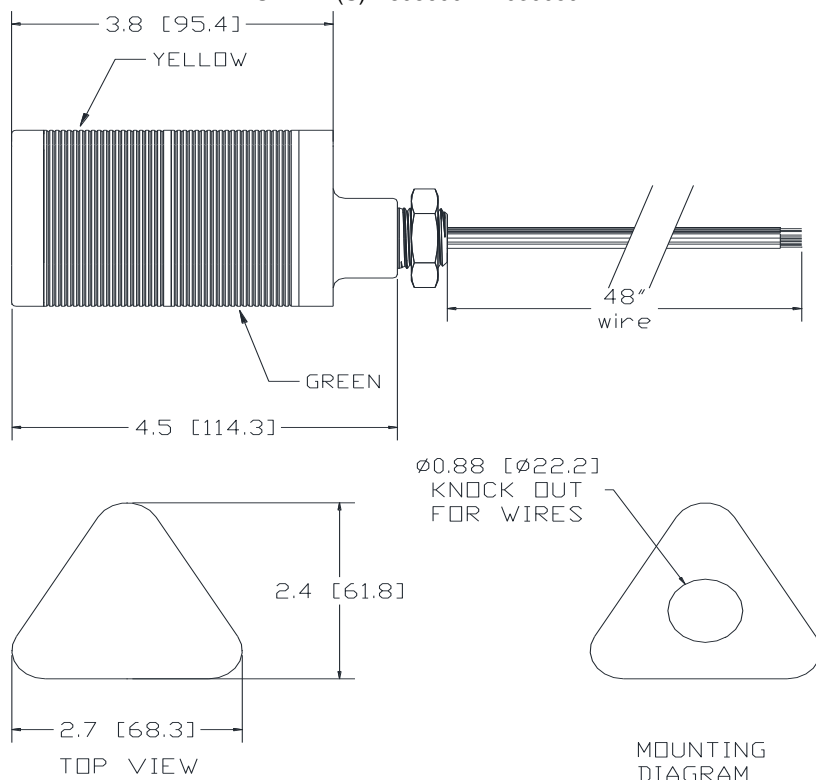

LED OPERATION: CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[JT120-YG-CD](#)