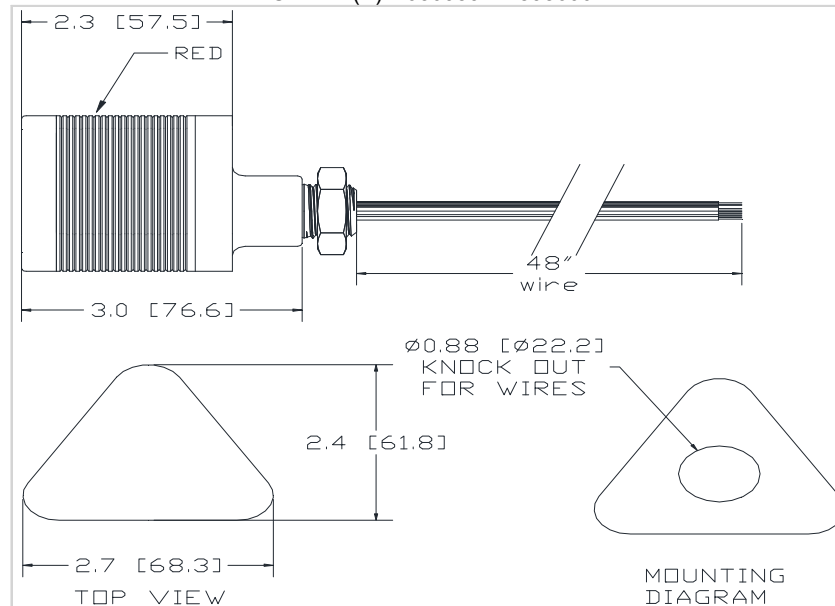


**Mallory Sonalert Products, Inc.**Part #: **JTC028-R-CD****Sales Outline Drawing**Revision: **A****Specifications:**

Stack Number:	1				
LED Color:	RED				
LED Operation:	Continuous				
Connection Wires:	Red and Brown				
LED Current Draw:	<50 mA				
Rated Voltage:	24 VAC/DC				
Operating Voltage:	20-28 VAC/DC				
Total Max Current:	<50mA				
Operating Temperature:	-25° ~ +60°C				
Lens Color:	Transparent - matching LED stack color				
Material:	Lexan CFR7431				
Mounting Method:	Direct Mount using 1/2" NPT Stainless Steel Pipe and Nut				
Weight Typical (g):	160				
NEMA 12:	Approved				
Options:	Please contact factory.				

Dimensions: Inches (mm)**cUL Recognized CE Certified****ROHS Compliant**

PATENT NUMBER(S) 10309594 D898600

**LED OPERATION:** CONNECT STACK COLOR WIRE TO POWER AND BROWN WIRE TO POWER.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[JTC028-R-CD](#)