



Mallory Sonalert Products, Inc.

Part #:

MSE14MTT3

Sales Outline Drawing

Revision:


B

Specifications:



| | |
|-----------------------|-------------------------------|
| Sound Level Category | Medium |
| Mode of Operation | 3-Tone Telephone Ringer |
| Voltage Rating | 7 to 14 VDC |
| Frequency | 3000-3700 Hz Typical |
| Loudness @ 1 FT | 75 to 85 dB(A) Typ. |
| Current Draw | 50mA MAX |
| Housing Material | Valox (UL94V-0), Color: Black |
| Storage Temperature | -40° to +80° C |
| Operating Temperature | -40° to +65° C |
| Weight (Typical) | 4.0g |
| Options | Please contact factory. |

Dimensions: Inches (mm)

ROHS Compliant

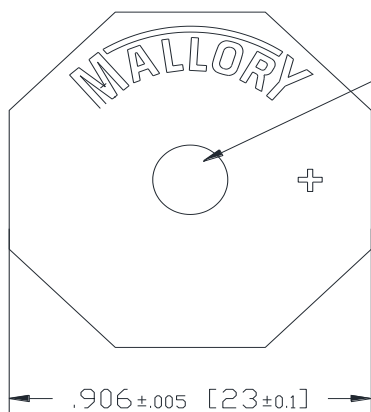

EMISSION HOLE

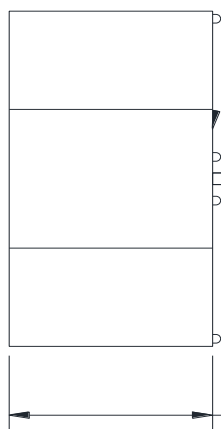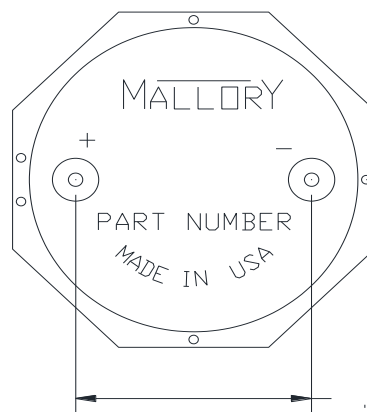

.031±.002 [0.8±0.4]
(2 Pins)

.197 [5]
.165 [4]

.509±.005 [12.9±0.1]

NOTE A:
TERMINALS - .031" DIA. NICKEL/TIN COATED BRASS.

NOTE B:
MOUNTING- INSERT INTO PRINTED CIRCUIT BOARD AND HAND OR MACHINE SOLDER.
UNITS ARE SUITABLE FOR WAVE SOLDERING. RECOMMENDED MAXIMUM TEMPERATURE
AND TIME DURATION FOR WAVE SOLDERING IS +270°C AND 3 SECONDS RESPECTIVELY.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[MSE14MTT3](#)