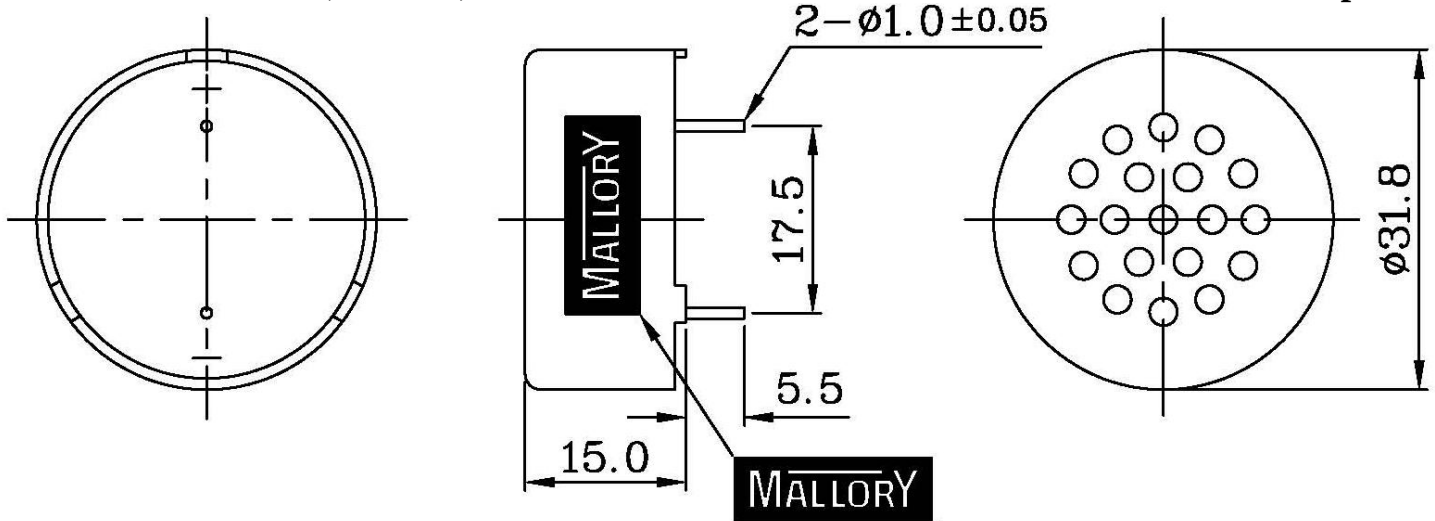


**Sales Outline Drawing**Revision **A****Specifications:**

|                        |                                                                                              |
|------------------------|----------------------------------------------------------------------------------------------|
| Impedance ( $\Omega$ ) | $8 \pm 20\%$ at 1500 Hz at 1.0 V                                                             |
| Rated Power (W)        | 0.1                                                                                          |
| Max Power (W)          | 0.2                                                                                          |
| Resonance Freq Fo (Hz) | $1250 \pm 200$ at 1.0V                                                                       |
| Frequency Range (Hz)   | Fo ~ 4000                                                                                    |
| Output S.P.L. (dB)     | $95 \pm 3$ at 0.1w/0.1m 1.5k, 2K, 2.5k, 3.0kHz<br>$85 \pm 3$ at 1w/1m 1.5k, 2K, 2.5k, 3.0kHz |
| Magnet Size (mm)       | $\varnothing 16.0 \times 7.0 \times 2.5$                                                     |
| Magnet                 | Ferrite                                                                                      |
| Frame Material         | ABS UL-94HB                                                                                  |
| Operating Temp         | -20 to 55°C                                                                                  |
| Weight (g)             | 10.0                                                                                         |
| Options                | For other options contact factory                                                            |

**Dimensions:  $\pm 0.5$**  (units: mm)**ROHS Compliant**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PB-3212PK](#)