

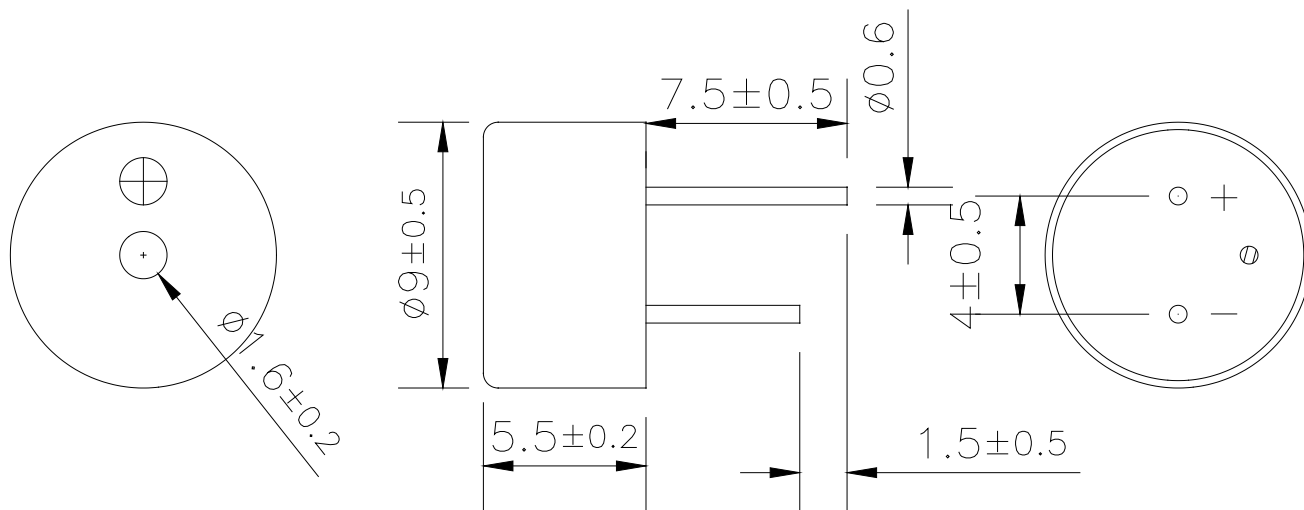
**Sales Outline Drawing**

Revision

**D**

**May not be suitable for all Medical and Aerospace applications.  
Contact Mallory Sonalert to discuss your application.**

Oscillation Frequency (Hz)	2300 $\pm$ 500
Operating Voltage (Vdc)	2.0 ~ 4.0
Rated Voltage (Vdc)	3.0
Current Consumption Max. (mA)	30 at Rated Voltage
Sound Pressure Level (dB/min)	82 at 10cm at Rated Voltage
Tone/Pulse Rate	Constant
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Lead Pin	Tin Plated Brass
Housing	PPO plastic resin (Color: Black)
Weight (Grams)	.6
Condition by wave soldering (°C)	260 $\pm$ 5 / 3 $\pm$ 0.5 sec
Condition by hand soldering (°C)	350 $\pm$ 20 / within 5 sec
Options	For other options contact factory

**Dimensions:** (units: mm)**ROHS Compliant**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PB-09N23P-03Q](#)