


**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**

Oscillation Frequency (Hz)	2300 \pm 300
Operating Voltage (Vdc)	20 ~ 28
Rated Voltage (Vdc)	24
Current Consumption Max. (mA)	30 at Rated Voltage
Sound Pressure Level Min. (dB)	85 at 10cm at Rated Voltage
Tone/Pulse Rate	Constant
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Housing	NORYL plastic resin (Color: Black)
Leading Pin	Tin Plated Brass
Weight (Grams)	2.0
Condition by wave (°C)	260 \pm 5 / within 5 sec
Condition by hand (°C)	350 \pm 20 / within 5 sec
Options	For other options contact factory

Dimensions: (units: mm)

ROHS Compliant

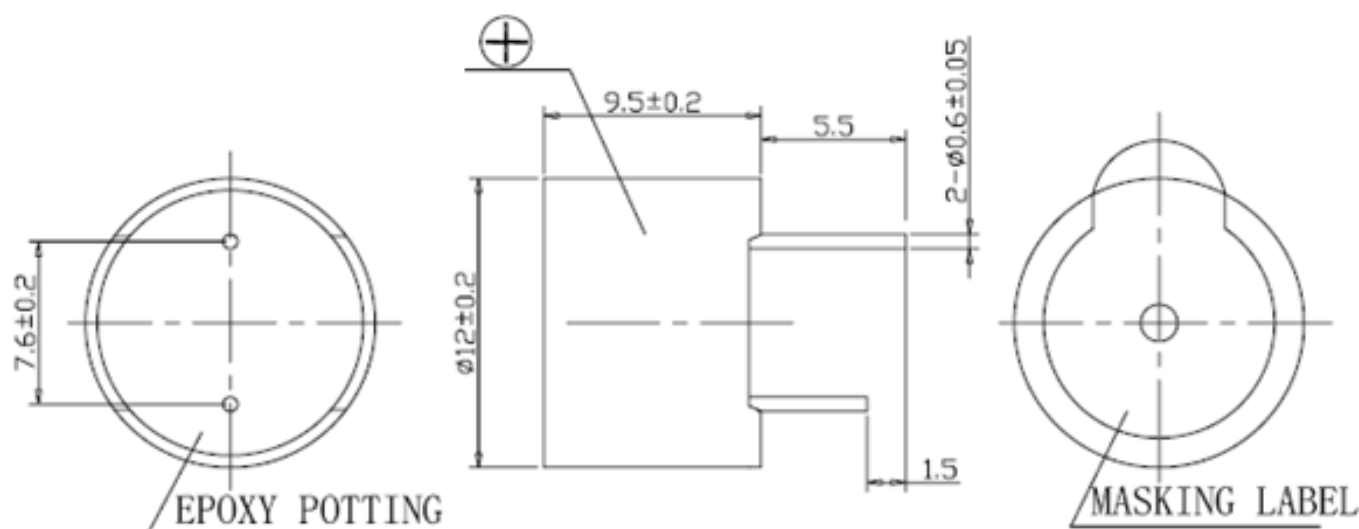

Packaging:

Parts are supplied 100 pcs per box.

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PB-12N23PC-24Q](#)