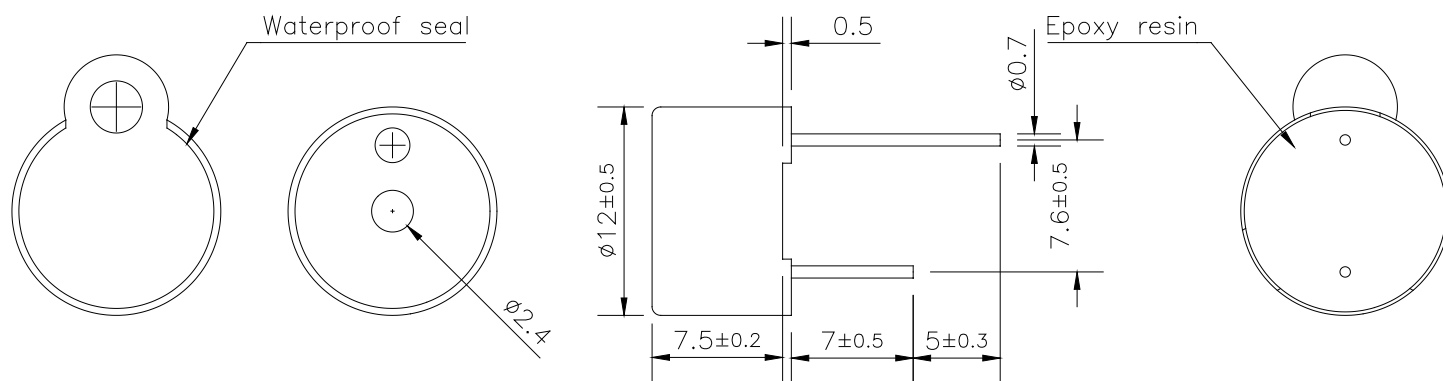


**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**

| | |
|----------------------------------|-----------------------------------|
| Oscillation Frequency (Hz) | 3200 \pm 400 |
| Operating Voltage (Vdc) | 9.0 ~ 15 |
| Rated Voltage (Vdc) | 12 |
| Current Consumption Max. (mA) | 50 at Rated Voltage |
| Sound Pressure Level Min. (dB) | 85 at 10cm at Rated Voltage |
| Tone/Pulse Rate | Constant |
| Operating Temperature (°C) | -20 ~ +70 |
| Storage Temperature (°C) | -30 ~ +80 |
| Housing | PPO plastic resin (Color: Black) |
| Leading Pin | Tin Plated Brass |
| Condition by wave soldering (°C) | 260 \pm 5 / within 5 sec |
| Condition by hand soldering (°C) | 350 \pm 20 / within 5 sec |
| Weight (Grams) | 1.6 |
| Options | For other options contact factory |

Dimensions: (units: mm)**ROHS Compliant**

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PB-12N32MP-12Q](#)