


**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**

Oscillation Frequency (Hz)	3000 \pm 500
Operating Voltage (VDC)	3 ~ 30
Rated Voltage (VDC)	12
Current Consumption Max. (mA)	12 at Rated Voltage
Sound Pressure Level Min. (dB)	80 at 30cm at Rated Voltage
Tone / Pulse Rate (Hz)	Fast Pulse 3.0 \pm 20%
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Housing	ABS 757 UL94 HB plastic resin (Color: Black)
Leading Pin	Tin Plated Brass
Weight (Grams)	3.0
Options	For other options contact factory

RoHS Compliant

Dimensions: (units: mm)

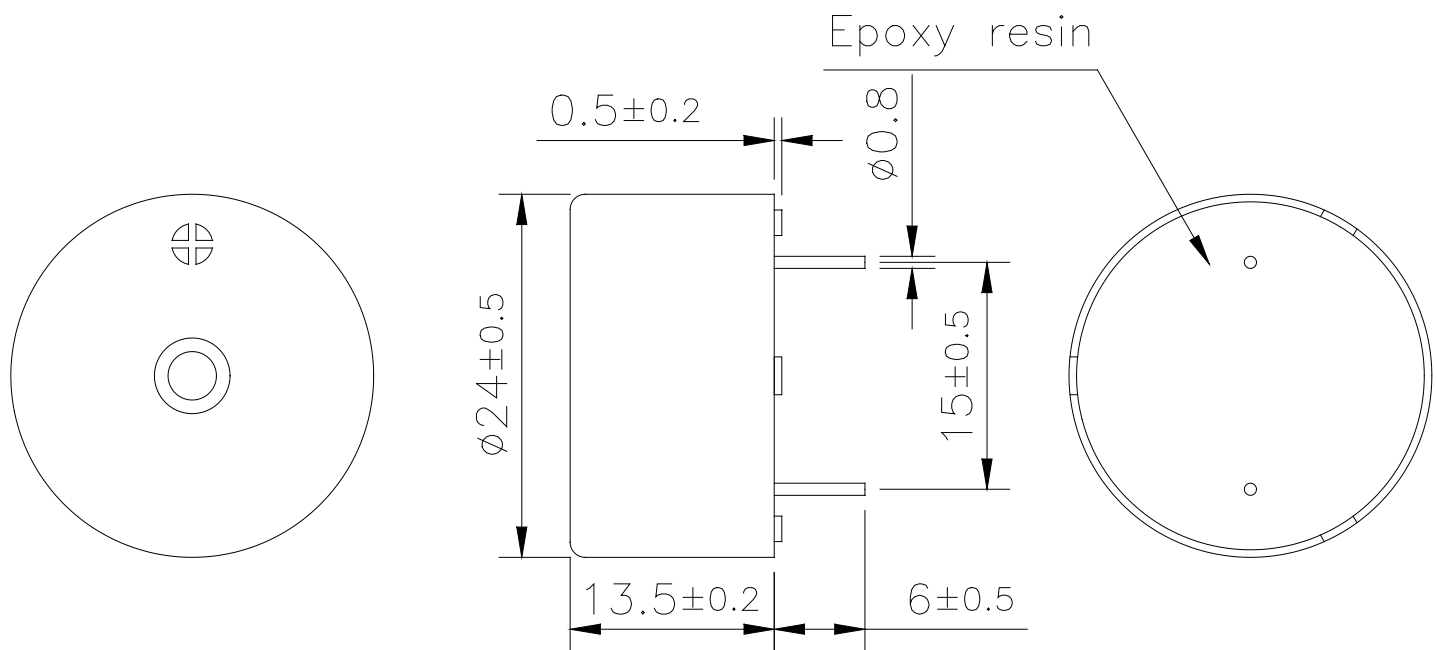

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PF-21N31PQ](#)