


**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**

Oscillation Frequency (Hz)	3000 \pm 500
Operating Voltage (VDC)	5 ~ 15
Rated Voltage (VDC)	12
Current Consumption Max. (mA)	30 at Rated Voltage
Sound Pressure Level Min. (dB)	95 at 30cm at Rated Voltage
Tone / Pulse Rate	Constant
LED Type	Multi-Color (See Note)
Operating Temperature ($^{\circ}$ C)	-20 ~ +70
Storage Temperature ($^{\circ}$ C)	-30 ~ +80
Housing	PC Plastic Resin (Color: Transparent)
Lead Wires	24 AWG
Weight (Grams)	17.8
Options	For other options contact factory

Dimensions: (units: mm)

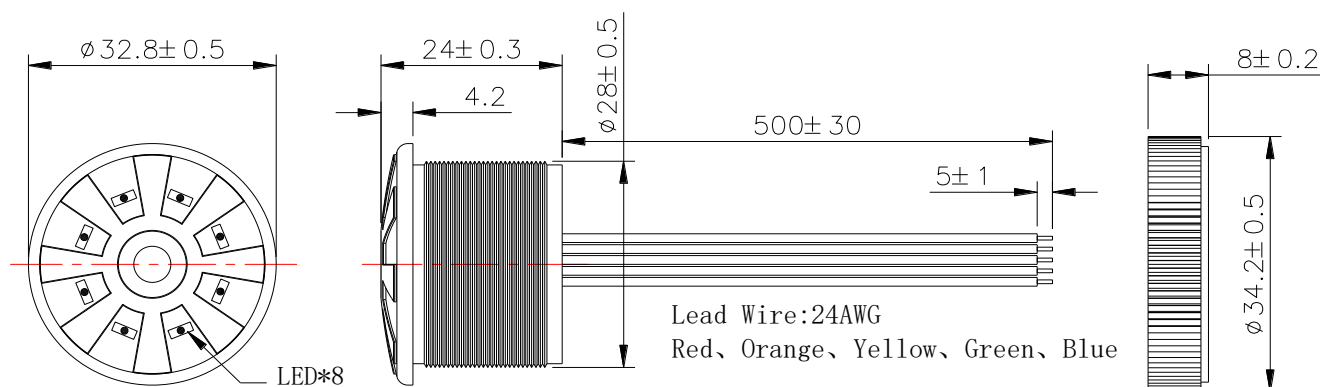

Note:

Connect Orange Wire to “+” and Yellow Wire to “-” for Constant Tone
Connect Orange Wire to “+” and Red Wire to “-” for Red Light
Connect Orange Wire to “+” and Blue Wire to “-” for Blue Light
Connect Orange Wire to “+” and Green Wire to “-” for Green Light

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PKD-27A30EWQ](#)