


**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**

Resonant Frequency (Hz)	400 ± 100
Operating Voltage (Vdc)	1.5 ~ 2.0
Rated Voltage (Vdc)	1.5
Current Consumption Max. (mA)	30 at Rated Voltage
Sound Pressure Level Min. (dB)	75 at 30cm at Rated Voltage
Tone/Pulse Rate	Constant
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +85
Housing	ABS 707 UL94HB plastic resin (Color: Black)
Leading Wire	26 AWG
Weight (Grams)	8.0
Options	For other options contact factory

Dimensions: (units: mm)

RoHS Compliant

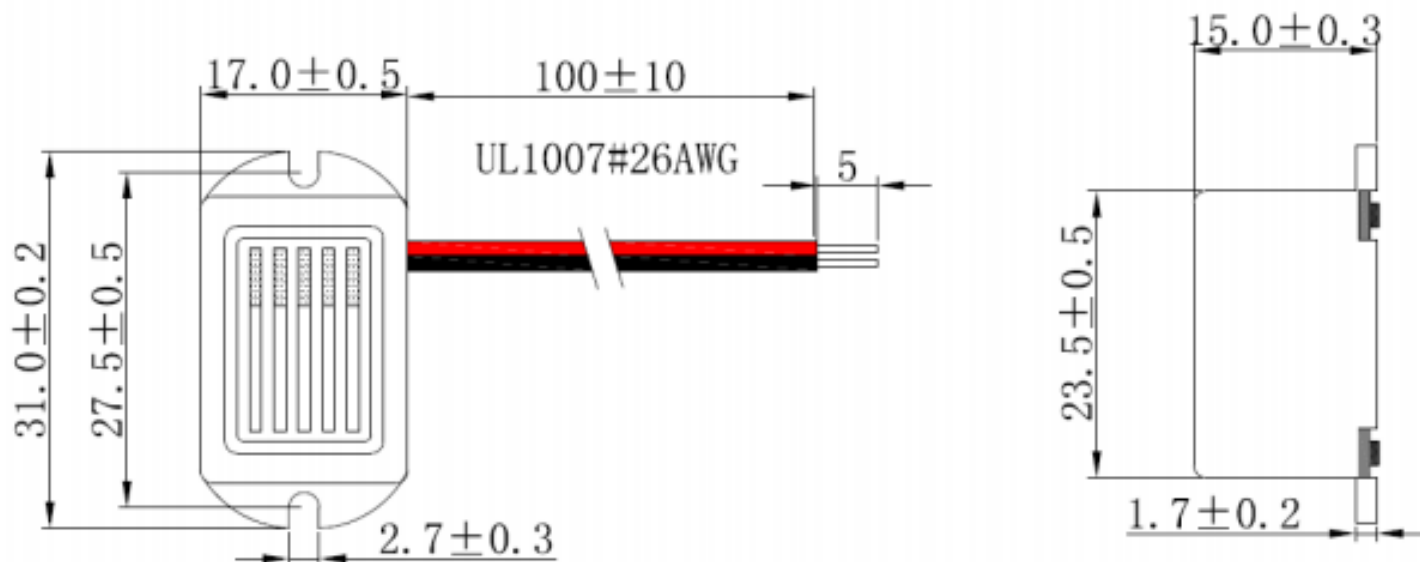

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PK-16N04WA-01Q](#)