


May not be suitable for all medical and aerospace applications.

Specifications: Contact Mallory Sonalert to discuss your application.

Resonant Frequency (Hz)	400 ± 100
Operating Voltage (Vdc)	8 ~ 16
Rated Voltage (Vdc)	12
Current Consumption Max. (mA)	35 at Rated Voltage
Sound Pressure Level Min. (dB)	84 at 30cm at Rated Voltage Typical
Tone/Pulse Rate	Constant
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Housing	ABS 757 UL94HB plastic resin (Color: Black)
Leading Wire	26 AWG
Weight (Grams)	7.8
Options	For other options contact factory

Dimensions: (units: mm)

RoHS Complaint

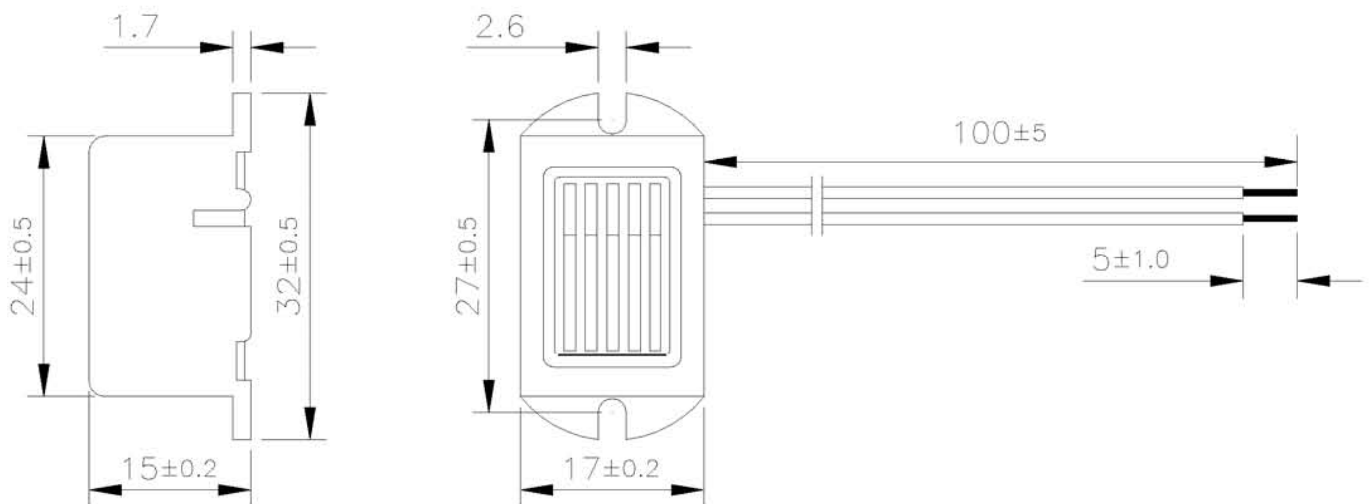

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PK-16N04WA-12Q](#)