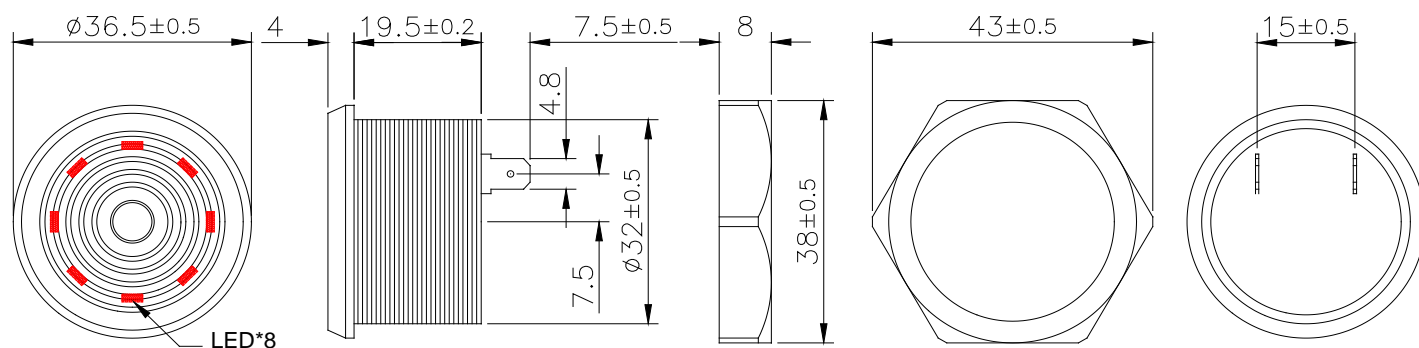


**Sales Outline Drawing****Revision C**

**May not be suitable for all Medical and Aerospace applications.  
Contact Mallory Sonalert to discuss your application.**

Oscillation Frequency (Hz)	3500 ± 500
Operating Voltage (Vdc)	3 – 15
Rated Voltage (Vdc)	12
Current Consumption (mA/max)	18 at Rated Voltage
Sound Pressure Level (dB/min)	95 at 30cm at Rated voltage
Tone/Pulse Rate	Constant
LED Color	BLUE
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Housing	ABS 757 UL94HB plastic resin (Color: Hyaline)
Terminals	Tin Plated Brass
Weight (Grams)	21
Options	For other options contact factory

**Dimensions:** (units: mm)**ROHS Compliant**

# Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PK-27A35EPDBQ](#)