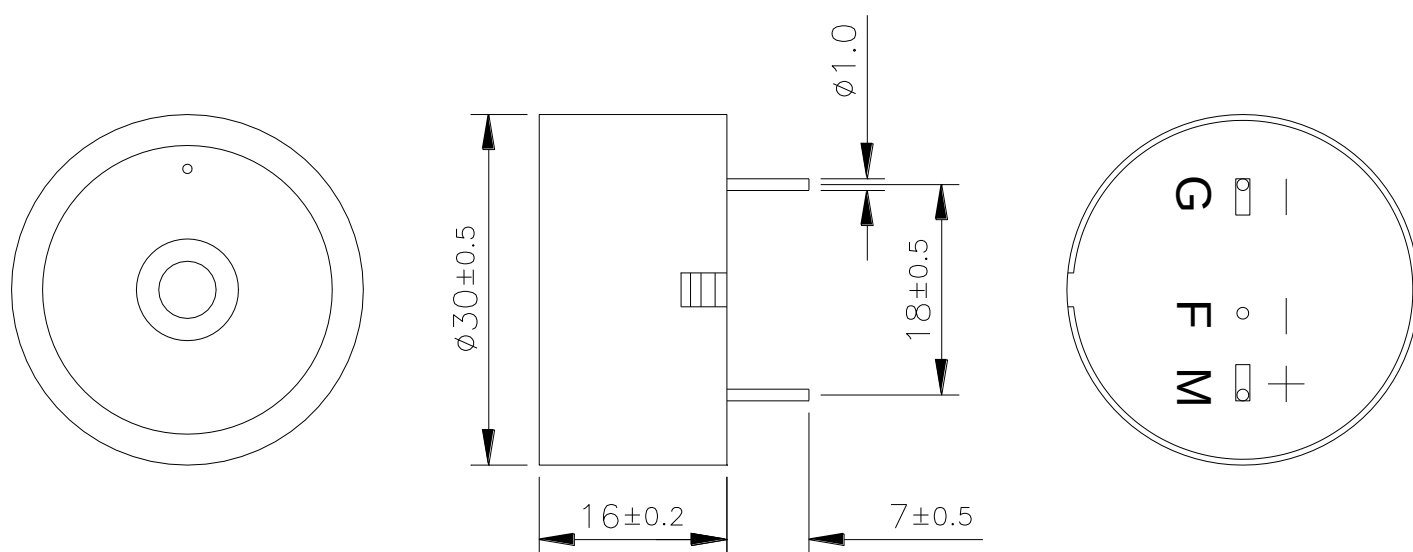


MALLORY**Mallory Sonalert
Products Inc.**Part # **PK-27H35P-24VQ****Sales Outline Drawing**Revision **A**

**May not be suitable for all Medical and Aerospace applications.
Contact Mallory Sonalert to discuss your application.**

Oscillation Frequency (Hz)	3500 ± 500
Operating Voltage (VDC)	18 ~ 28
Rated Voltage (VDC)	24
Current Consumption Max. (mA)	20 at Rated Voltage
Sound Pressure Level Min. (dB)	100 at 10cm at Rated Voltage
Tone / Pulse Rate	Constant
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Housing	ABS 757 Plastic Resin (Color: Black)
Lead Pin	Tin Plated Brass
Weight (Grams)	7.0
Condition by hand soldering (°C)	350 ±20 / within 5 sec
Options	For other options contact factory

Dimensions: (units: mm)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PK-27H35P-24VQ](#)