


May not be suitable for all medical and aerospace applications.

Specifications: Contact Mallory Sonalert to discuss your application.

Resonant Frequency (Hz)	3000 \pm 500
Operating Voltage (Vdc)	3 ~ 28
Rated Voltage (Vdc)	12
Current Consumption Max. (mA)	12 at Rated Voltage
Sound Pressure Level Min. (dB)	80 at 30cm at Rated Voltage
Tone/Pulse Rate (Hz)	Slow Pulse 1.2 \pm 20%
Operating Temperature (°C)	-20 ~ +90
Storage Temperature (°C)	-30 ~ +100
Housing	ABS 777 UL94HB plastic resin (Color: Black)
Leading Pin	Tin Plated Brass
Weight (Grams)	3.0
Options	For other options contact factory

Dimensions: (units: mm)

ROHS Complaint

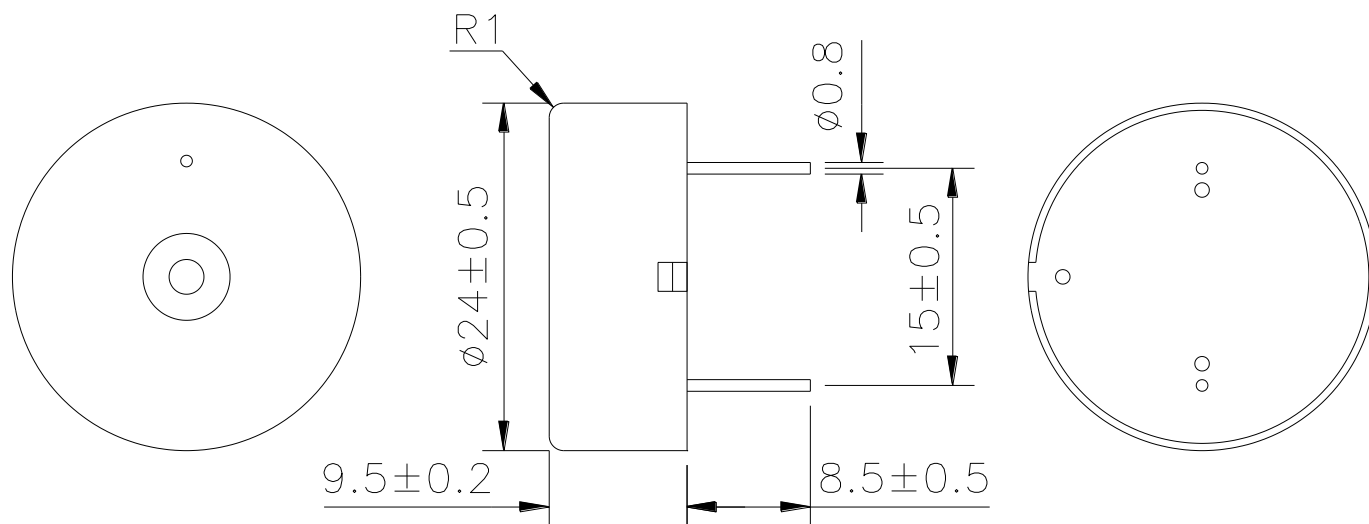

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PL-21N30PQ](#)