


May not be suitable for all medical and aerospace applications.

Specifications: Contact Mallory Sonalert to discuss your application.

Resonant Frequency (Hz)	3000 \pm 500
Operating Voltage (Vdc)	3 ~ 24
Rated Voltage (Vdc)	12
Current Consumption Max. (mA)	18 at Rated Voltage
Sound Pressure Level Min. (dB)	85 at 30 cm at Rated Voltage
Tone/Pulse Rate (Hz)	Constant + Slow Pulse 1.2 \pm 20%
Operating Temperature (°C)	-20 ~ +70
Storage Temperature (°C)	-30 ~ +80
Housing	ABS 757 UL94HB plastic resin (Color: Black)
Leading Wire	28 AWG
Weight (Grams)	3.6
Options	For other options contact factory

RoHS Compliant

Dimensions: (units: mm)

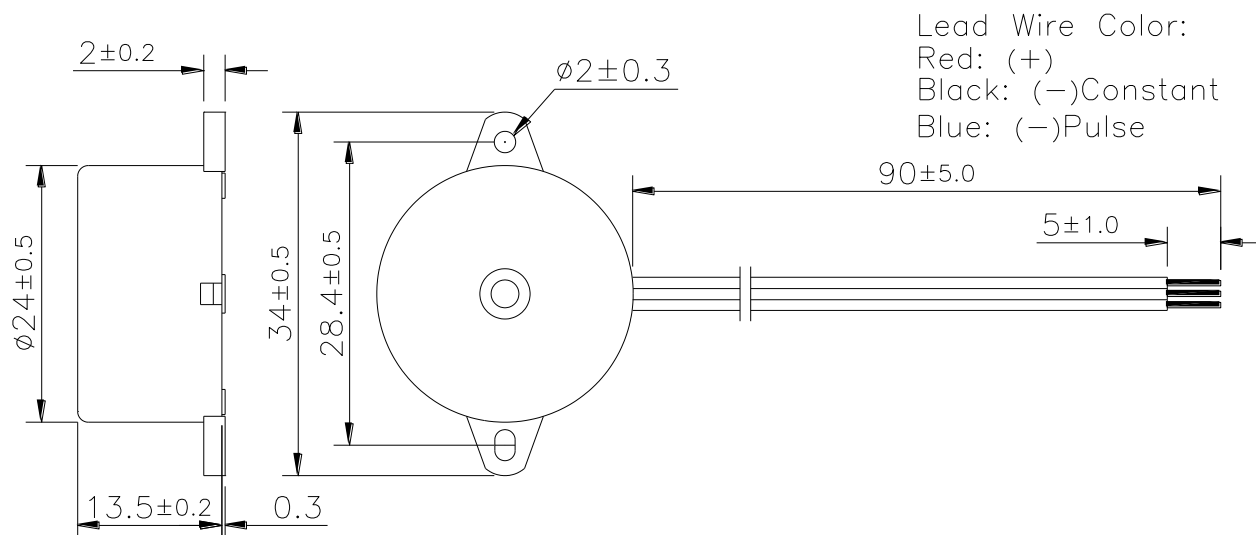

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PLD-21A29WQ](#)