

Sales Outline Drawing

Revision

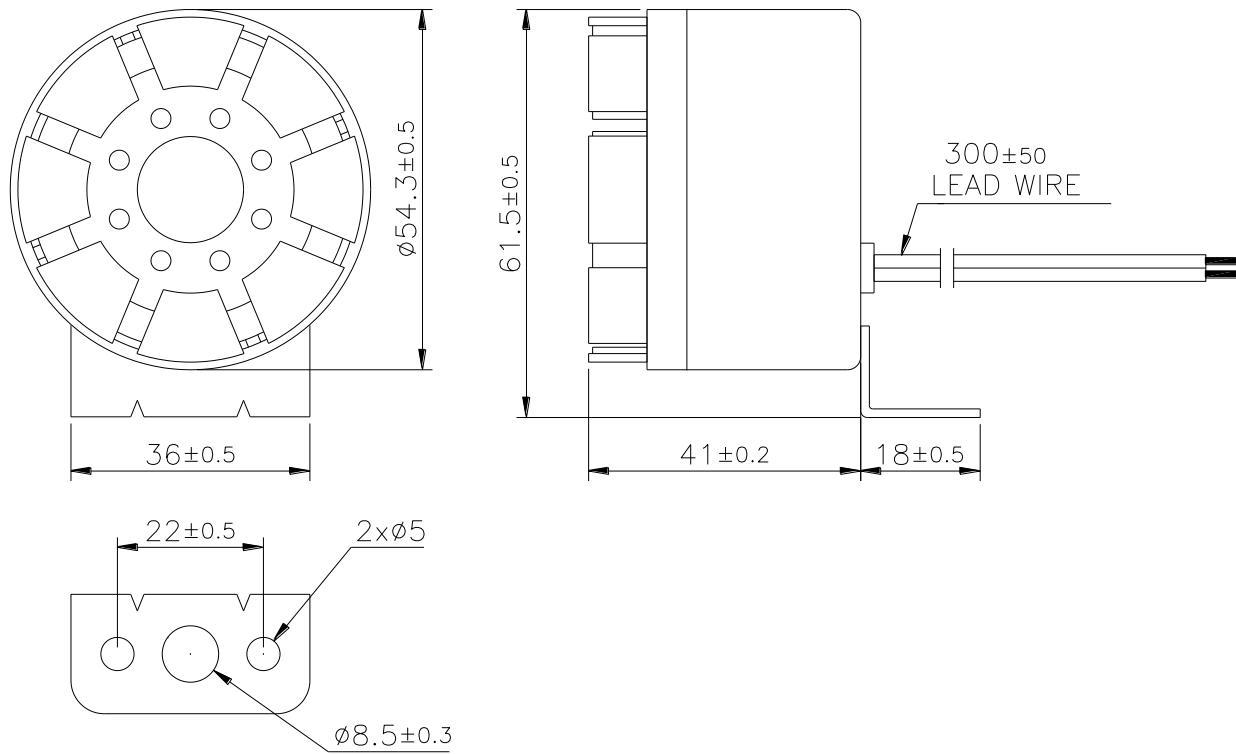
B

May not be suitable for all medical and aerospace applications.

Specifications: Contact Mallory Sonalert to discuss your application.

Resonant Frequency (Hz)	2500 \pm 350
Operating Voltage (Vdc)	5 \sim 15
Rated Voltage (Vdc)	12
Current Consumption (mA/max)	200 at Rated Voltage
Sound Pressure Level (dB/min)	105 at 100cm at Rated voltage
Tone/Pulse Rate (Hz)	Hi/Low 1.2 \pm 20%
Operating Temperature (°C)	-20 \sim +70
Storage Temperature (°C)	-30 \sim +80
Housing	ABS 757 UL94HB plastic resin (Color: Black)
Lead Wire	20 AWG
Weight (Grams)	73.2
Condition by wave soldering (°C)	245 \pm 5 / 3 \pm 0.5 sec
Condition by hand soldering (°C)	350 \pm 20 / within 5 sec
Options	For other options contact factory

RoHS Compliant

Dimensions: (units: mm)

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PS-552Q](#)