

Sales Outline Drawing


Revision C

Specifications:

Voice Coil Impedance (Ω)	$8 \pm 15\%$ at 800 Hz / 1.0 V
Rated Input (W)	0.25
Max. Input (W)	0.30
Lowest Resonance Freq Fo (Hz)	$1300 \pm 20\%$
Frequency Range (Hz)	Fo 6000
Output S.P.L. (dB)	80 ± 3 at 1W 100 Hz, 1k, 1.2k, 1.5kHz
Magnet Size (mm)	$\phi 16.0 * 1.9$
Magnet	Ferrite
Core Material Mylar	Transparent
Frame Material	Plastic
Operation / Storage Temp	-25 to 50°C
Weight	3.6g
Options	For other options contact factory

Dimensions: (units: mm)

ROHS Compliant

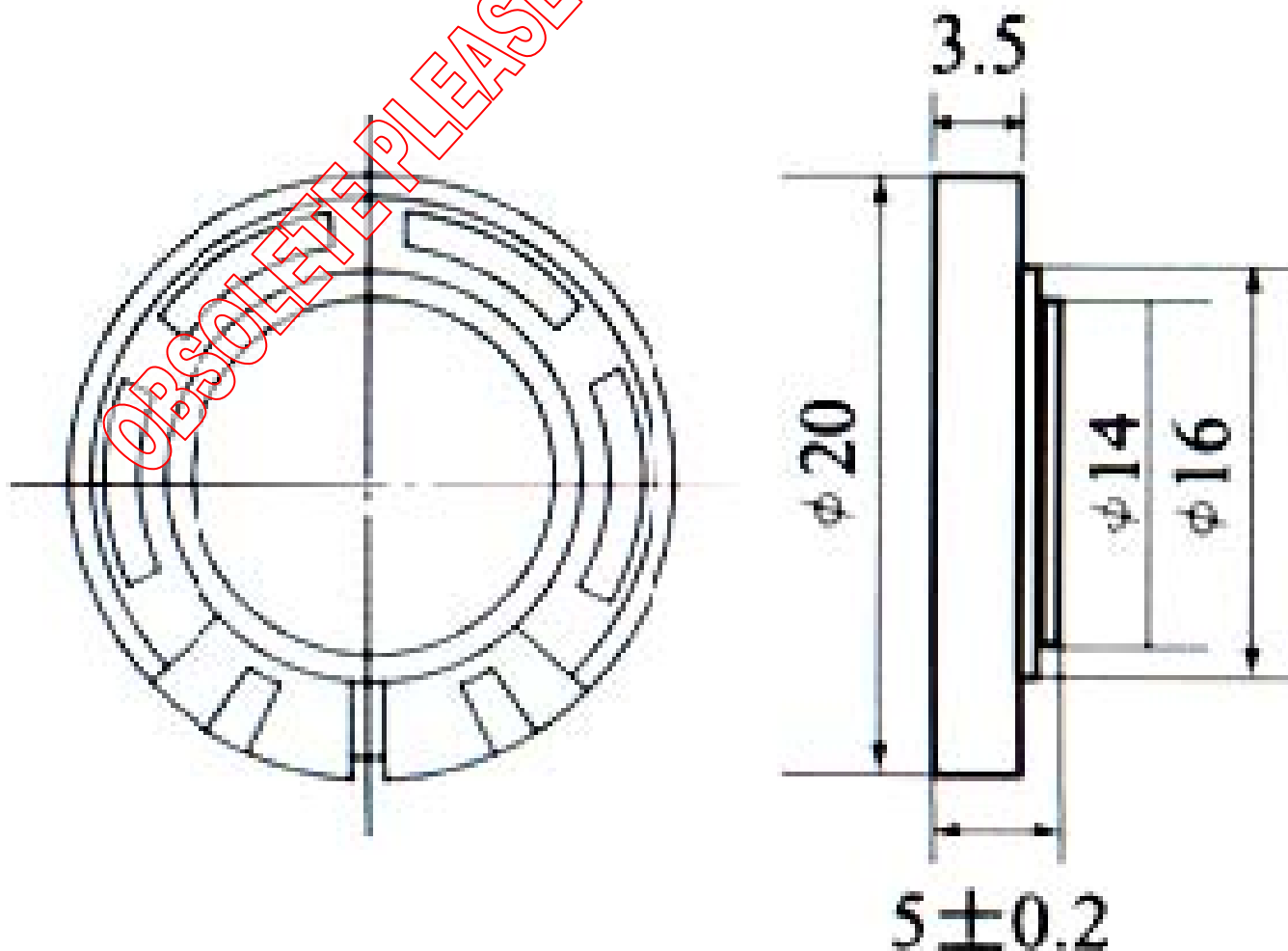

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PSR-20F08S-JQ](#)