

Sales Outline Drawing


May not be suitable for all medical and aerospace applications.

Specifications: Contact Mallory Sonalert to discuss your application.

Impedance (Ω)	$8 \pm 15\%$ at 1500 Hz at 1.0 V
Rated Power (W)	1.0
Max Power (W)	1.5
Resonance Freq F_o (Hz)	$570 \pm 20\%$ at 1.0V
Frequency Range (Hz)	$F_o \sim 5000$
Output S.P.L. (dB)	104 ± 3 at 1w/.1m 0.8k, 1.0k, 1.2k, 1.5kHz 88 ± 3 at 1w/0.5m 0.8k, 1.0k, 1.2k, 1.5kHz
Magnet Size (mm)	$\varnothing 12.5 \times 1.5$
Magnet	Nd-Fe-B
Frame Material	Metal
Operating Temp	-40 to 55°C
Weight (g)	8.0
Options	For other options contact factory

Dimensions: ± 0.5 (units: mm)

ROHS Compliant

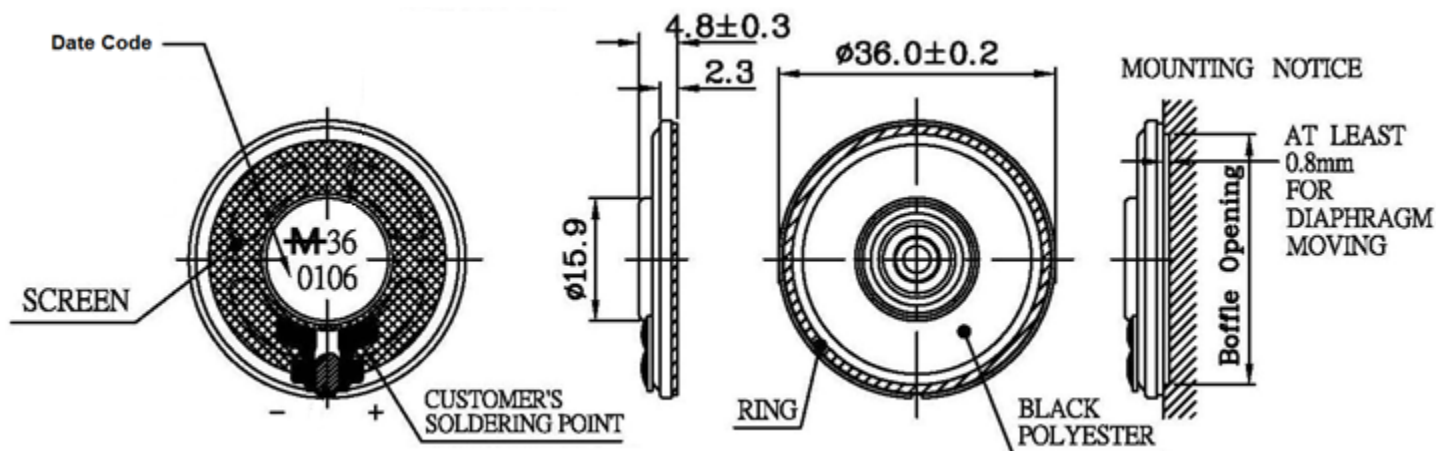

Mouser Electronics

Authorized Distributor

Click to View Pricing, Inventory, Delivery & Lifecycle Information:

[Mallory Sonalert:](#)

[PSR36N08AK](#)